


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

0.4 OD 12.5mm Dia, Absorptive ND Filter

See More by [Hoya](#)

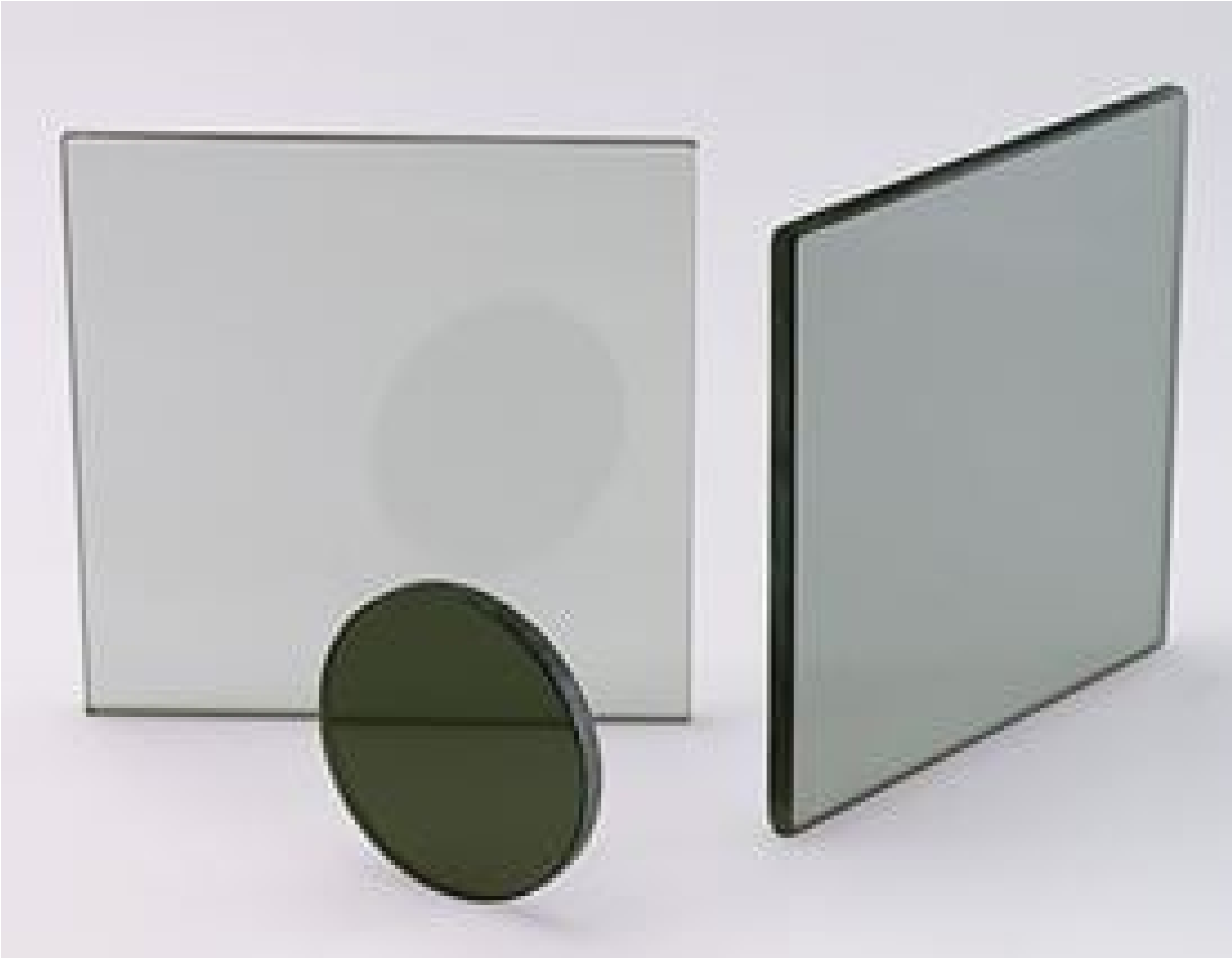

Stock #48-525 3-4 DAYS

1 €31,00

ADD TO CART

Qty 1-10

€31,00

Qty 11+

€28,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.50

Optical Density OD (Average):

0.4 ±0.05
Glass/Filter Number: Hoya ND-40
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.50
Surface Quality: 80-50
Transformation Temperature (°C): 525
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.5
Transmission (%): 40.0 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View