


Siemens Star Target, 60mm Dia., 72 Sectors Chrome on Glass

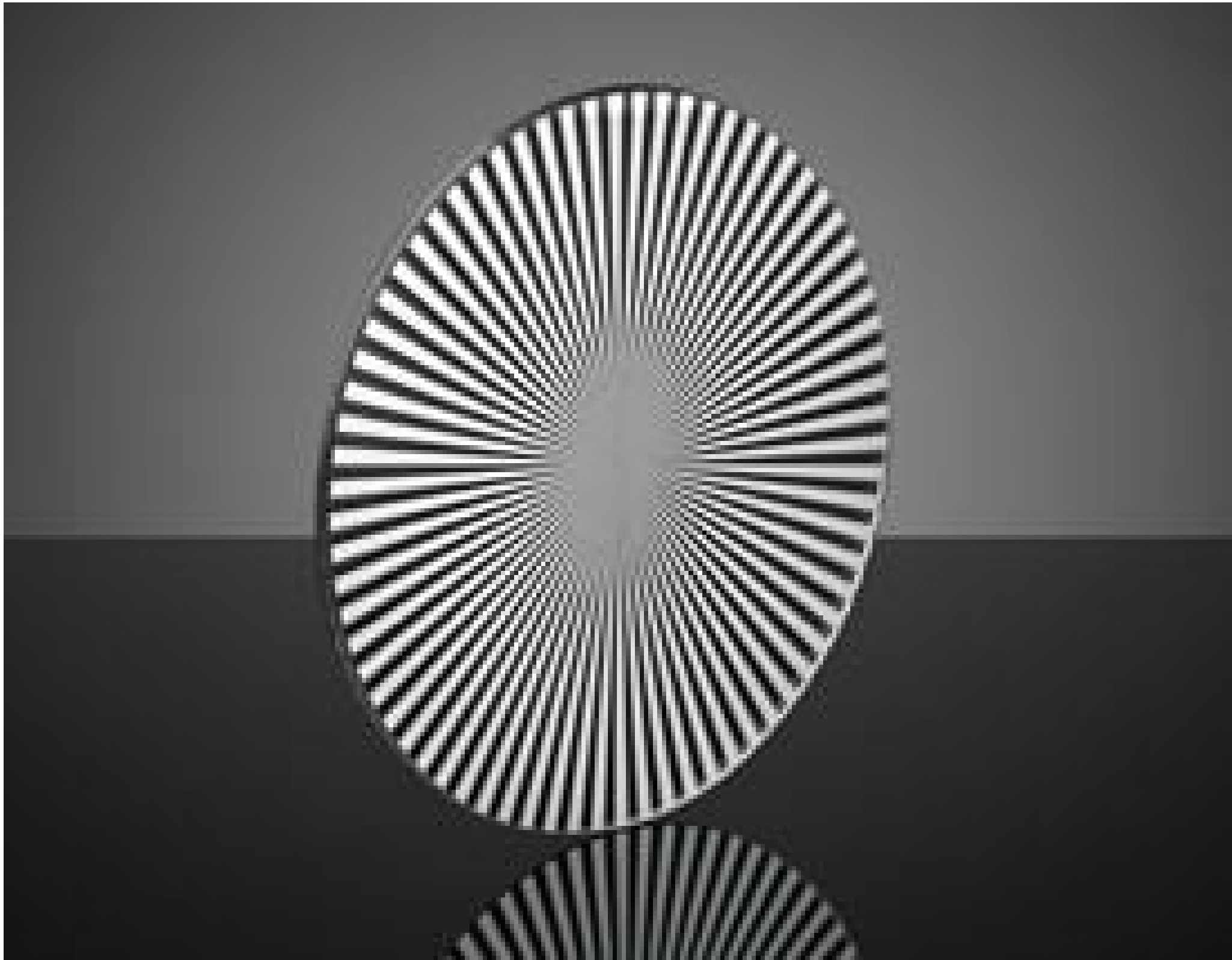

Glass Star Target

Stock #58-833 3-4 DAYS



1



€435,00

ADD TO CART

Qty 1-4

€435,00

Qty 5+

€413,60

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
Physical Vapor Deposition (Chromium Coating)

Diameter (mm):
60.00 ±0.1

Frequency (lp/mm):
0.458 - 229.2

Substrate: Float Glass
Line Width (mm): 1.1 - 0.002
Number of Sectors: 72
Optical Density OD (Average): >3.5
Pattern Diameter (mm): 50.00
Thickness (mm): 1.50 ±0.05
Wedge Angle: 5°
Unresolved Core Diameter (mm): 0.1
NIST Certification: No

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View