


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

1000µm, Optical Grade Plastic Optical Fiber Unjacketed

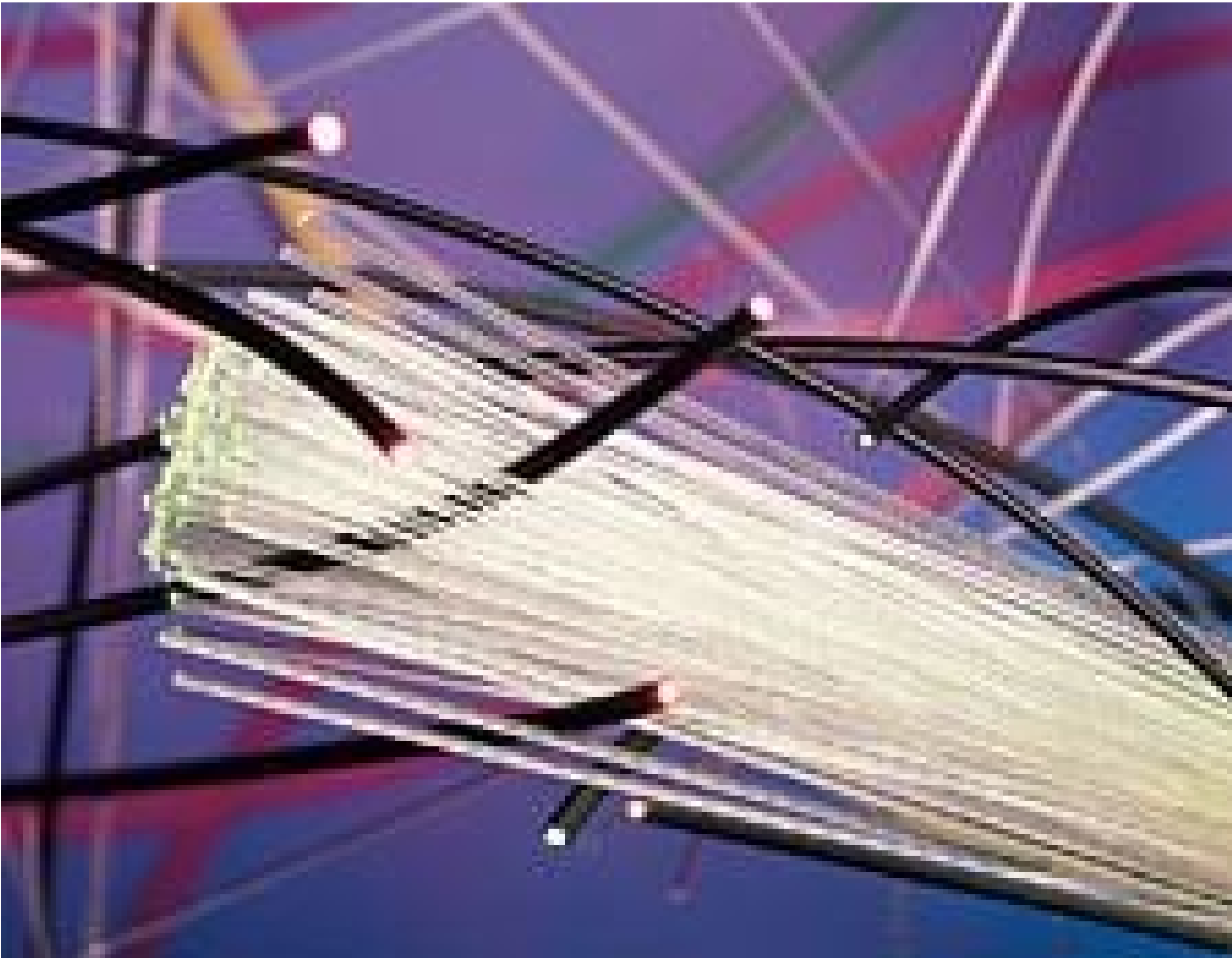

Stock #02-534 3-4 DAYS

- 1 + **€1,80**

ADD TO CART

Qty 1+

€1,80

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Acceptance Angle (°):
61.00

Minimum Bend Radius (mm):
25.00

Substrate:
Acrylic

Attenuation (dB/m):
0.15

Numerical Aperture NA:
0.51

Number of Fibers: 1.00
Operating Temperature (°C): -55 to +70
Outer Diameter (mm): 1.0
Core Diameter (μm): 980.00
Fiber Diameter (μm): 1000.00
Length (ft): Cut to Order, Minimum 10
Construction: Unjacketed
Index of Refraction n_d - Core: 1.492
Index of Refraction n_d - Cladding: 1.402
Attenuation (dB/km): 150 - 300 (@ 650nm)
Numerical Aperture (NA) Tolerance: ±0.03
Diameter Tolerance (%): ±6

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View