

In order to provide more accurate inventory information, please select your shipping country:


Select Your Country/Region: European Union



SUBMIT

10mm Square, 0.7mm Thick, Coherent® Uncoated Polycrystalline CVD Diamond window

See More by [Coherent®](#)

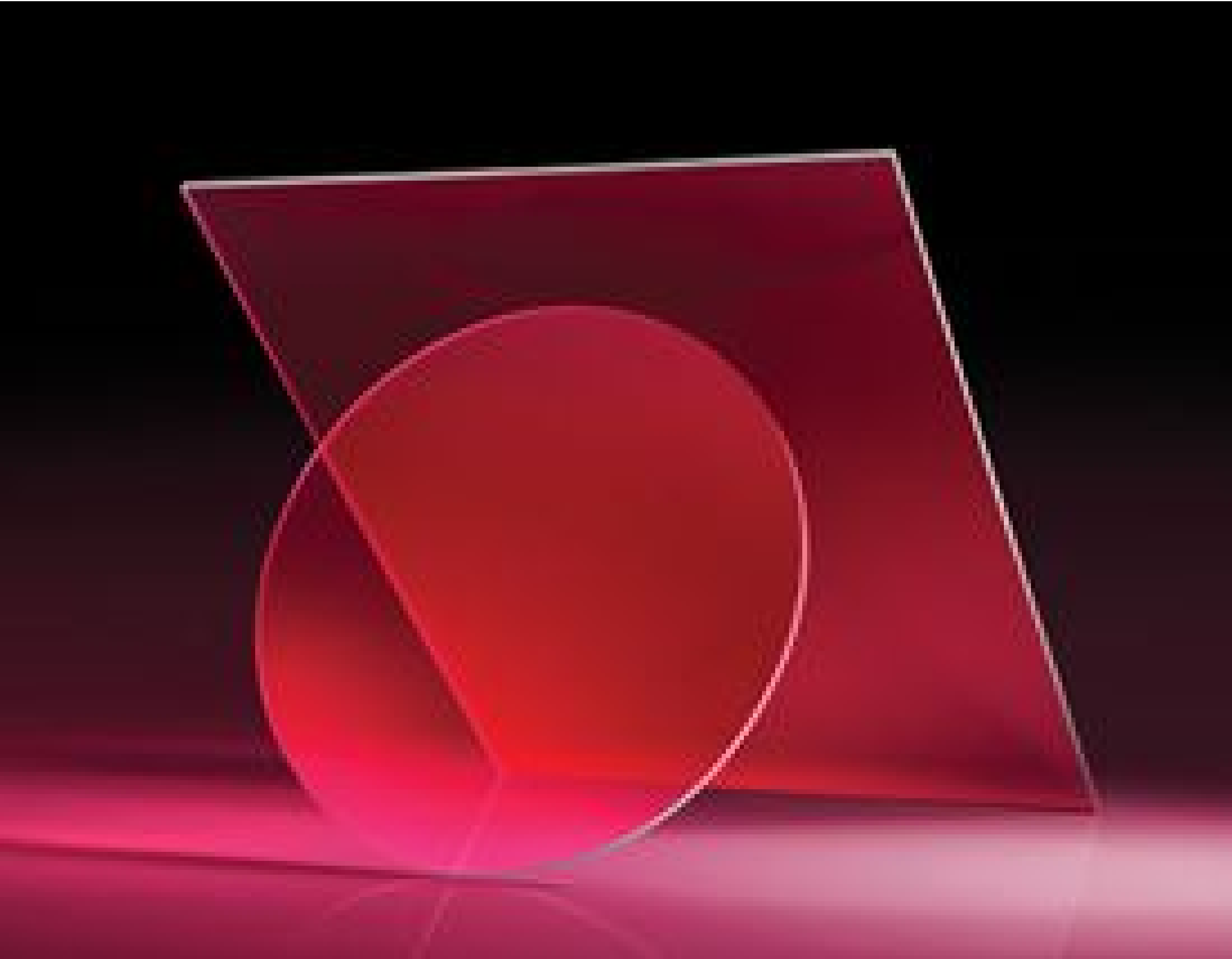

Stock #12-668 3-4 DAYS



1



€2.425,00

ADD TO CART

Qty 1-10
€2.425,00

Qty 11+
€2.182,50

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm):
9.00 x 9.00

Dimensions (mm): 10.00 x 10.00
Thickness (mm): 0.70 ±0.10
Coating: Uncoated
Index of Refraction n_d: 2.38 @ 10.6µm
Parallelism (arcmin): <5
Substrate: Coherent® Optical Grade Polycrystalline CVD Diamond
Surface Quality: 40-20
Type: Protective Window
Wavelength Range (nm): 300 - 25000
Length (mm): 10.00
Width (mm): 10.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View