


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 10mm Aperture, 125mm L Standard NA, Hexagonal Light Pipe

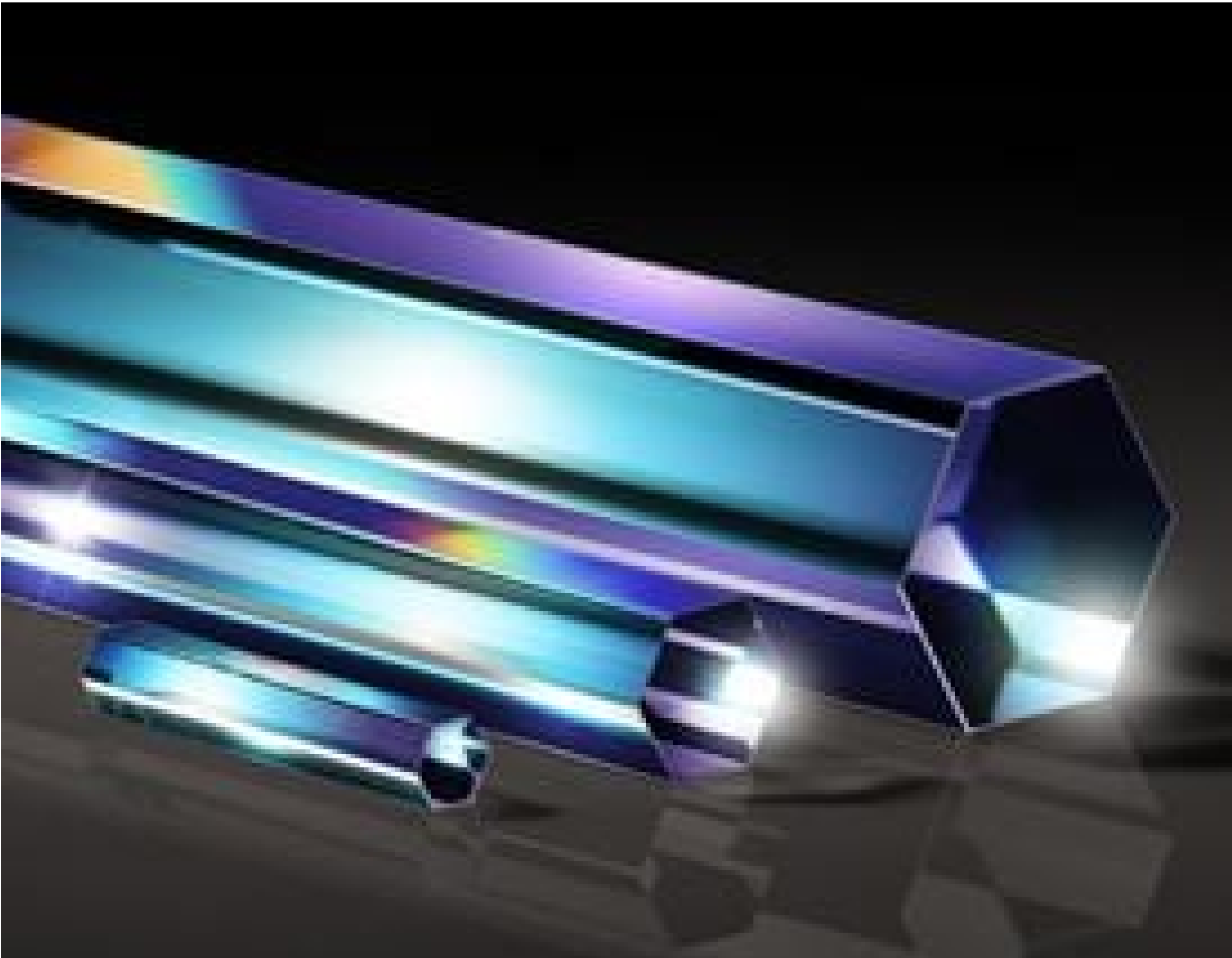

N-BK7 Light Pipe Homogenizing Rods



Stock #48-584 3-4 DAYS



1



€160,00

ADD TO CART

Qty 1-5

€160,00

Qty 6+

€128,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Uncoated

Substrate:

N-BK7
Length (mm): 125.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 10.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Standard
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 3λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
