


10mm Diameter Laser Diode Mirror

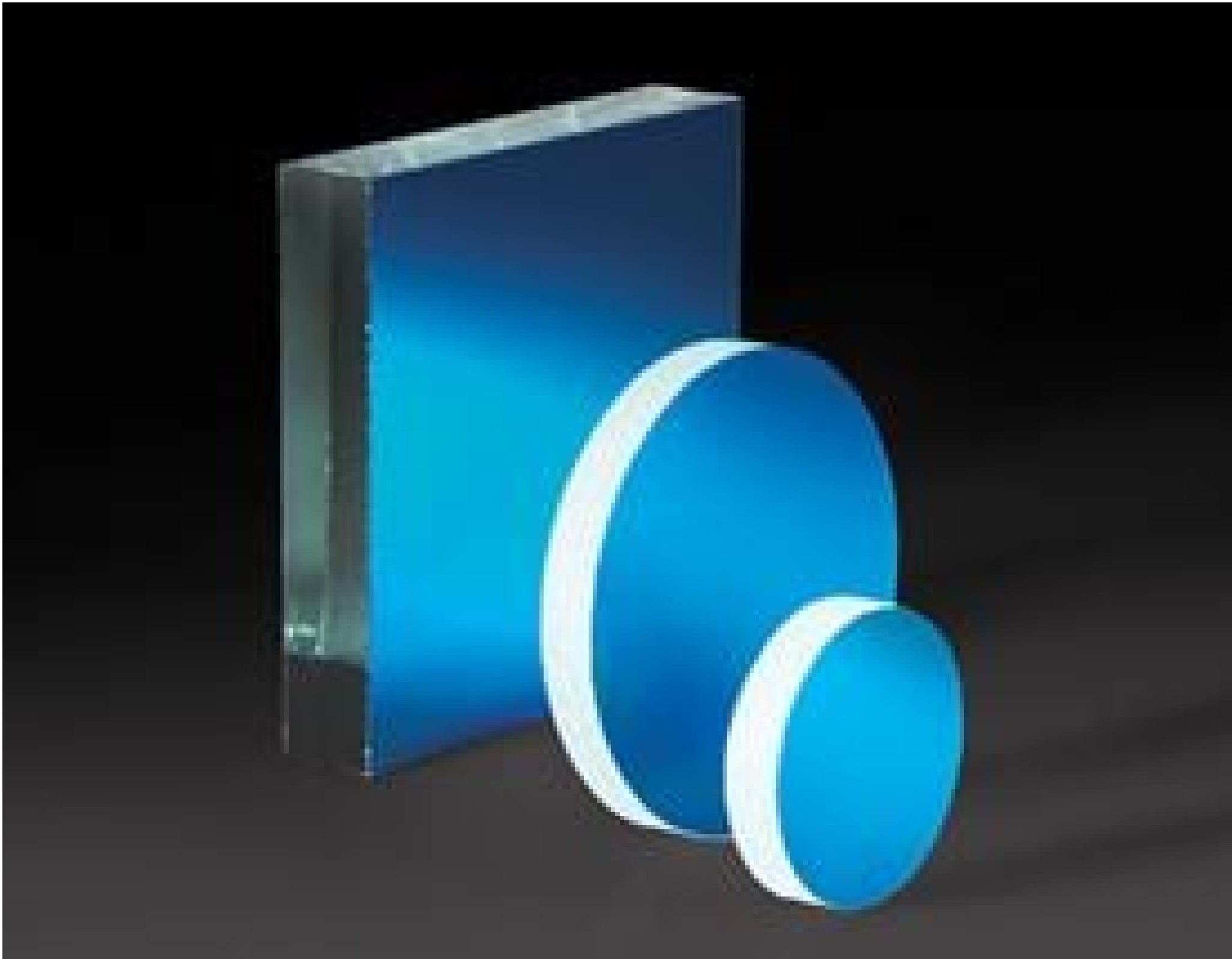

Stock **#43-853** ☐ In Stock

1 **€24,50**

ADD TO CART

Qty 1-10
€24,50
Qty 11+
€19,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
10.00 ±0.25

Substrate: ☐
Float Glass

Surface Quality:
80-50

Dimensional Tolerance (mm):

±0.25
Coating Specification: R _{abs} >97% @ 633nm
Coating: Dielectric Mirror (500-700nm)
Coating Type: Dielectric
Design Wavelength DWL (nm): 633
Durability: ML-C-48497A
Thickness (mm): 3.00
Type: Flat Mirror

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant