


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 12.5mm Enhanced Aluminum Coated, N-BK7 Right Angle Mirror

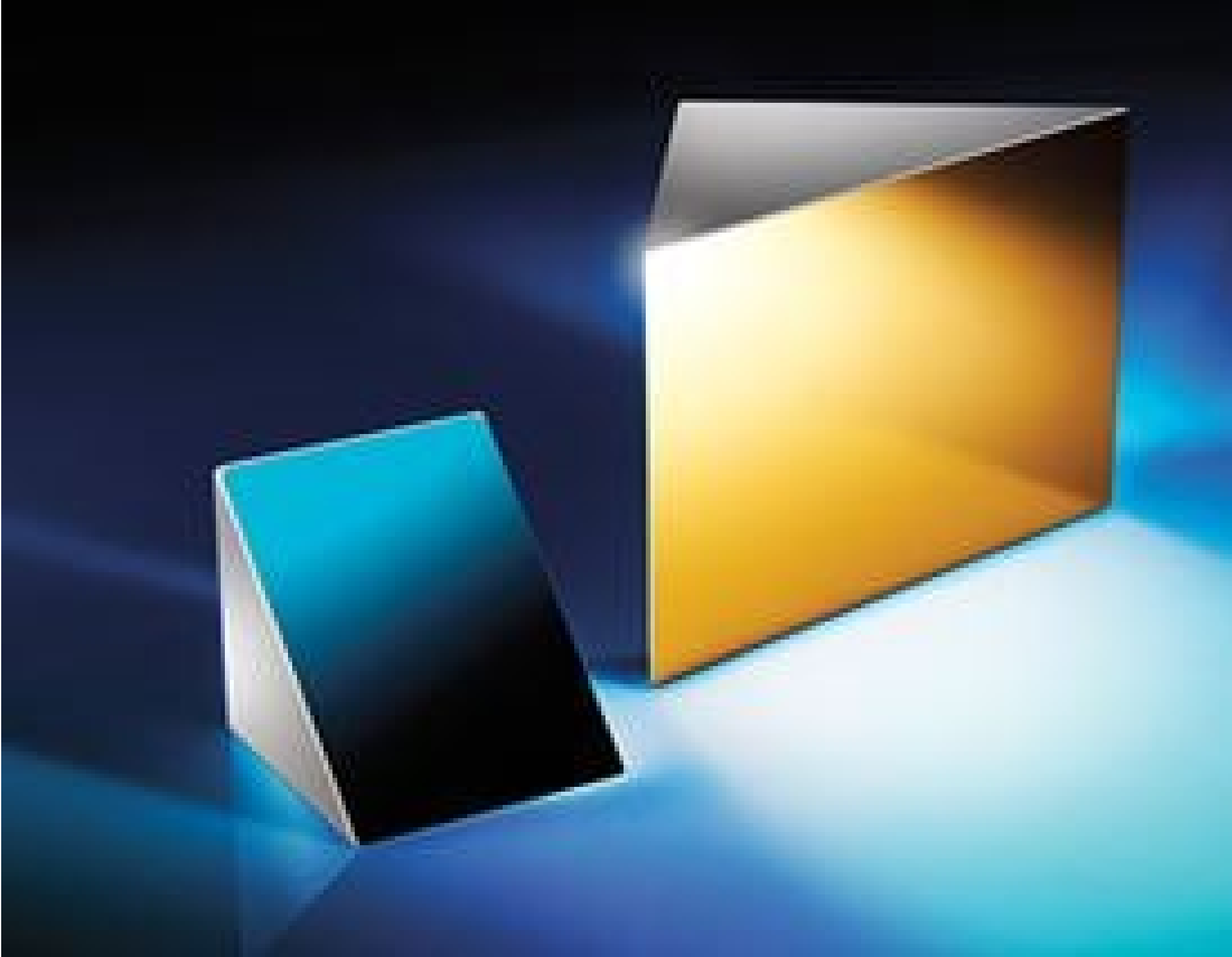

Stock #48-384 ☐ In Stock

-

1

+

 €82,50

ADD TO CART

Qty 1-5

€82,50

Qty 6+

€66,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/8

Substrate: ☐
[N-BK7](#)

Surface Quality:
40-20

Length of Legs (mm): 12.50
Dimensional Tolerance (mm): ±0.1
Coating Specification: R _{avg} >95% @ 450 - 650nm
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 15.91 x 11.25
Length of Hypotenuse (mm): 17.70
Type: Right Angle Mirror
Wavelength Range (µm): 0.45 - 0.65
Wavelength Range (nm): 450 - 650
Damage Threshold, Reference:  0.2 J/cm ² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View