


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 125mm, Side Drive, Thru-Hole, Metric Micrometer Stage

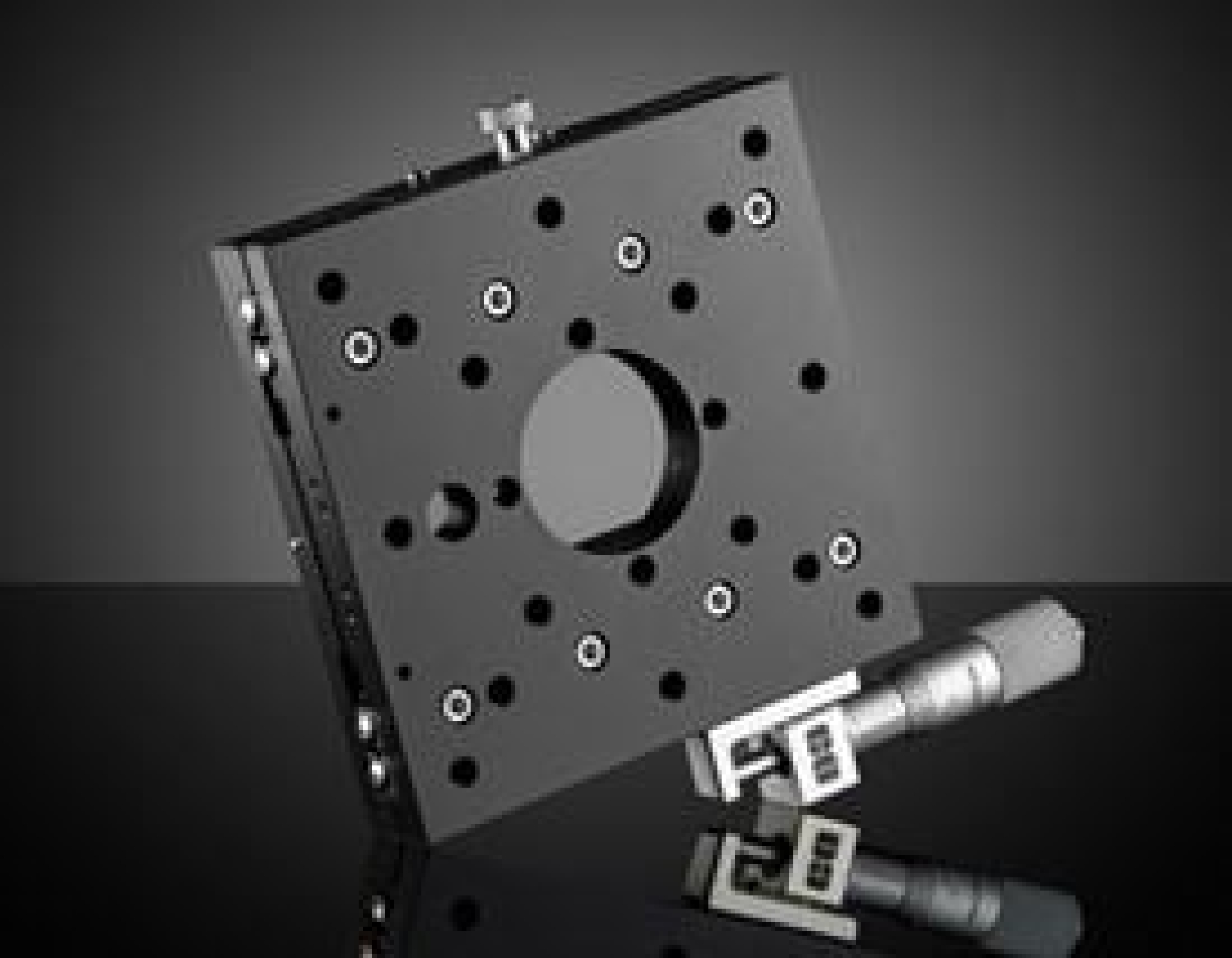

Stock #66-472 3-4 DAYS

- 1 + €620,00

ADD TO CART

Qty 1-2

€620,00

Qty 3+

€543,40

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:  
Linear (X)

Guide System:  
Crossed Roller Bearing

Type of Drive:  
Metric Micrometer

Drive Orientation:

|                                                         |
|---------------------------------------------------------|
| Side Drive                                              |
| <b>Type:</b><br>Metric                                  |
| <b>Stage Size (mm):</b><br>125 x 125                    |
| <b>Travel (mm):</b><br>25                               |
| <b>Center Hole:</b><br>M42 x 0.75                       |
| <b>Construction:</b><br>Aluminium Stage                 |
| <b>Leadscrew Pitch (mm):</b><br>0.5                     |
| <b>Load Capacity (kg):</b><br>20                        |
| <b>Mounting Threads:</b><br>(1) M42 x 0.75, (20) M6 x 1 |
| <b>Stage Size (inches):</b><br>4.92 x 4.92              |
| <b>Straight Line Accuracy (µm):</b><br>2                |
| <b>Pitch (arcsec):</b><br>30                            |
| <b>Yaw (arcsec):</b><br>25                              |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Exempt</a>                |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 233:</b><br><a href="#">Contains SVHC(s)</a>      |