


12mm, 0.59mm Focal Length, Fast Axis Collimator

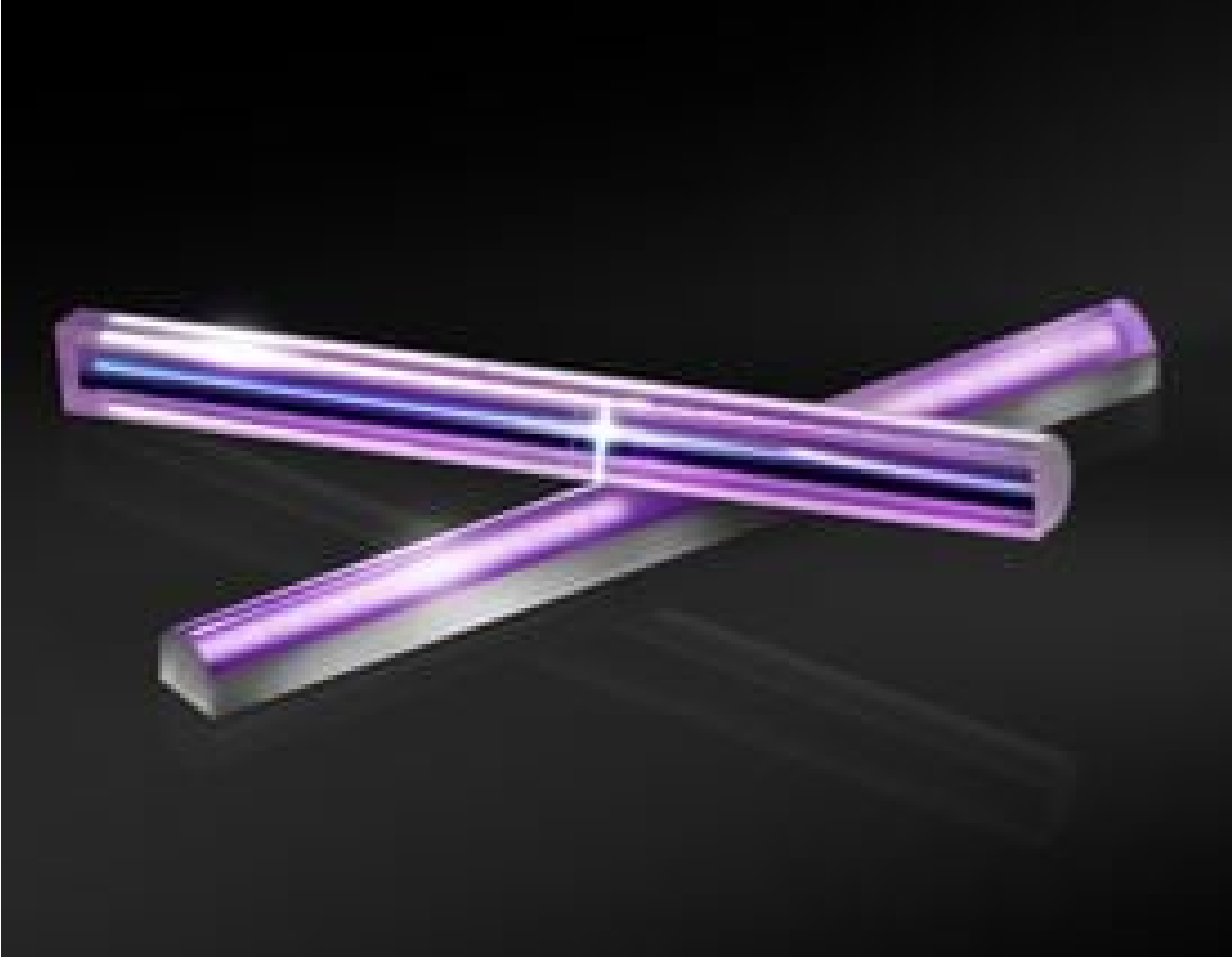

Fast Axis Collimators

Stock **#87-351** 3-4 DAYS



1



€190,00

ADD TO CART

Qty 1-10

€190,00

Qty 11+

€167,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Effective Focal Length EFL (mm):
0.59

Substrate: ☐
[S-TIH53](#)

f/#:
0.63

Numerical Aperture NA: 0.80
Coating: BBAR (790-990nm)
Type: Beam Shaping Lens
Wavelength Range (nm): 790 - 990
Back Focal Length BFL (mm): 0.15
Clear Aperture CA (mm): 11.0 x 0.9
Coating Specification: R _{avg} <1.0% @ 790 - 990nm
Height (mm): 1.00
Height Tolerance (mm): ±0.05
Length (mm): 12.00
Length Tolerance (mm): ±0.05
Power Distribution (%): within ±1.1: >85
Surface Accuracy: λ/4
Transmission (%): >99
Width (mm): 0.80
Width Tolerance (mm): ±0.01

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View