


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

12mm, 1.50mm Focal Length, Fast Axis Collimator

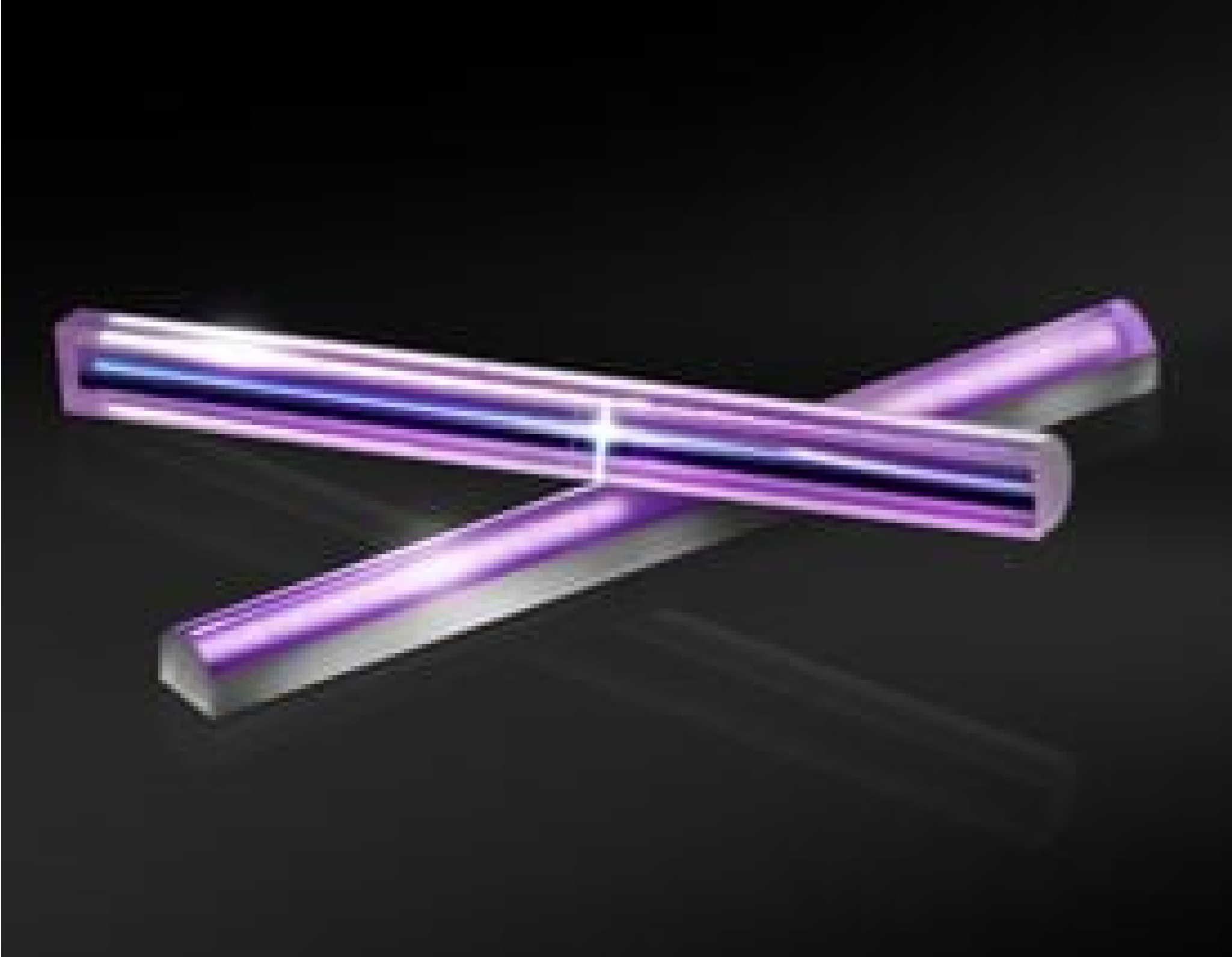

Fast Axis Collimators

Stock #87-353 3-4 DAYS



1



€190,00

ADD TO CART

Qty 1-10

€190,00

Qty 11+

€167,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Effective Focal Length EFL (mm):
1.50

Substrate: □
[S-TIH53](#)

f/#:
0.7

Numerical Aperture NA: 0.50
Coating: BBAR (790-990nm)
Type: Beam Shaping Lens
Wavelength Range (nm): 790 - 990
Back Focal Length BFL (mm): 0.45
Clear Aperture CA (mm): 11.0 x 1.55
Coating Specification: R _{avg} <1.0% @ 790 - 990nm
Height (mm): 1.65
Height Tolerance (mm): ±0.05
Length (mm): 12.00
Length Tolerance (mm): ±0.05
Power Distribution (%): within ±0.8: >85
Surface Accuracy: λ/4
Transmission (%): >99
Width (mm): 1.82
Width Tolerance (mm): ±0.01

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View