


2.0 OD, 12.5mm Dia., IR Neutral Density Filter

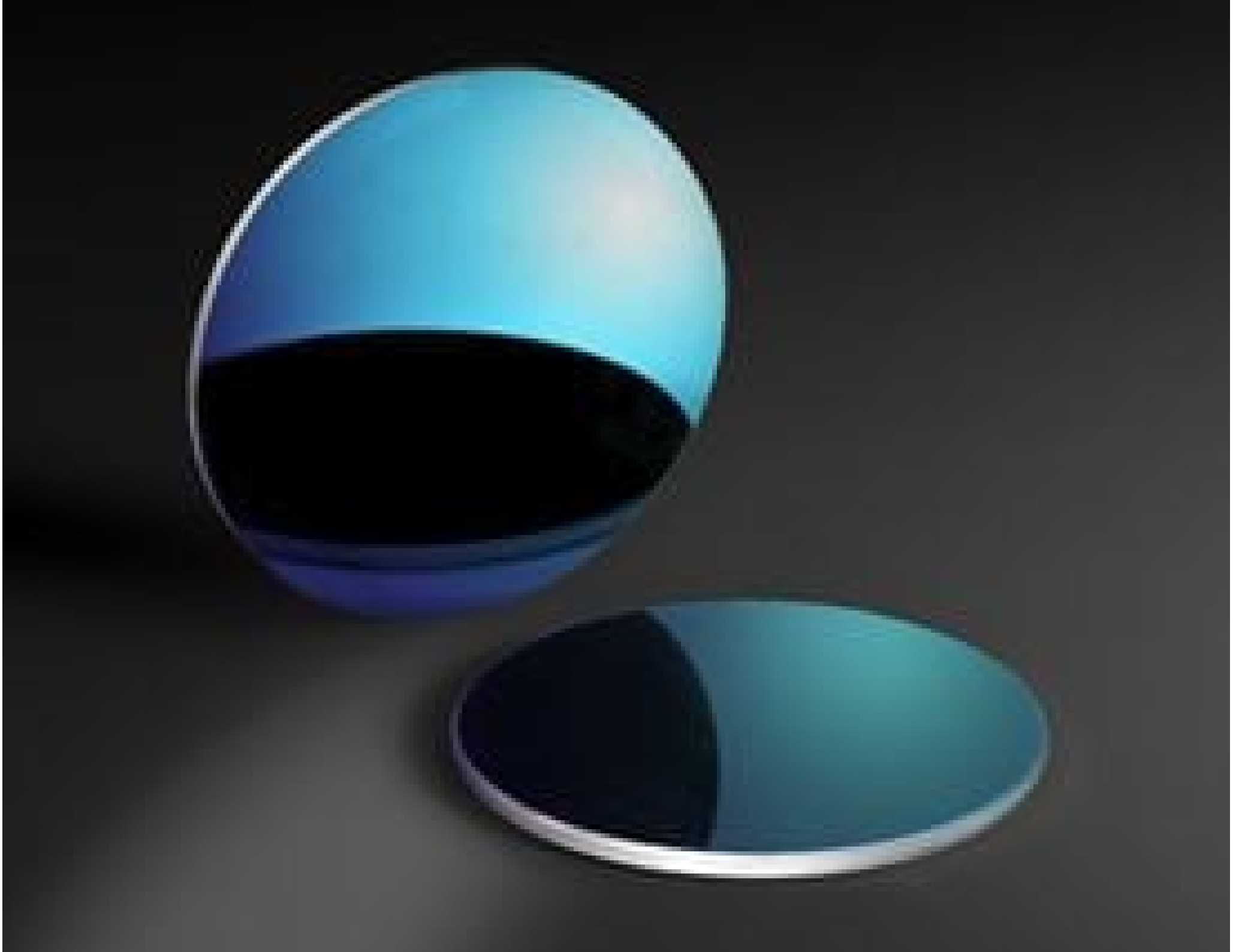

Infrared (IR) Neutral Density (ND) Filters

Stock #12-015 3-4 DAYS

⊖ 1 ⊕ **€205,00**

ADD TO CART

Qty 1-10

€205,00

Qty 11+

€184,50

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50 ±0.2

Optical Density OD (Average):
2.0

Substrate:
Germanium (Ge)

Coating:
Metallic Based ND

Surface Quality:
80-50

Thickness (mm):
1.00 ±0.2

Transmission (%):
1.0

Transmission Tolerance (%):
±0.25

Type:
Neutral Density Filter

Blocking Wavelength Range (nm):
2000 - 14,000

Parallelism (arcmin):
<10

Clear Aperture (%):
90

Wavelength Range (µm):
2 - 14

Surface Flatness (P-V):
3 - 5λ

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

REACH 241:
[Compliant](#)
