


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

2.0 OD 50mm Sq, Absorptive ND Filter

See More by [Hoya](#)

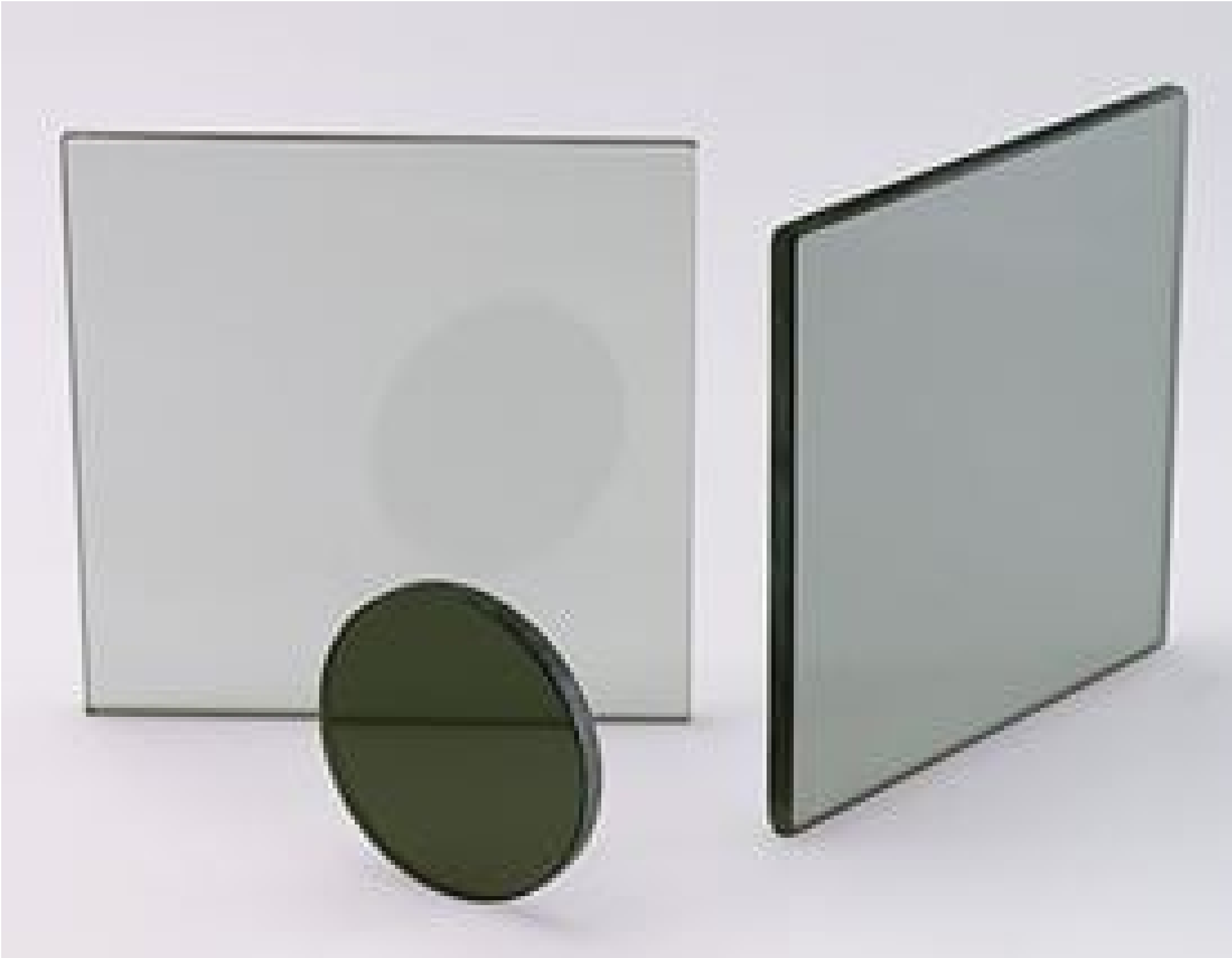

Stock #48-097 ☐ In Stock



1



€95,00

ADD TO CART

Qty 1-10

€95,00

Qty 11+

€84,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
50.0 x 50.0

Optical Density OD (Average):

2.0 ±0.05
Glass/Filter Number: Hoya ND-0.3
Substrate: ☐ ND Filter Glass
Length (mm): 50.00
Coating: Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 80-50
Transformation Temperature (°C): 490
Thickness (mm): 2.00
Thickness Tolerance (mm): ±0.5
Transmission (%): 1.0 (average)
Type: Neutral Density Filter
Width (mm): 50.00
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.2
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View