


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 20 X 20mm Protected Gold, $\lambda/20$ Mirror

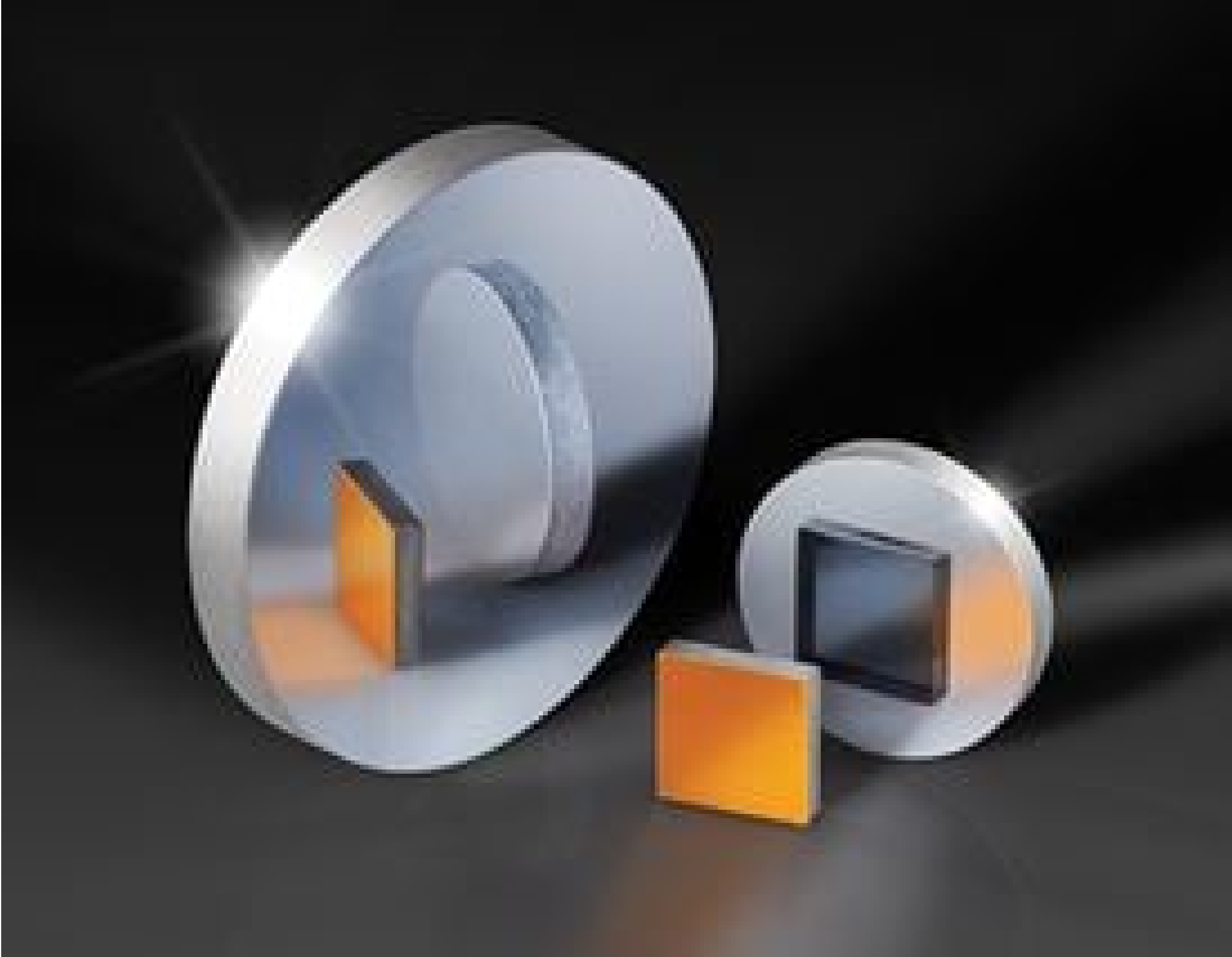

Stock #34-375 3-4 DAYS



1



€168,00

ADD TO CART

Qty 1-5

€168,00

Qty 6+

€134,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
 $\lambda/20$ (flatness pre-coating)

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Back Surface:
Commercial Polish

Surface Quality: 20-10
Dimensions (mm): 20.0 x 20.0 +0.00/-0.20
Coating Specification: R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm
Coating: Protected Gold (700-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 3.00
Type: Flat Mirror
Wavelength Range (nm): 700 - 10000
Length (mm): 20.00
Width (mm): 20.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant