


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

20mm Diameter Laser Diode Mirror

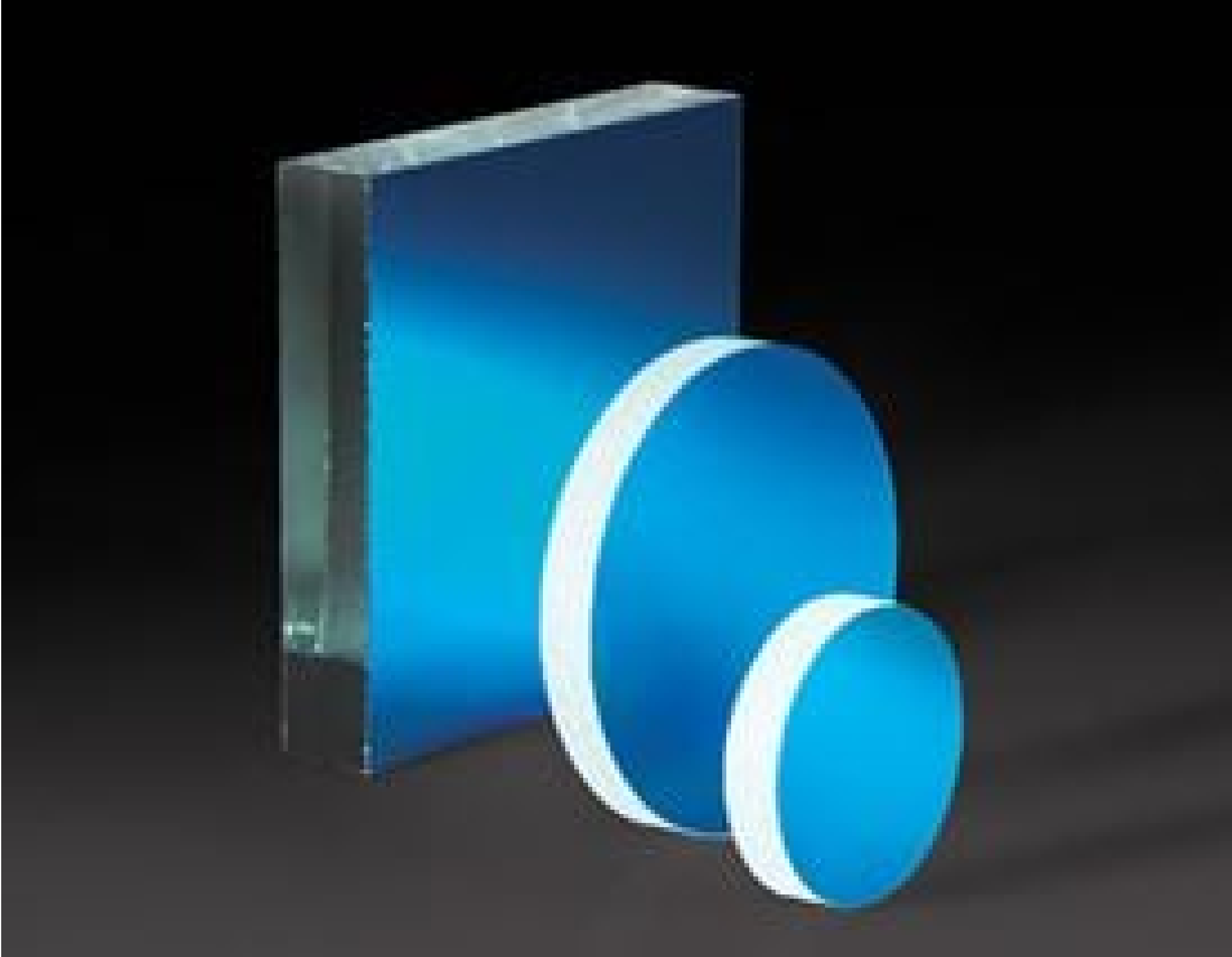

Stock #46-619 3-4 DAYS

- 1 + €24,50

ADD TO CART

Qty 1-10

€24,50

Qty 11+

€19,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):  
20.00 ±0.25

Substrate: ☐  
Float Glass

Surface Quality:  
80-50

Dimensional Tolerance (mm):

|                                                                |
|----------------------------------------------------------------|
| ±0.25                                                          |
| <b>Coating Specification:</b><br>R <sub>abs</sub> >97% @ 633nm |
| <b>Coating:</b><br>Dielectric Mirror (500-700nm)               |
| <b>Coating Type:</b><br>Dielectric                             |
| <b>Design Wavelength DWL (nm):</b><br>633                      |
| <b>Durability:</b><br>ML-C-48497A                              |
| <b>Thickness (mm):</b><br>3.00                                 |
| <b>Type:</b><br>Flat Mirror                                    |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 233:</b><br><a href="#">Compliant</a>             |