


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

25.4mm Dia. 1030nm 0°, Low Cost Laser Line Mirror

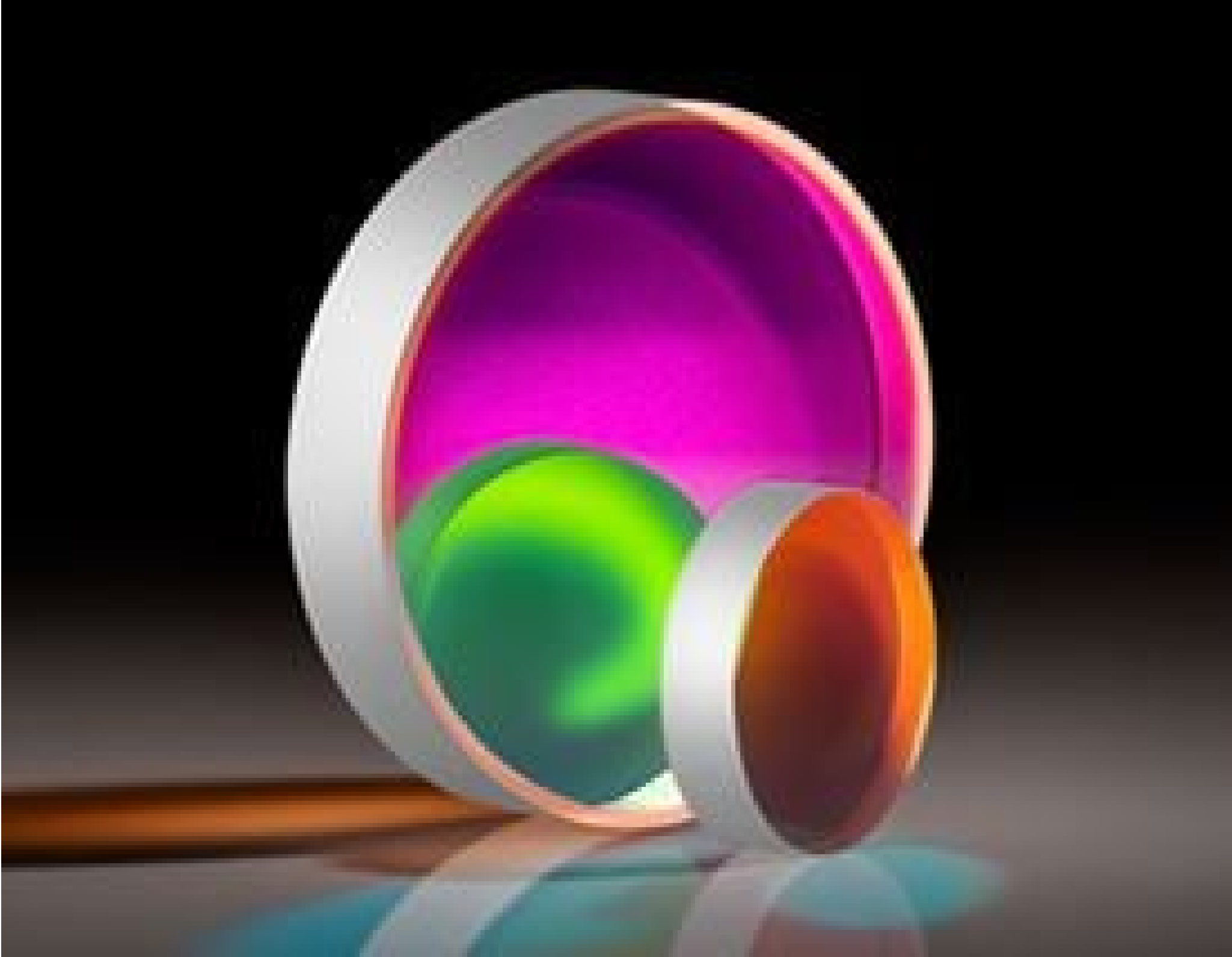

Stock #11-107 ☐ In Stock



1



€118,00

ADD TO CART

Qty 1-10

€118,00

Qty 11+

€105,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%) : 90
Durability : ML-C-675C
Back Surface : Commercial Polish
Reflection at DWL (%) : 99
Coating Specification : R _{abs} >99% @ 1030nm
Surface Flatness (P-V) : λ/10
Coating Type : Dielectric
Coating : Laser Mirror (1030nm)
Design Wavelength DWL (nm) : 1030
Diameter (mm) : 25.40 +0.0/-0.1
Thickness (mm) : 6.35 ±0.2
Angle of Incidence (°) : 0
Substrate : ☐ N-BK7
Damage Threshold, By Design : ☐ 5 J/cm ² @ 1030nm, 20ns, 20Hz

Regulatory Compliance

RoHS 2015 : Compliant
Reach 223 : Compliant
Certificate of Conformance : View