


25.4mm Dia. 1030nm 45°, Low Cost Laser Line Mirror

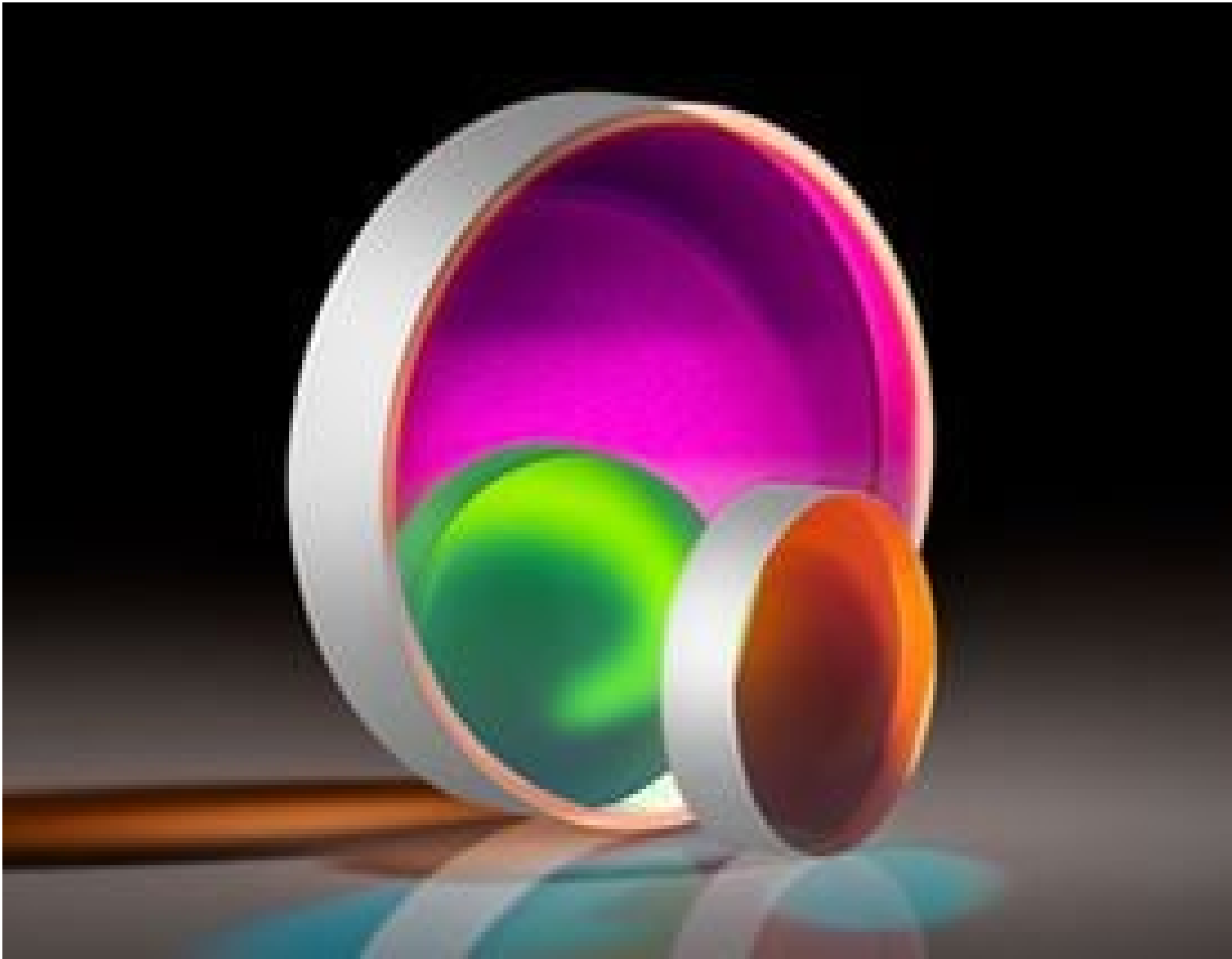

Stock #11-018 3-4 DAYS

⊖ 1 ⊕

€118,00

ADD TO CART

Qty 1-10
€118,00
Qty 11+
€105,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%): 90
Durability: ML-C-675C
Back Surface: Commercial Polish
Reflection at DWL (%): 99
Coating Specification: Rabs >99% @ 1030nm
Surface Flatness (P-V): λ/10
Coating Type: Dielectric
Coating: Laser Mirror (1030nm)
Design Wavelength DWL (nm): 1030
Diameter (mm): 25.40 +0.0/-0.1
Thickness (mm): 6.35 ±0.2
Angle of Incidence (°): 45
Substrate: N-BK7
Damage Threshold, By Design: 5 J/cm² @ 1030nm, 20ns, 20Hz

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View