


25.4mm Dia. 532nm 45°, Low Cost Laser Line Mirror

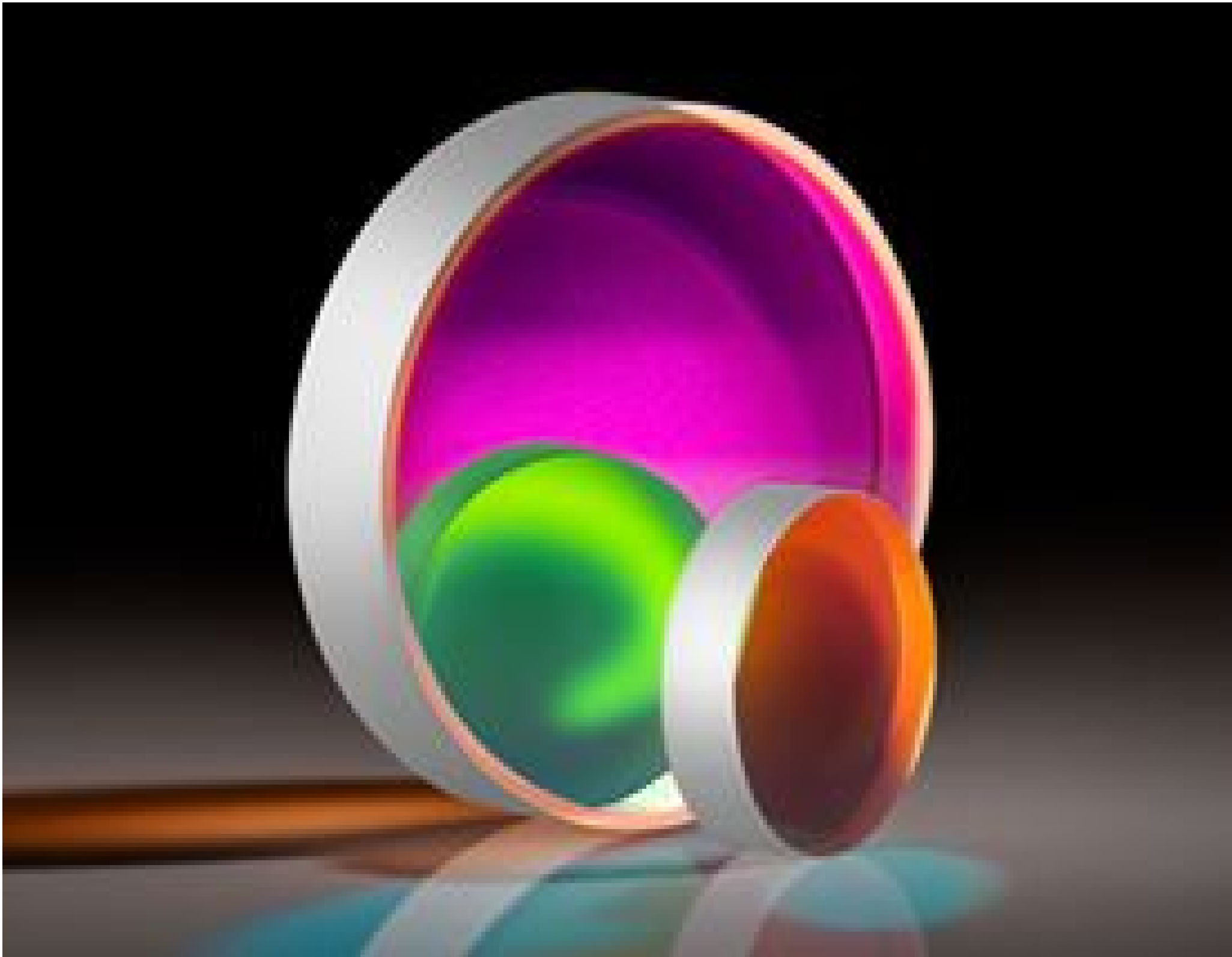

Stock #11-073 3-4 DAYS

⊖ 1 ⊕ **€118,00**

ADD TO CART

Qty 1-10
€118,00
Qty 11+
€105,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Parallelism (arcmin):
<3

Clear Aperture (%) 90
Durability: MIL-C-675C
Back Surface: Commercial Polish
Reflection at DWL (%) 99
Coating Specification: R_{abs} >99% @532nm
Surface Flatness (P-V): λ/10
Coating Type: Dielectric
Coating: Laser Mirror (532nm)
Design Wavelength DWL (nm): 532
Diameter (mm): 25.40 +0.0/-0.1
Thickness (mm): 6.35 ±0.2
Angle of Incidence (°): 45
Substrate: ☐ N-BK7
Damage Threshold, By Design: ☐ 3 J/cm² @532nm, 20ns, 20Hz

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View