


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 25.4mm Dia. UV, Precision Broadband Laser Mirror

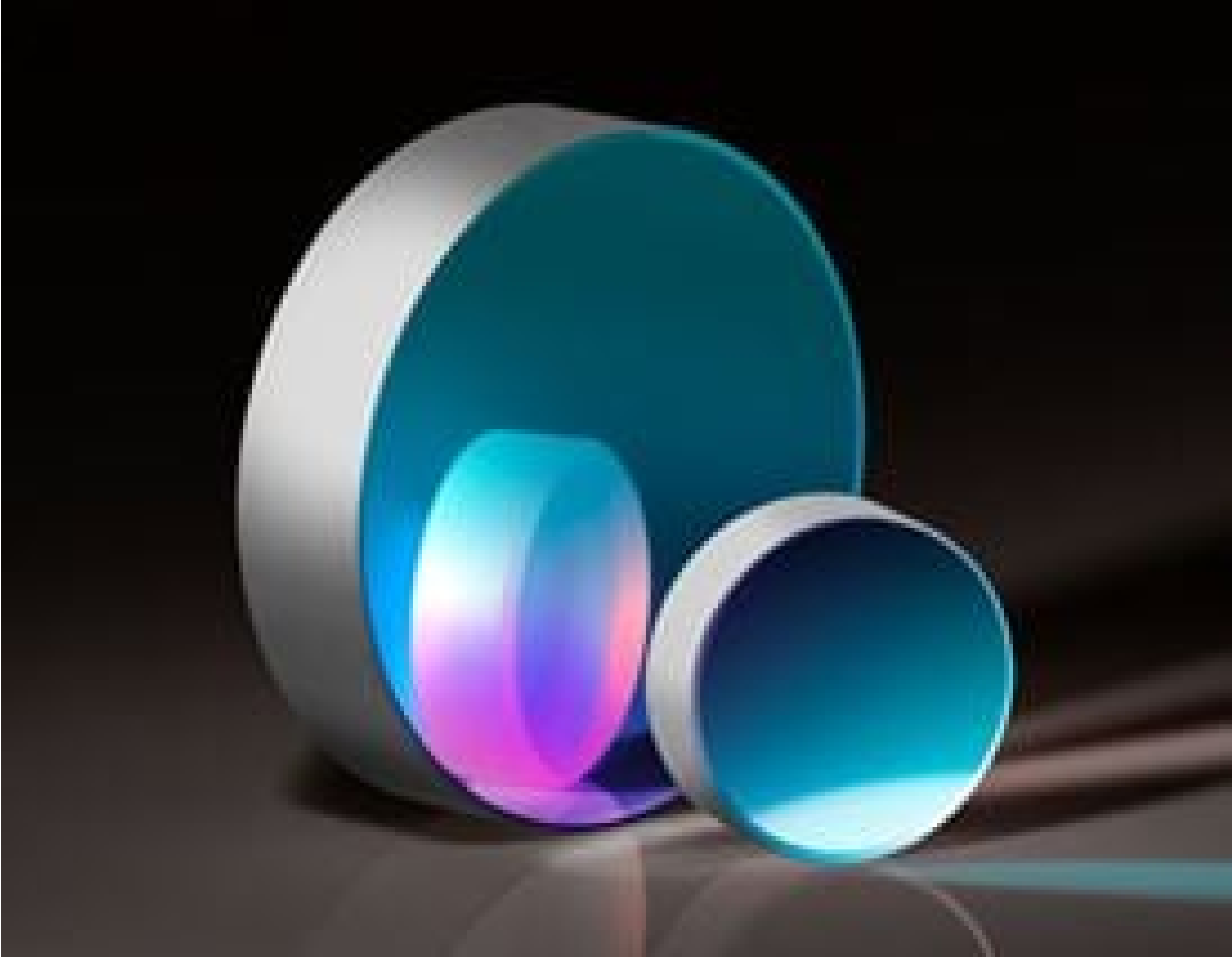

Stock #48-016 ☒ In Stock

-

1

+

 €156,00

ADD TO CART

Qty 1-5

€156,00

Qty 6+

€137,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Clear Aperture (%):
>80

Durability: ML-M-13508-C
Back Surface: Ground
Coating Specification: R_{avg} >99% @ 300 - 550nm
Wavelength Range (nm): 300 - 550
Surface Flatness (P-V): λ/10
Irregularity (P-V) @ 632.8nm: λ/20
Coating Type: Dielectric
Coating: Dielectric Mirror (300-550nm)
Diameter (mm): 25.40 +0.0/-0.2
Thickness (mm): 8.00 ±0.3
Angle of Incidence (°): 0-45
Substrate:  BOROFLOAT®
Note: Optical Power: λ/10
Damage Threshold, By Design:  0.3 J/cm² @ 10ns @ 355nm

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View