

In order to provide more accurate inventory information, please select your shipping country:


Select Your Country/Region: European Union



SUBMIT

25mm Dia. Metal Velvet™ Panel

See More by [Acktar](#)

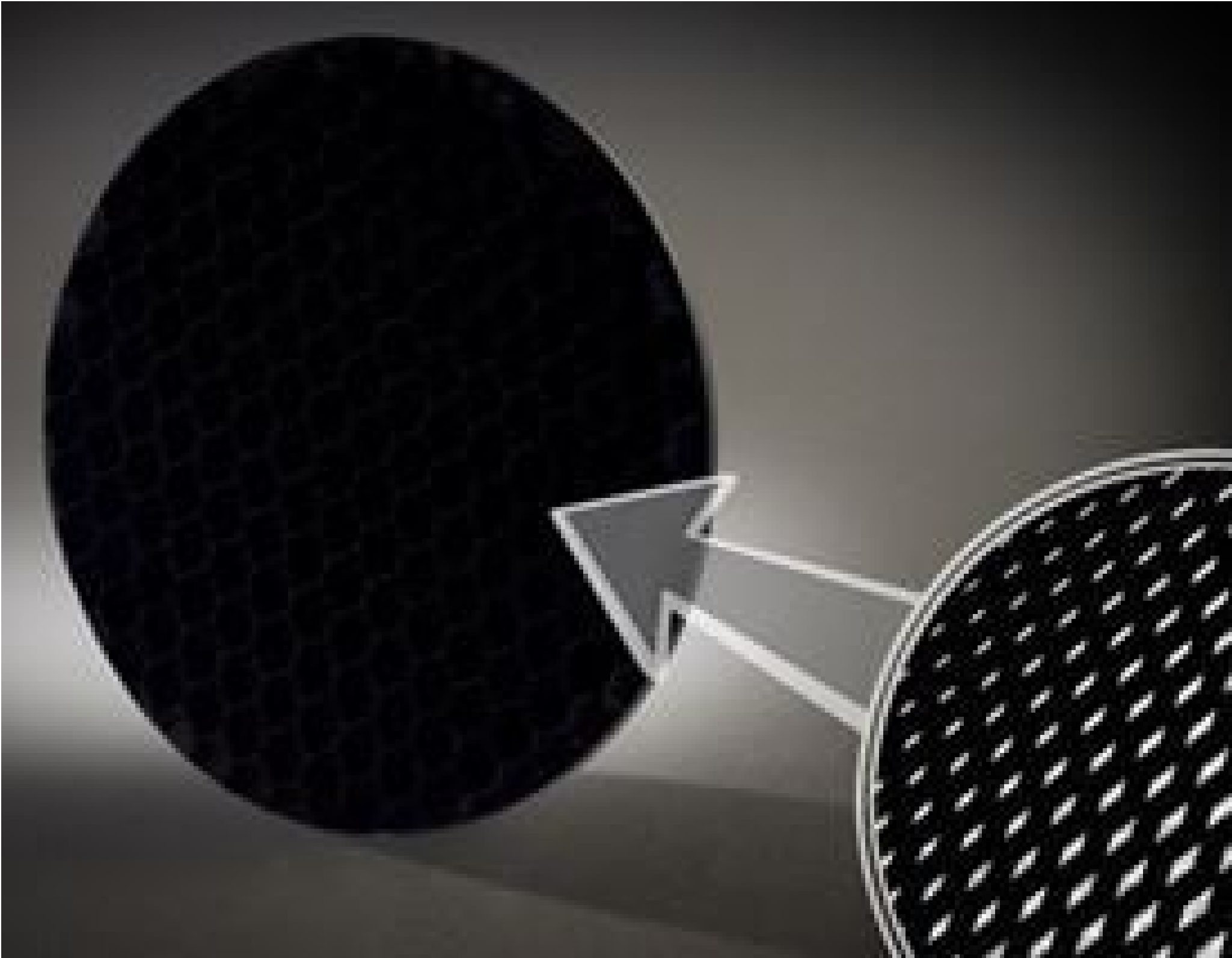

Acktar Hexa-Black™ Panel



Stock #37-832 3-4 DAYS



1



€53,50

ADD TO CART

Qty 1+

€53,50

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Metal Velvet™

Diameter (mm):
25.00

Model Number:

MMP-25-3
Operating Temperature (°C): -50 to 150
Abrasion Resistance: Light, do not touch
Absorbance (%): 99.5 - 99.7 (0 - 10° AOI)
Adhesive Thickness (µm): 60
Humidity Resistance: ML-C-48497A
Wavelength Range (µm): 0.3 - 14
Note: Ships with a low outgassing adhesive sticker that can be applied to the back surface
Thickness (mm): 1.20

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant