


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 25mm Dia. X 125mm FL VIS 0th Coated, UV Plano-Convex Lens

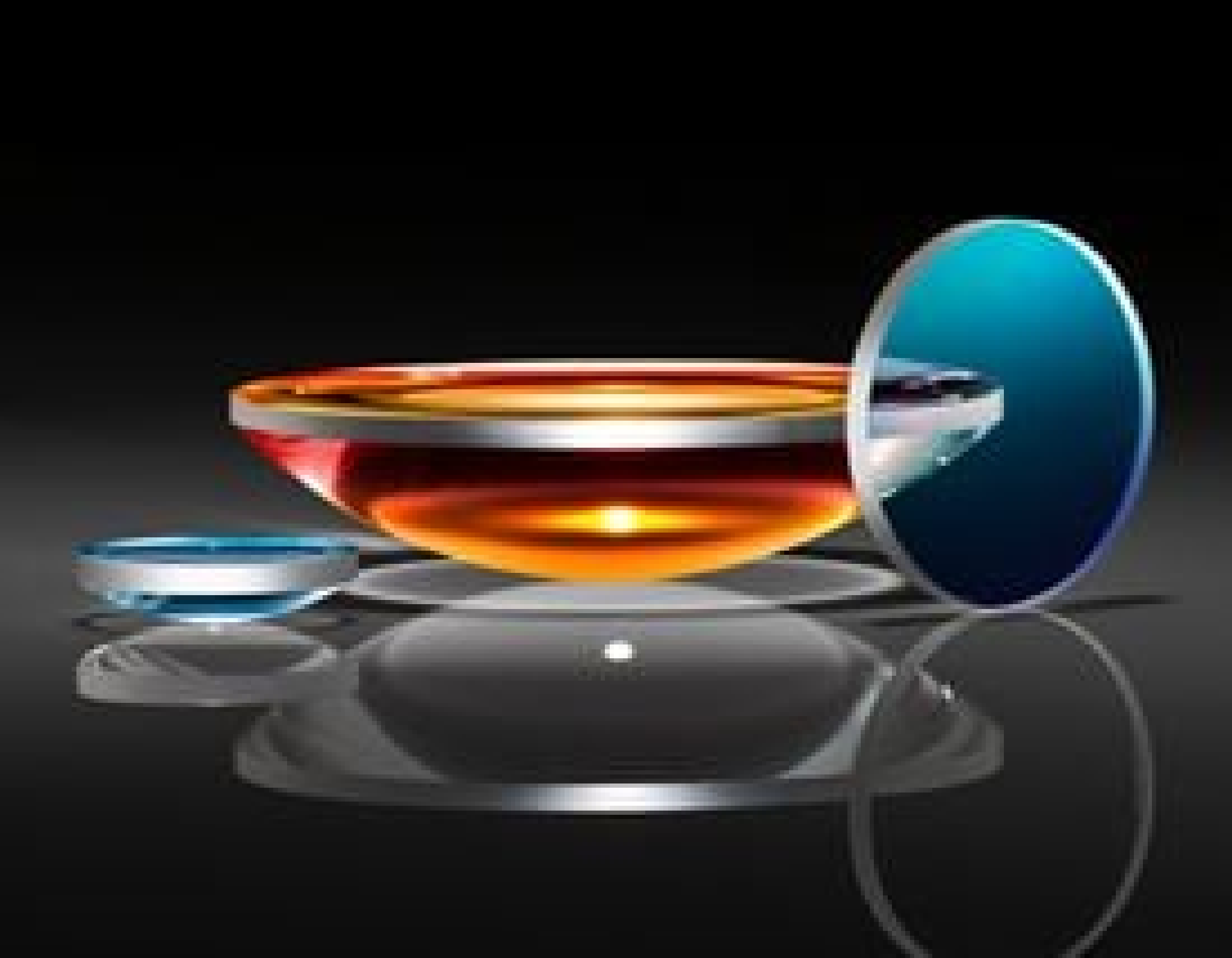

UV Fused Silica Plano-Convex (PCX) Lenses



Stock #48-966 3-4 DAYS

- 1 +

€145,00

ADD TO CART

Qty 1-5

€145,00

Qty 6+

€116,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.00 +0.0/-0.025

Effective Focal Length EFL (mm):

125.00 @587.6nm
Back Focal Length BFL (mm): 122.65
Coating: VS 0° (425-675nm)
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Substrate: Fused Silica (Coming 7980)
Surface Quality: 40-20
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Focal Length Tolerance (%): ±1
Centering (arcmin): <1
Center Thickness CT (mm): 3.42 ±0.10
Edge Thickness ET (mm): 2.04
Radius R₁ (mm): 57.30
Clear Aperture CA (mm): 24
f/#: 5
Numerical Aperture NA: 0.10
Type: Plano-Convex Lens
Bevel: Protective bevel as needed
Wavelength Range (nm): 425 - 675
Damage Threshold, Reference: 5 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant