


25mm Dia x 5mm Thickness Uncoated, Potassium Bromide Window

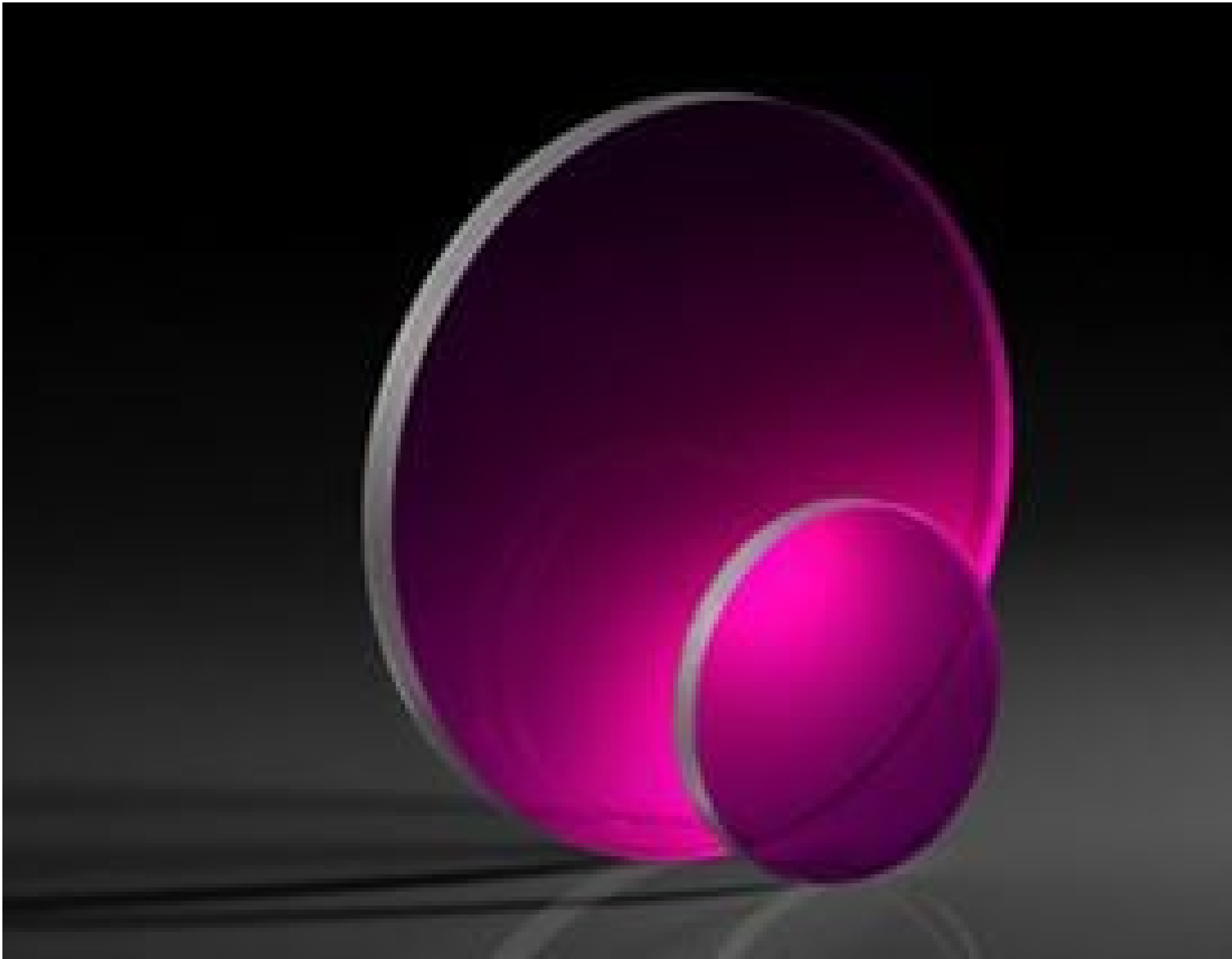

Stock **#68-809** 3-4 DAYS

- 1 + **€91,00**

ADD TO CART

Qty 1-10
€91,00
Qty 11+
€82,00
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):
33.64

Bevel:
Protective as needed

Diameter (mm):
25.00 ±0.50

Thickness (mm): 5.00 ±0.50
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 43
Density (g/cm³): 2.753
Edges: Fine Ground
Index of Refraction n_d: 1.56
Knoop Hardness (kg/mm²): 7
Poisson's Ratio: 0.203
Solubility, in 100g of H₂O @ 273K (g): 53.48
Substrate: Potassium Bromide (KBr)
Surface Quality: 60-40
Type: Protective Window
Wavelength Range (nm): 250 - 26000
Young's Modulus (GPa): 26.8

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View