


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 25mm Diameter Uncoated, Zinc Sulfide Multispectral Window

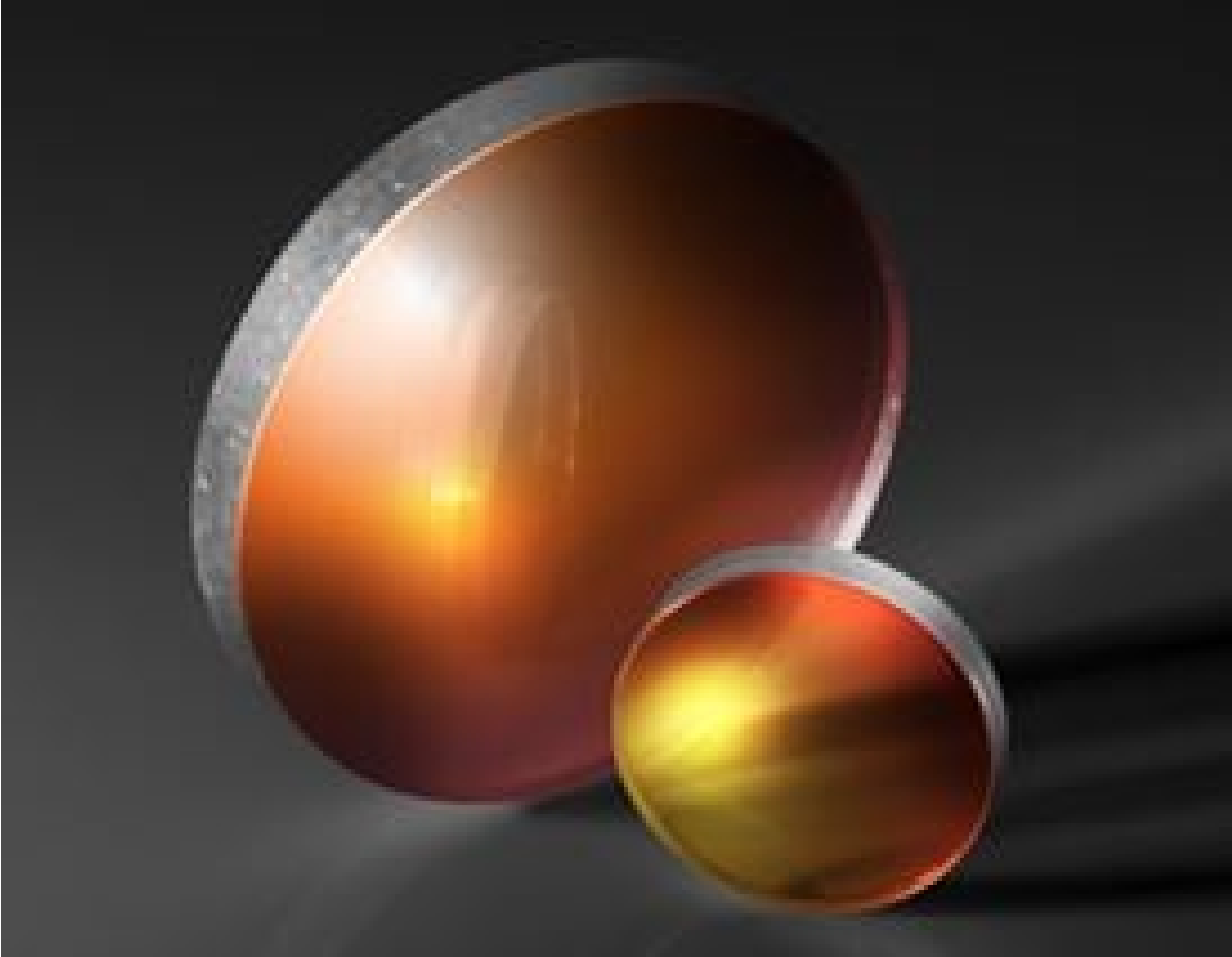

TECHSPEC® Zinc Sulfide Multispectral Windows

Stock #66-201 □ In Stock



1



€280,00

ADD TO CART

Qty 1-10

€280,00

Qty 11+

€252,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Bevel:
Protective as needed

Clear Aperture (%):
90.00

Clear Aperture CA (mm):

22.50
Diameter (mm): 25.00 +0.0/-0.1
Thickness (mm): 3.00 ±0.1
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 6.8
Density (g/cm³): 4.08
Edges: Fine Ground
Index of Refraction n_d: 2.371
Knoop Hardness (kg/mm²): 210
Parallelism (arcmin): <1
Poisson's Ratio: 0.27
Substrate: Zinc Sulfide Multispectral
Surface Flatness (P-V): λ/10 @ 10.6μm
Surface Quality: 60-40
Type: Protective Window
Wavelength Range (nm): 400 - 12000
Young's Modulus (GPa): 74.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View