


TECHSPEC® 2mm Aperture x 50mm L Standard NA, Fused Silica Light Pipe

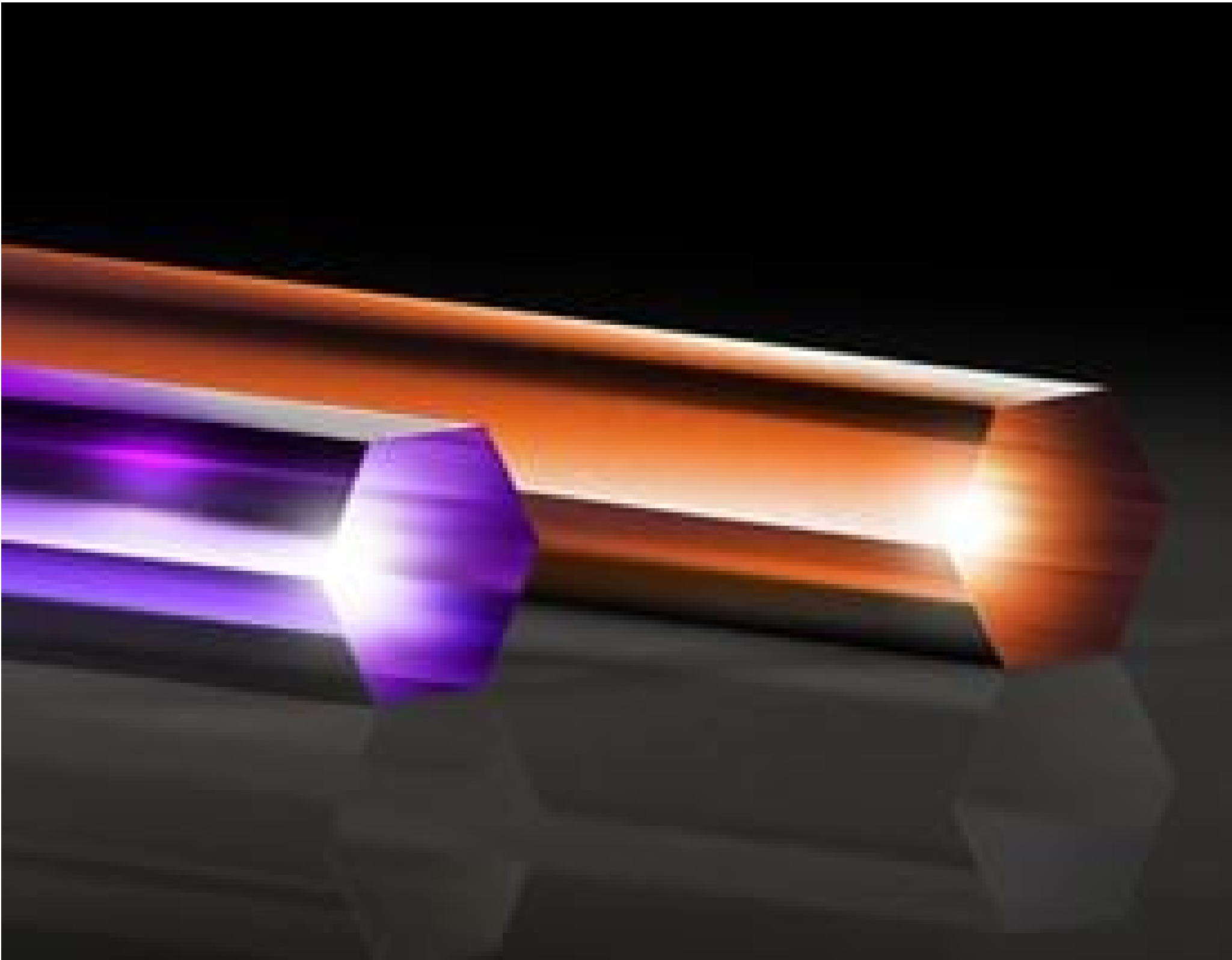

Fused Silica Light Pipe Homogenizing Rods



Stock **#65-828** 3-4 DAYS

⊖ 1 ⊕

€200,00

ADD TO CART

Qty 1-5
€200,00
Qty 6+
€160,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Uncoated

Substrate:

[Fused Silica](#) (Corning 7980)

Length (mm): 50.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 2.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Standard
Wavelength Range (nm): 200 - 2200
Surface Flatness (P-V): 1λ
#Sorting: 4.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View