


300 Grooves, 25mm Square, 1000nm NIR Ruled Grating

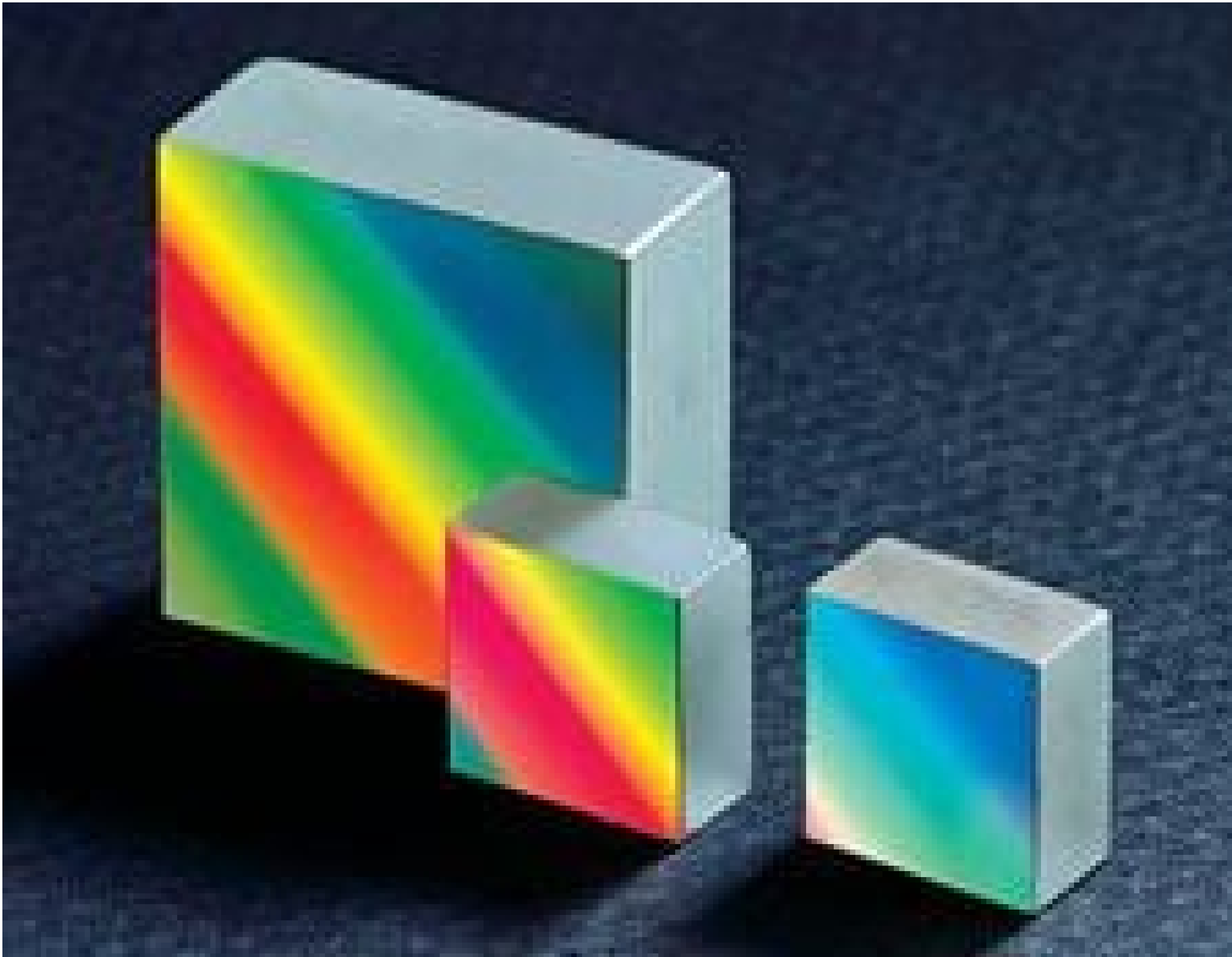

Stock **#49-572** ☐ In Stock

⊖ 1 ⊕ **€160,00**

ADD TO CART

Qty 1+
€160,00

Volume Pricing
Request Quote

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm): 300
Wavelength Range (nm): 700 - 3000
Blaze Wavelength (nm): 1000
Blaze Angle (°): 8.60

Dimensions (mm): 25.0 x 25.0 ±0.5
Clear Aperture (%) : 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 25.00
Substrate: ☐ Float Glass
Thickness (mm): 9.50 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 25.00
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View