


TECHSPEC® 35mm Square 45°, Blue Dichroic Filter

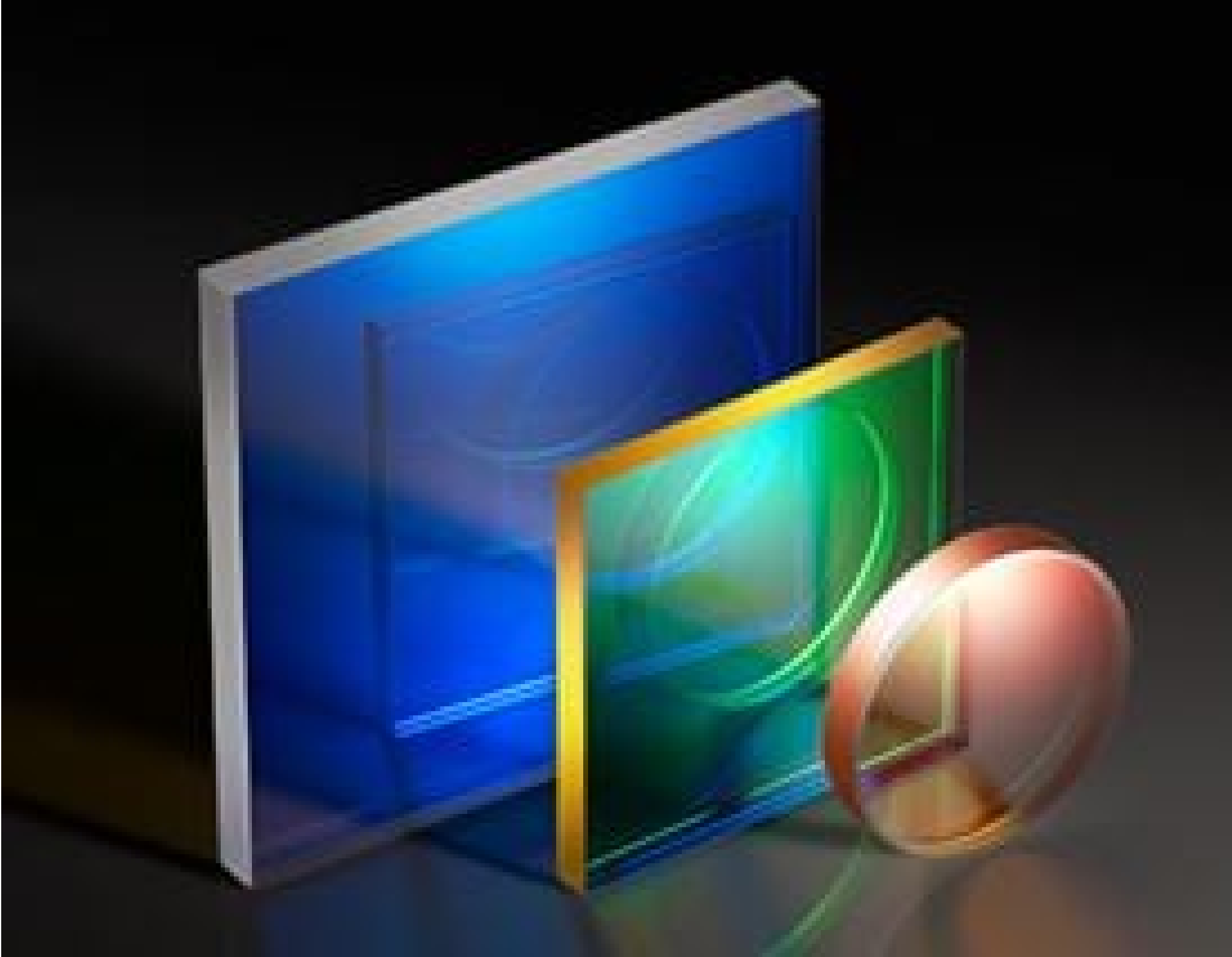

Stock **#49-472** 3-4 DAYS

⊖ 1 ⊕ **€110,00**

ADD TO CART

Qty 1-10
€110,00

Qty 11+
€93,50

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
35.0 x 35.0

Angle of Incidence (°):
45.00

Cut-Off Wavelength (nm):
510.00

Substrate: N-BK7
Length (mm): 35.00
Coating: Traditional Coated
Color: Blue
Reflection (%): R_{abs} = 50% @ 510nm R_{avg} > 98% @ 400 - 475nm
Reflection Wavelength (nm): 400 - 475
Surface Quality: 60-40
Thickness (mm): 3.00
Thickness Tolerance (mm): ±0.20
Transmission (%): 90.00
Transmission Wavelength (nm): 530 - 800
Type: Dichroic Filter
Width (mm): 35.00
Wavelength Tolerance (nm): ±15
Parallelism (arcmin): <1
Dimensional Tolerance (mm): ±0.25
Clear Aperture (%): 90.00
Coating Specification: Surface 1: Multi-Layer Dichroic Surface 2: Single Layer MgF₂
Wavelength Range (nm): 400 - 800
Surface Flatness (P-V): λ/4

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant