


3" Diameter, Plastic Optical Windows

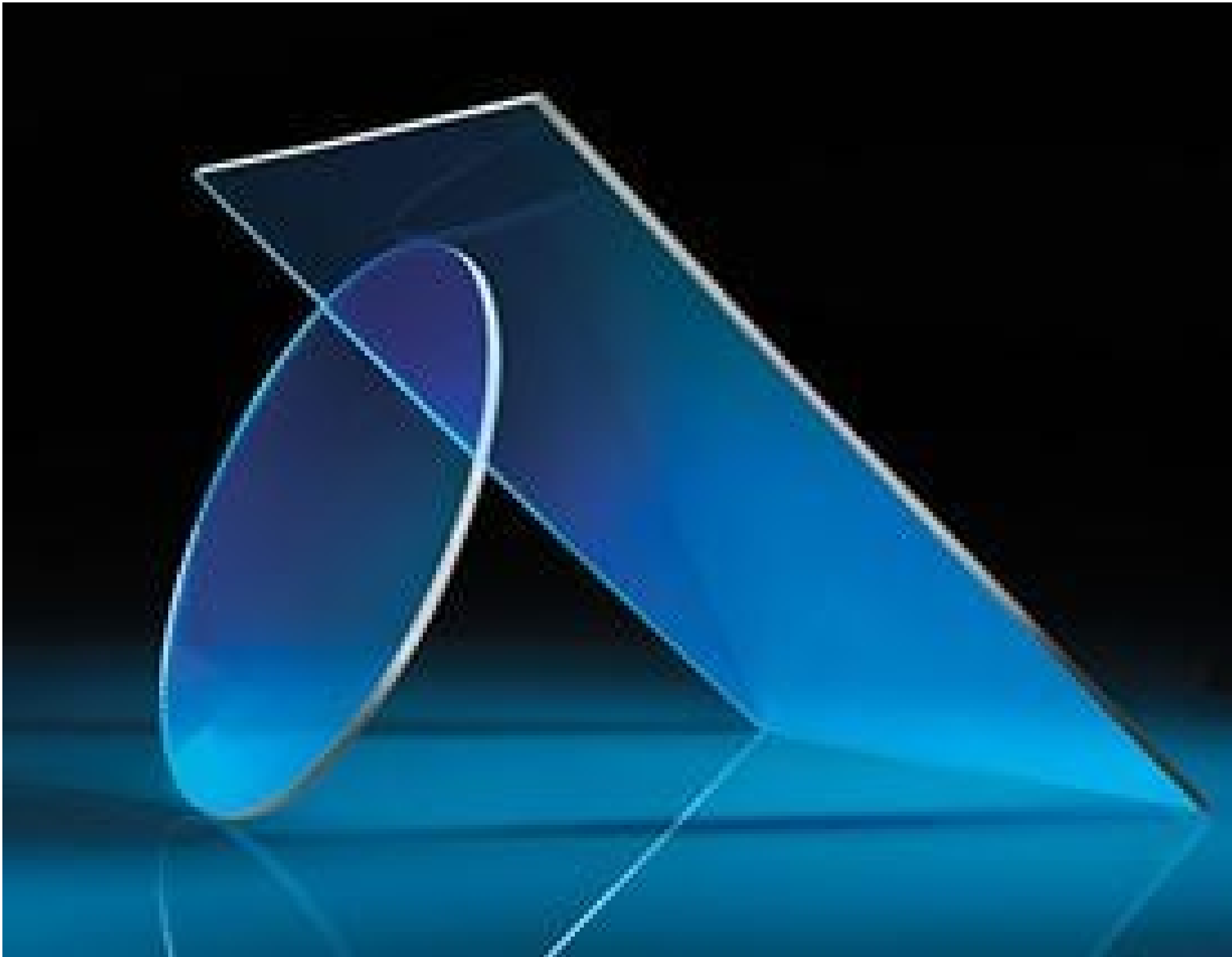

Stock **#43-925** 3-4 DAYS

⊖ 1 ⊕ **€32,50**

ADD TO CART

Qty 1-49
€32,50
Qty 50+
€26,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):
57.00

Diameter (mm):
76.20 ±0.3

Diameter (inches):
3.0

Thickness (mm): 1.50 ±0.15
Coating: Uncoated
Density (g/cm³): 1.320
Index of Refraction n_d: 1.501
Operating Temperature (°C): 100 Continuous, 130 for 1 hour
Substrate: Thermoset ADC (CR-39®)
Transmission (%): >90 (typical)
Type: Protective Window
Wavelength Range (nm): 400 - 1500

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View