


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 40mm, Center Drive, Thru-Hole, Metric Extended Micrometer

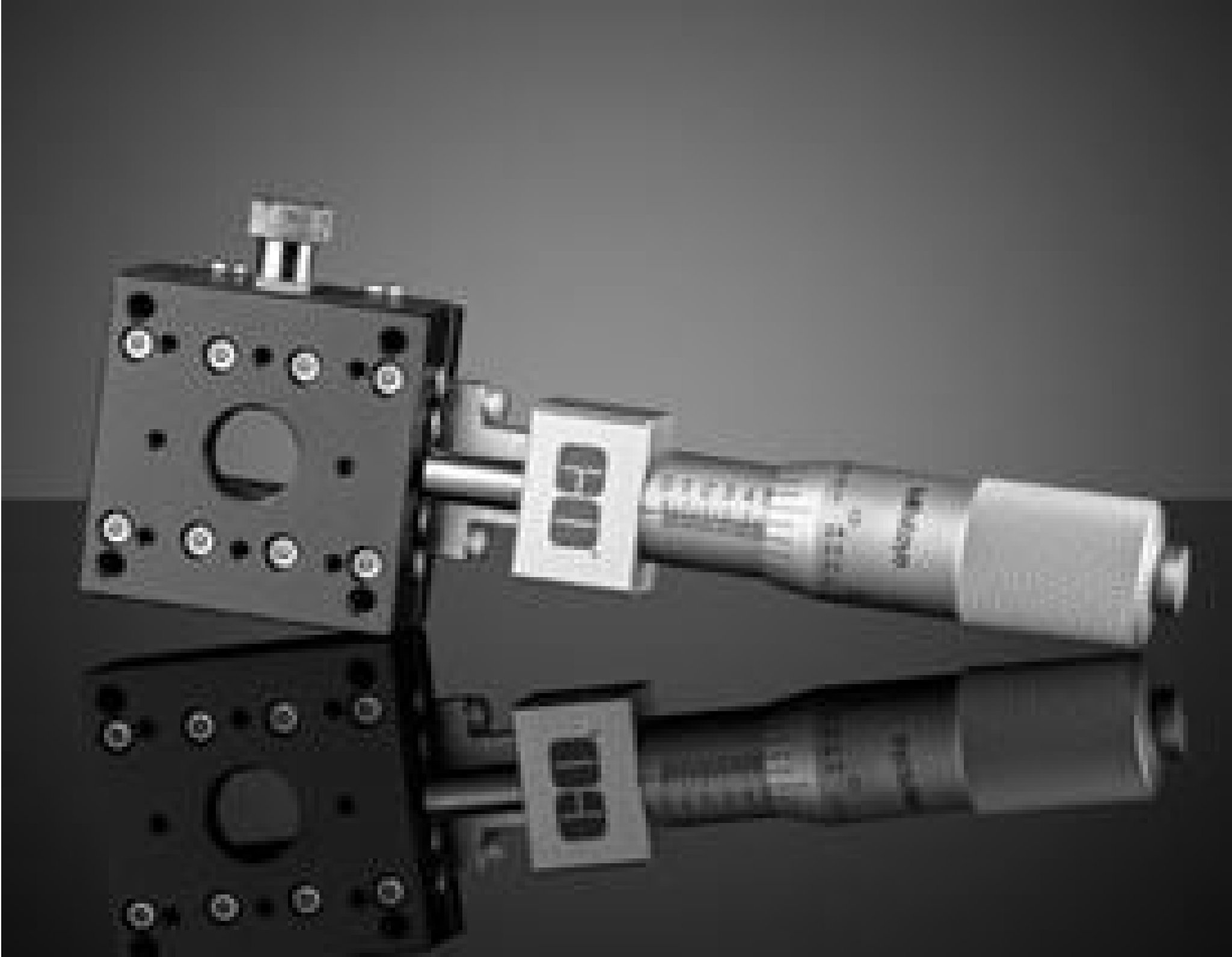

40mm, S-Mount (M12 x 0.5) Thread Centered, Micrometer Drive Stage (Center Drive)

Stock #66-422 3-4 DAYS



1



€416,00

ADD TO CART

Qty 1-2

€416,00

Qty 3+

€362,70

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
Metric Micrometer

Drive Orientation: Center Drive
Type: Metric
Stage Size (mm): 40 x 40
Travel (mm): 25
Center Hole: M12 x 0.5
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.5
Load Capacity (kg): 4
Mounting Threads: (1) M12 x 0.5, (4) M3 x 0.5, (8) M2 x 0.4
Stage Size (inches): 1.57 x 1.57
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)