


TECHSPEC® 40mm, Center Drive, Thru-Hole, Metric, Micrometer Stage

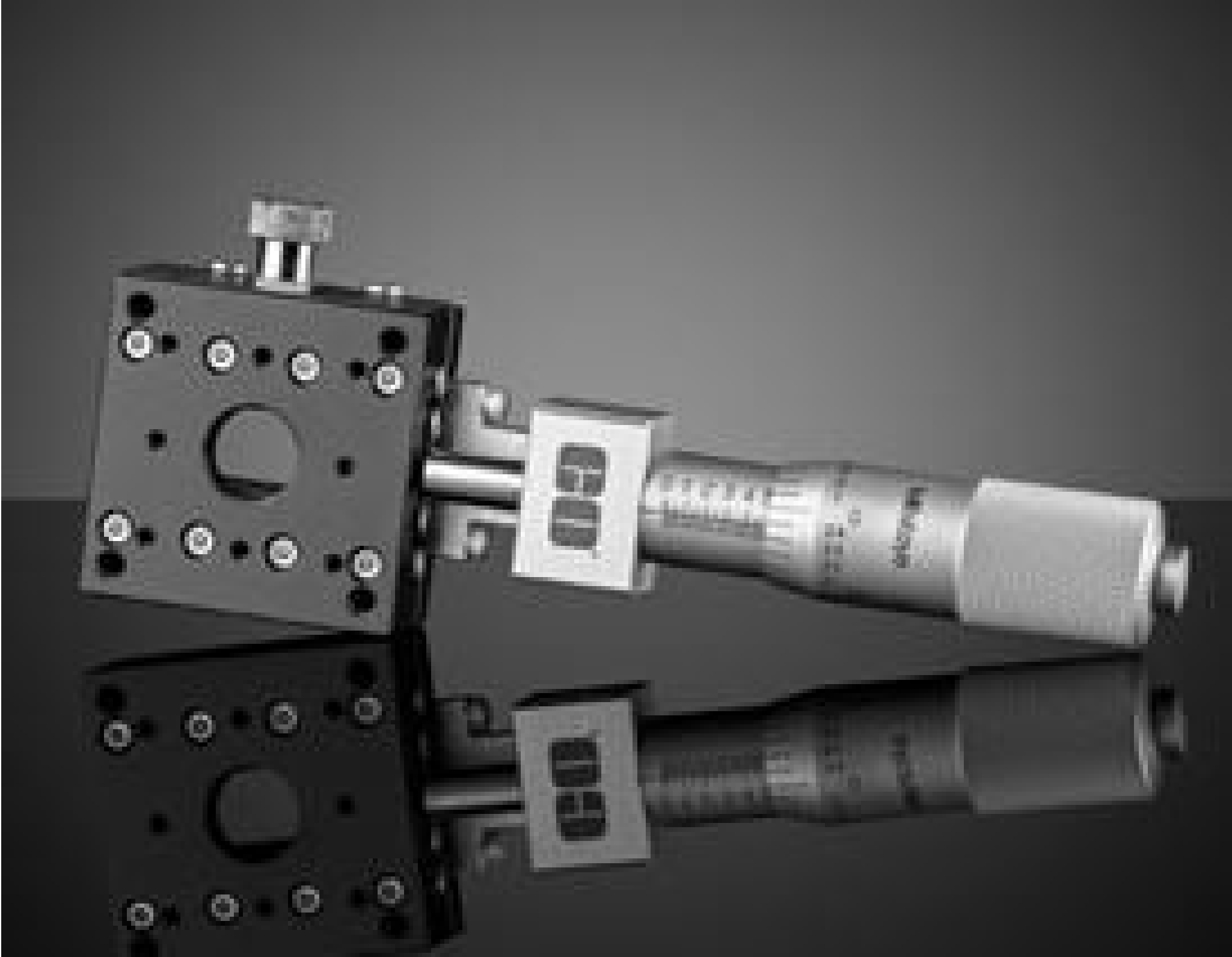

40mm, S-Mount (M12 x 0.5) Thread Centered, Micrometer Drive Stage (Center Drive)

Stock #66-421 3-4 DAYS



1



€392,00

ADD TO CART

Qty 1-2

€392,00

Qty 3+

€342,30

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
Metric Micrometer

Drive Orientation: Center Drive
Type: Metric
Stage Size (mm): 40 x 40
Travel (mm): 13
Center Hole: M12 x 0.5
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.5
Load Capacity (kg): 4
Mounting Threads: (1) M12 x 0.5, (4) M3 x 0.5, (8) M2 x 0.4
Stage Size (inches): 1.57 x 1.57
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)