


40mm Travel, Thick Base X-Y Axis Movement

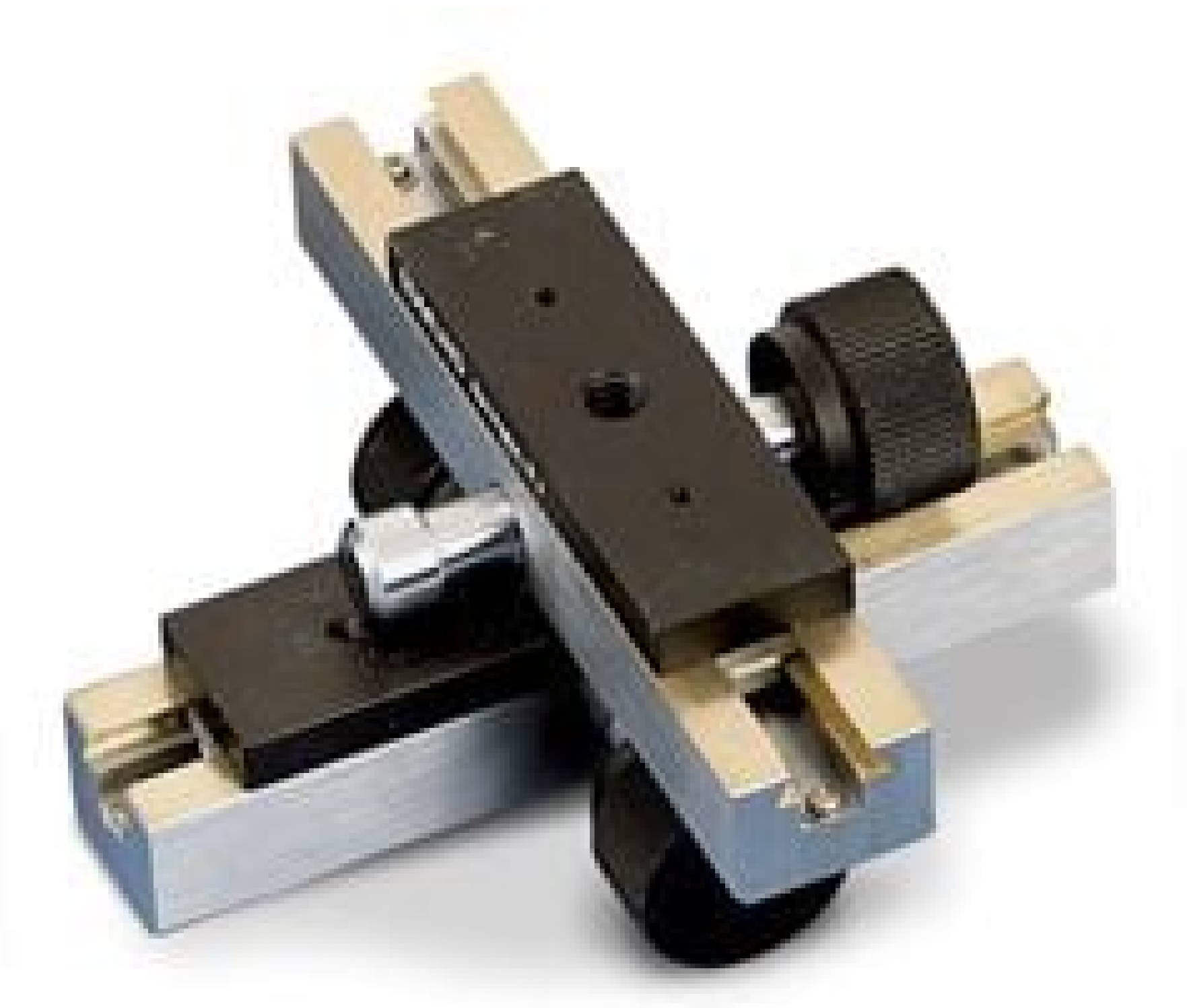

#03-683

Stock #03-683 3-4 DAYS



1



€418,00

ADD TO CART

Qty 1-9

€418,00

Qty 10+

€369,40

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X-Y)

Guide System:
Dovetail

Type of Drive:
Rack and Pinion

Type: English
Stage Size (mm): 20 x 100
Travel (mm): 40 (±20)
Load Capacity (kg): 3.5 Horizontal, 2.1 Vertical
Mounting Threads: Stage: (1) ¼-20 Base: (2) ¼-20
Note: Not Lockable
Straight Line Accuracy (µm): 50
Travel Per Knob Rotation (mm): 15
Weight (g): 500
Table Size (mm): 20 x 60

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Contains SVHC(s)
Certificate of Conformance: View