
 


50 x 50mm, 1λ Retarder Film (WP560)

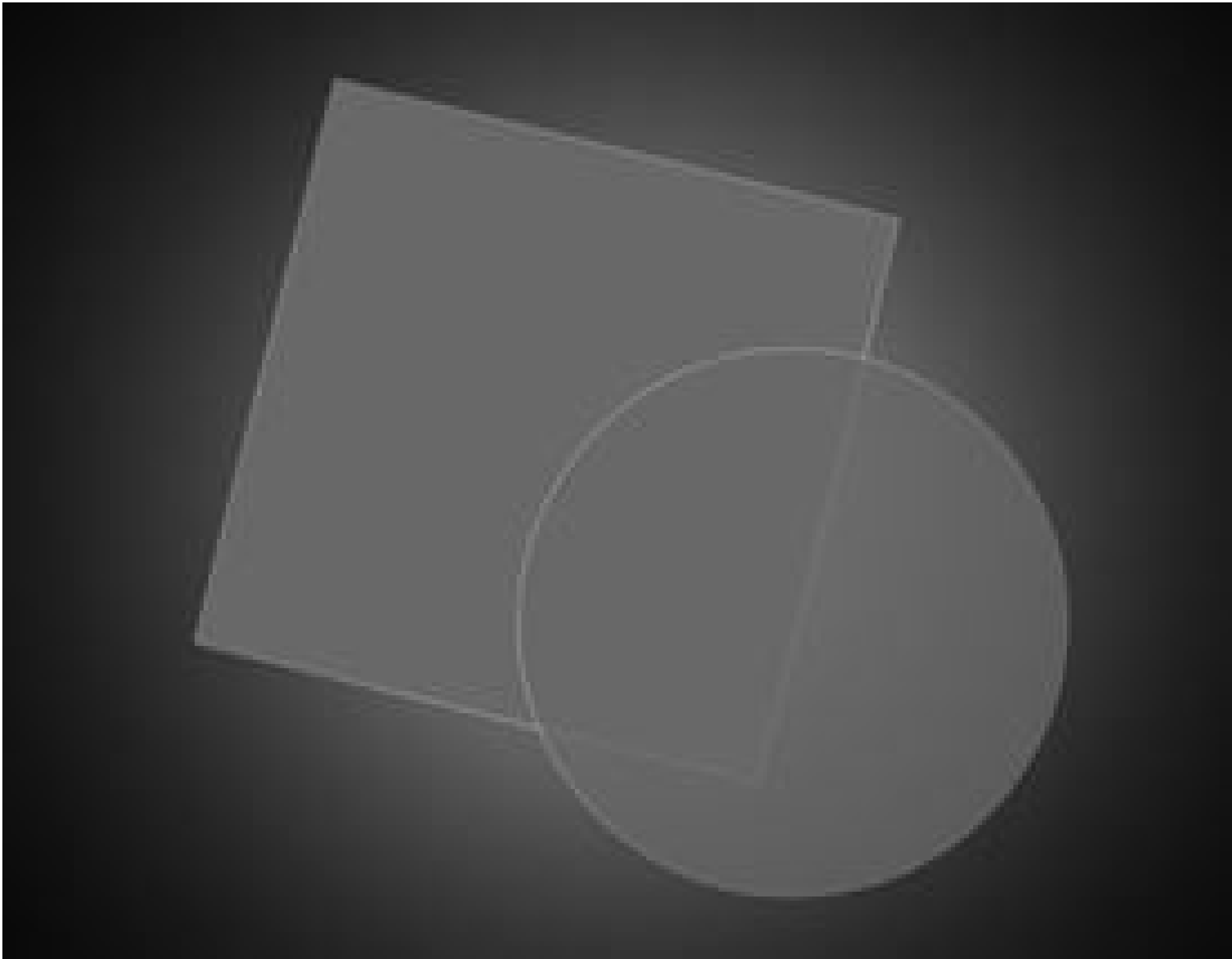

Retarder Film with protective film removed



Stock **#88-257** 3-4 DAYS

− 1 +

€23,00

ADD TO CART

Qty 1-10
€23,00
Qty 11+
€21,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Design Wavelength DWL (nm):
560

Substrate: [Polymer Film WP560](#)

Length (mm): 50.00
Operating Temperature (°C): -20 to +50
Retardance: 1λ
Dimensions (mm): 50.0 x 50.0
Thickness (mm): 0.15 ±0.015
Transmission (%): >89
Type: Retarder Film
Dimensional Tolerance (mm): +0.0/-0.5
Construction: Polarizing Film
Phase Shift (°): 360.00
Haze (%): <1
Note: Fast axis is indicated by a black stripe on the protective film. This film should be removed before use.
Wavelength Range (nm): 400 - 700
Heat Resistance (°C x Hours): 80 x 1000
Width (mm): 50.00
Retardation (nm): 560 ±10

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant