


50 x 50mm Laser Diode Mirror

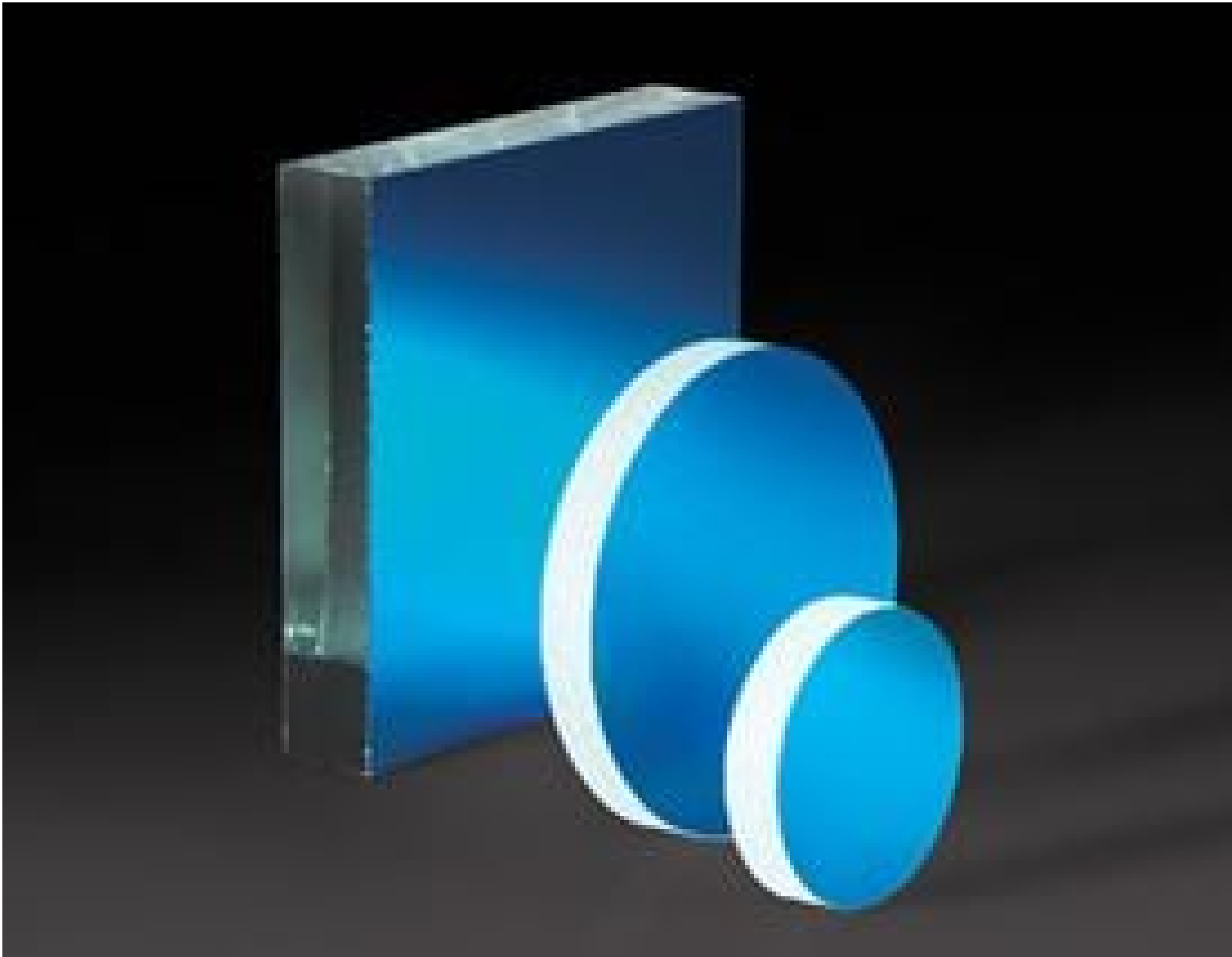

Stock **#43-533** 3-4 DAYS

- 1 + **€36,50**

ADD TO CART

Qty 1-10
€36,50

Qty 11+
€29,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate: ☐ Float Glass

Surface Quality:
80-50

Dimensions (mm):
50.0 x 50.0

Dimensional Tolerance (mm):

±0.25
Coating Specification: R _{abs} >97% @ 633nm
Coating: Dielectric Mirror (500-700nm)
Coating Type: Dielectric
Design Wavelength DWL (nm): 633
Durability: ML-C-48497A
Thickness (mm): 3.00
Type: Flat Mirror
Length (mm): 50.00
Width (mm): 50.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant