


TECHSPEC® 5mm Uncoated Dove Prism

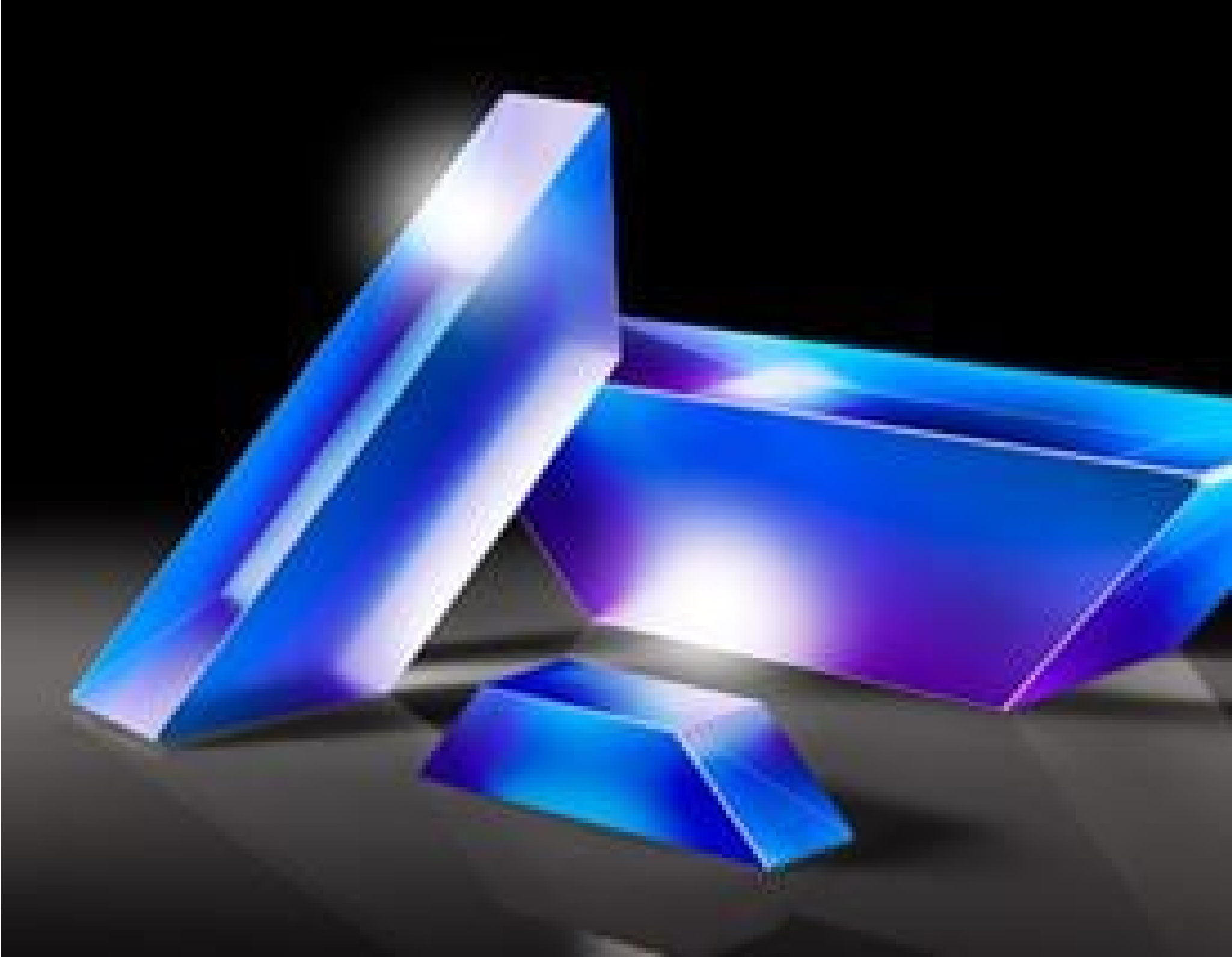

Stock **#32-998** ☐ In Stock

1 **€131,00**

ADD TO CART

Qty 1-5
€131,00
Qty 6+
€117,90
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Uncoated

Substrate: ☐

[N-BK7](#)

Height (mm):

5.0

Length (mm): 20.64
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2.00
Bevel: Protective bevel as needed
Image Orientation: Left-Handed
Ray Deviation (°): 0
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View