


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

64 X 97mm Laser Diode Mirror

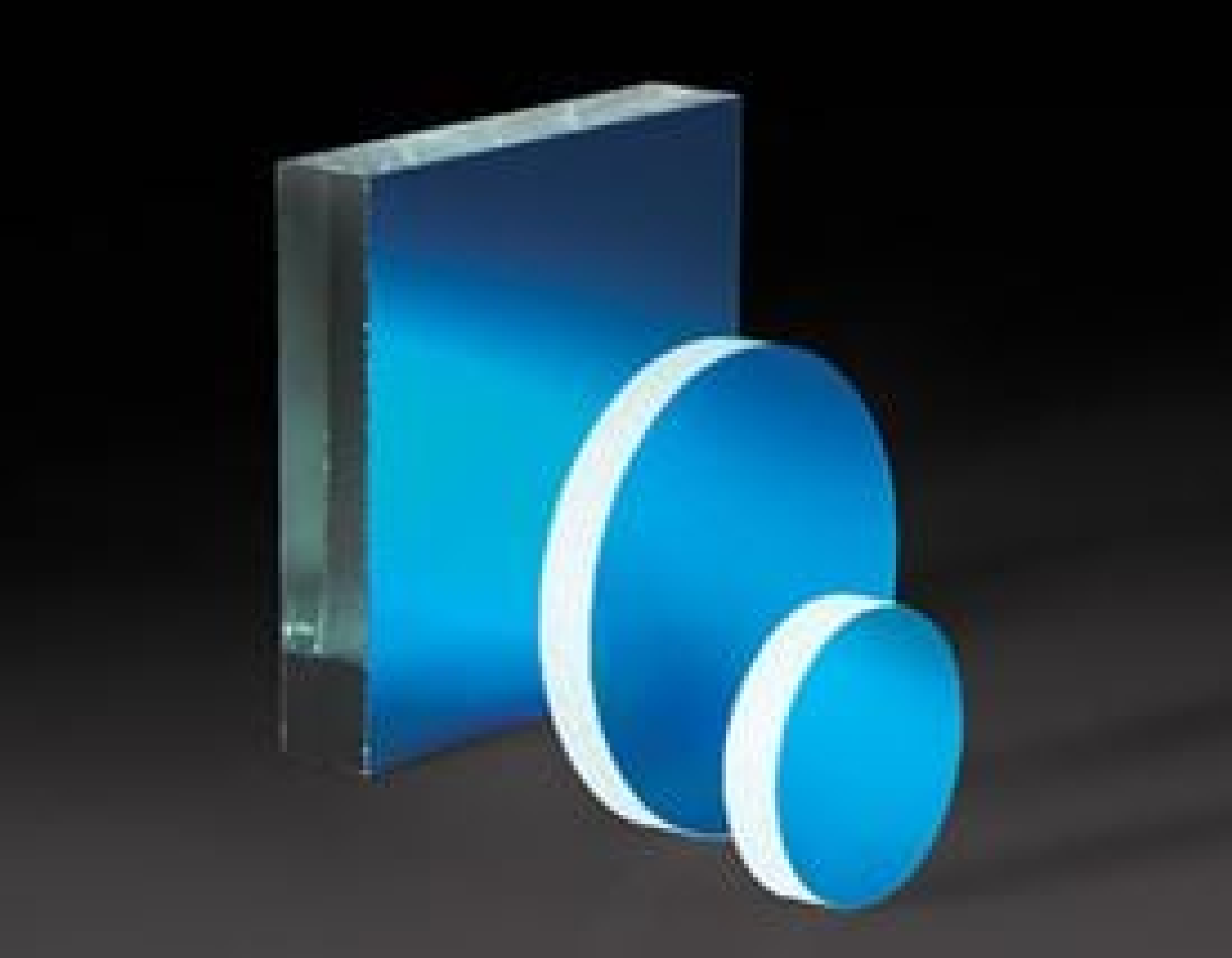

Stock #31-497 3-4 DAYS

- 1 + €45,50

ADD TO CART

Qty 1-10
€45,50

Qty 11+
€36,00

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate: ☐ Float Glass

Surface Quality: 80-50

Dimensions (mm): 64.0 x 97.0

Dimensional Tolerance (mm):

±0.25
Coating Specification: R _{abs} >97% @ 633nm
Coating: Dielectric Mirror (500-700nm)
Coating Type: Dielectric
Design Wavelength DWL (nm): 633
Durability: ML-C-48497A
Thickness (mm): 6.35
Type: Flat Mirror
Length (mm): 97.00
Width (mm): 64.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant