


70 Grooves/mm, 25mm Sq, Transmission Grating Beamsplitter

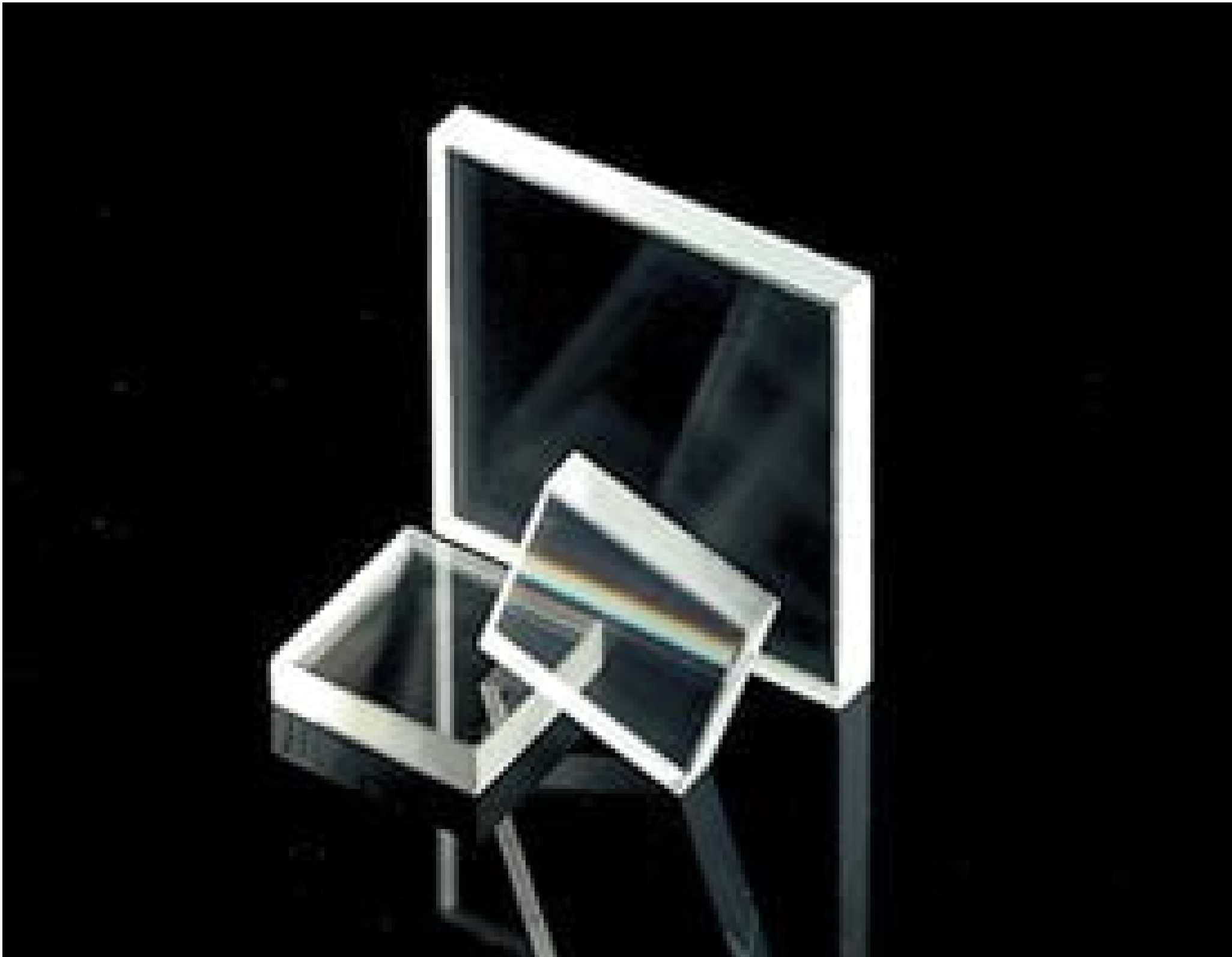

Stock **#46-068** 3-4 DAYS

- 1 + **€262,00**

ADD TO CART

Qty 1-10
€262,00

Qty 11+
€236,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
70

Design Wavelength DWL (nm):
632.8

Dimensions (mm):
25.0 x 25.0 ±0.5

Construction: Blazed Grating
Length (mm): 25.00
Substrate: ☐ E270
Thickness (mm): 3.00 ±0.5
Type: Transmission Diffraction Grating
Width (mm): 25.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
