


750μm, Optical Grade Plastic Optical Fiber Unjacketed

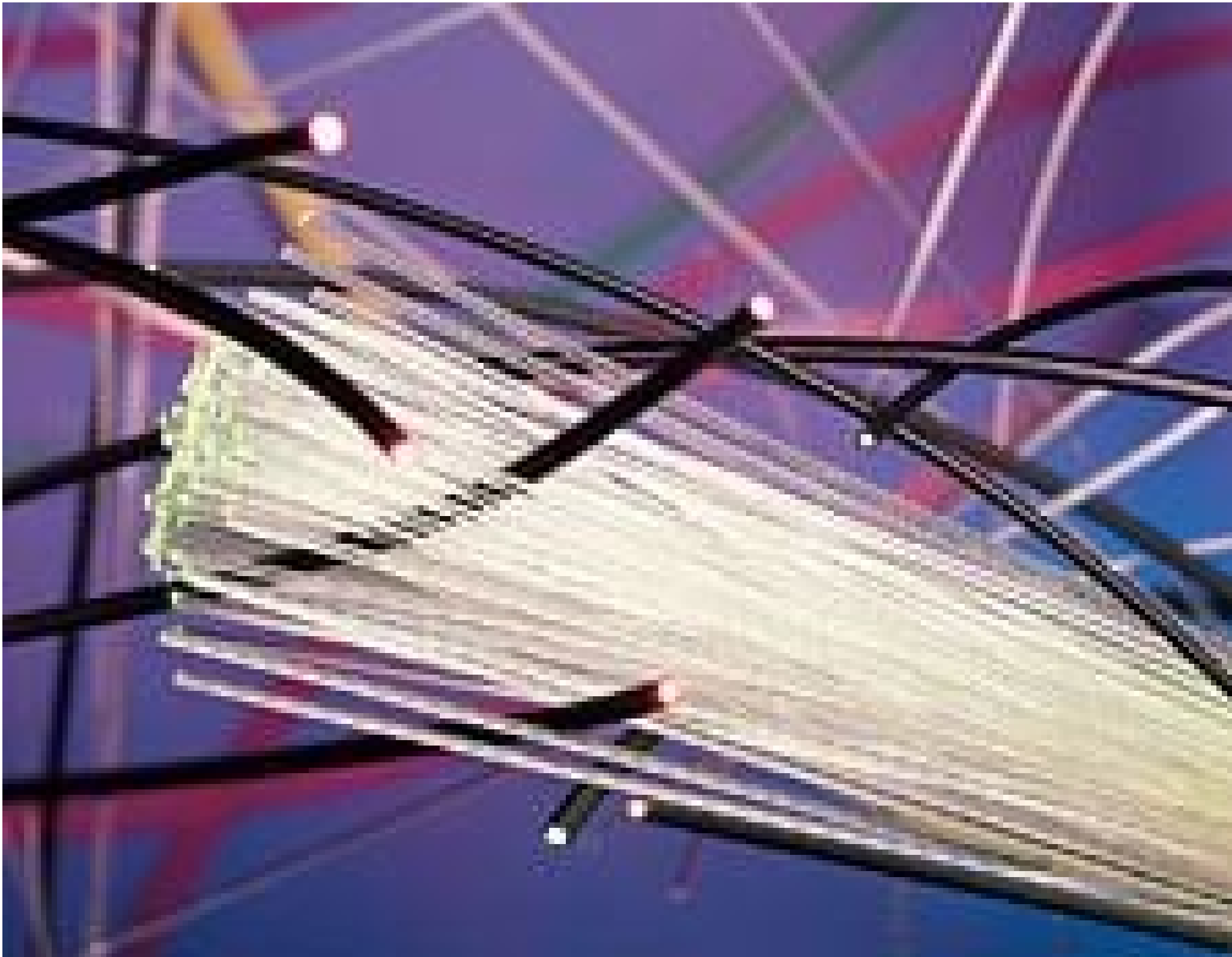

Stock #02-533 3-4 DAYS

- 1 + **€1,60**

ADD TO CART

Qty 1+
€1,60

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Acceptance Angle (°):
61.00

Minimum Bend Radius (mm):
18.75

Substrate: ☐
Acrylic

Attenuation (dB/m):
0.15

Numerical Aperture NA:
0.51

Number of Fibers: 1.00
Operating Temperature (°C): -55 to +70
Outer Diameter (mm): 0.75
Core Diameter (µm): 735.00
Fiber Diameter (µm): 750.00
Length (ft): Cut to Order, Minimum 10
Construction: Unjacketed
Index of Refraction n_d - Core: 1.492
Index of Refraction n_d - Cladding: 1.402
Attenuation (dB/km): 150 - 300 (@ 650nm)
Note: Minimum Purchase is 10ft or Qty = 10 per Stock No.
Numerical Aperture (NA) Tolerance: ±0.03
Diameter Tolerance (%): ±6

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View