


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

850nm, 25.4mm Dia., Colored Glass Replacement Longpass Filter

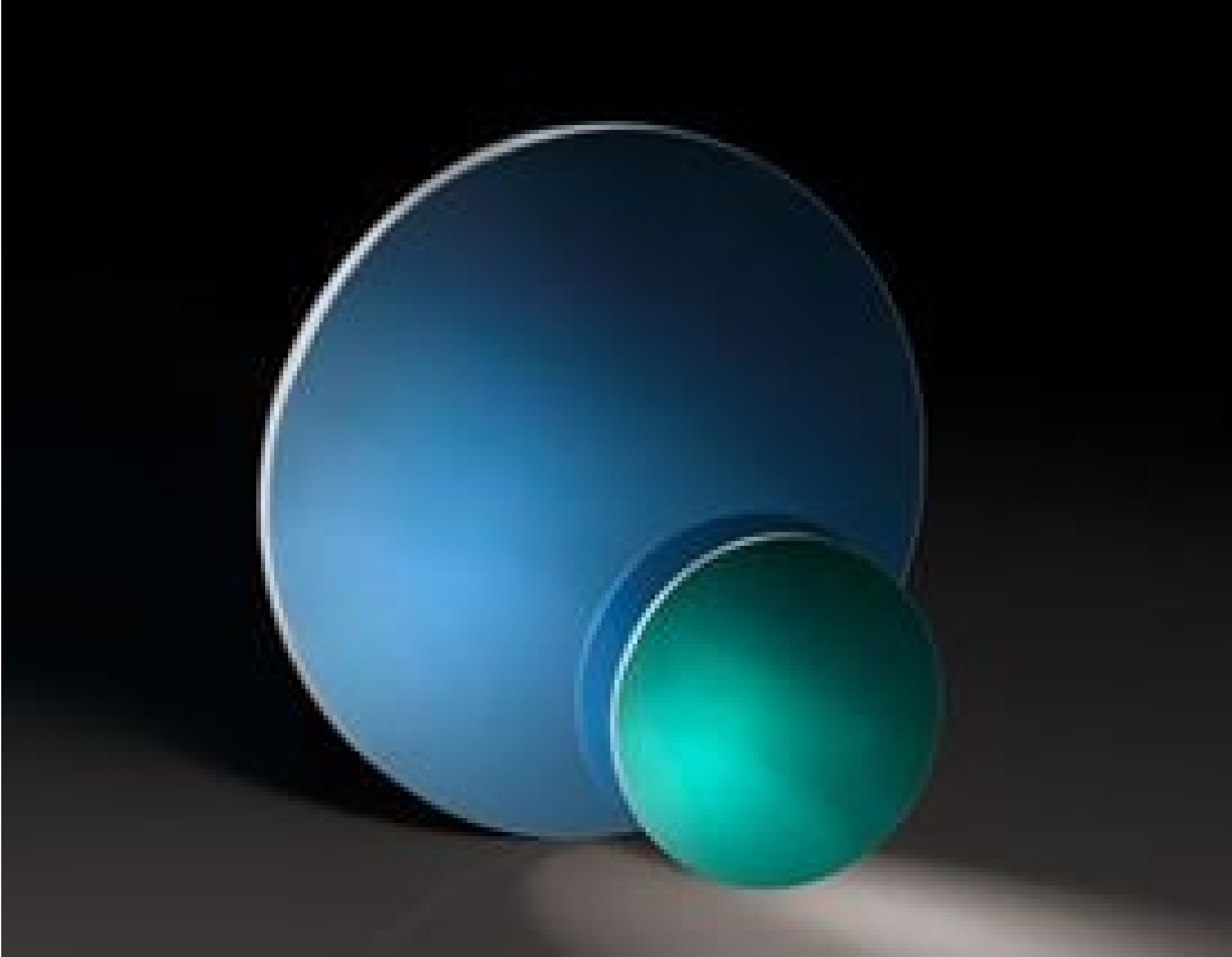

Colored Glass Replacement Longpass Filters

Stock #15-462 [CONTACT US](#)



1



€53,00

ADD TO CART

Qty 1-10

€53,00

Qty 11+

€47,70

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
25.40 ±0.127

Optical Density OD (Average):
≥5.0

Cut-On Wavelength (nm):
850.00 ±8

Substrate:  BOROFLOAT®
Operating Temperature (°C): -100 to +400
Coating: Dielectric
Index of Refraction n_d: 1.80
Rejection Wavelength (nm): 200 - 775
Surface Quality: 80-50
Thickness (mm): 1.10 ±0.10
Transmission (%): >90 (typical)
Transmission Wavelength (nm): 870 - 2500
Type: Longpass Filter
Clear Aperture (%): 90
Environmental Durability: MIL-STD-810, Method 507.3, Procedure III, Modified to 40 cycles
Physical Durability: MIL-C-48497
Wavelength Range (nm): 200 - 2500

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View