


TECHSPEC® 9mm Dia. x 13.5mm FL Uncoated, UV Plano-Convex Lens

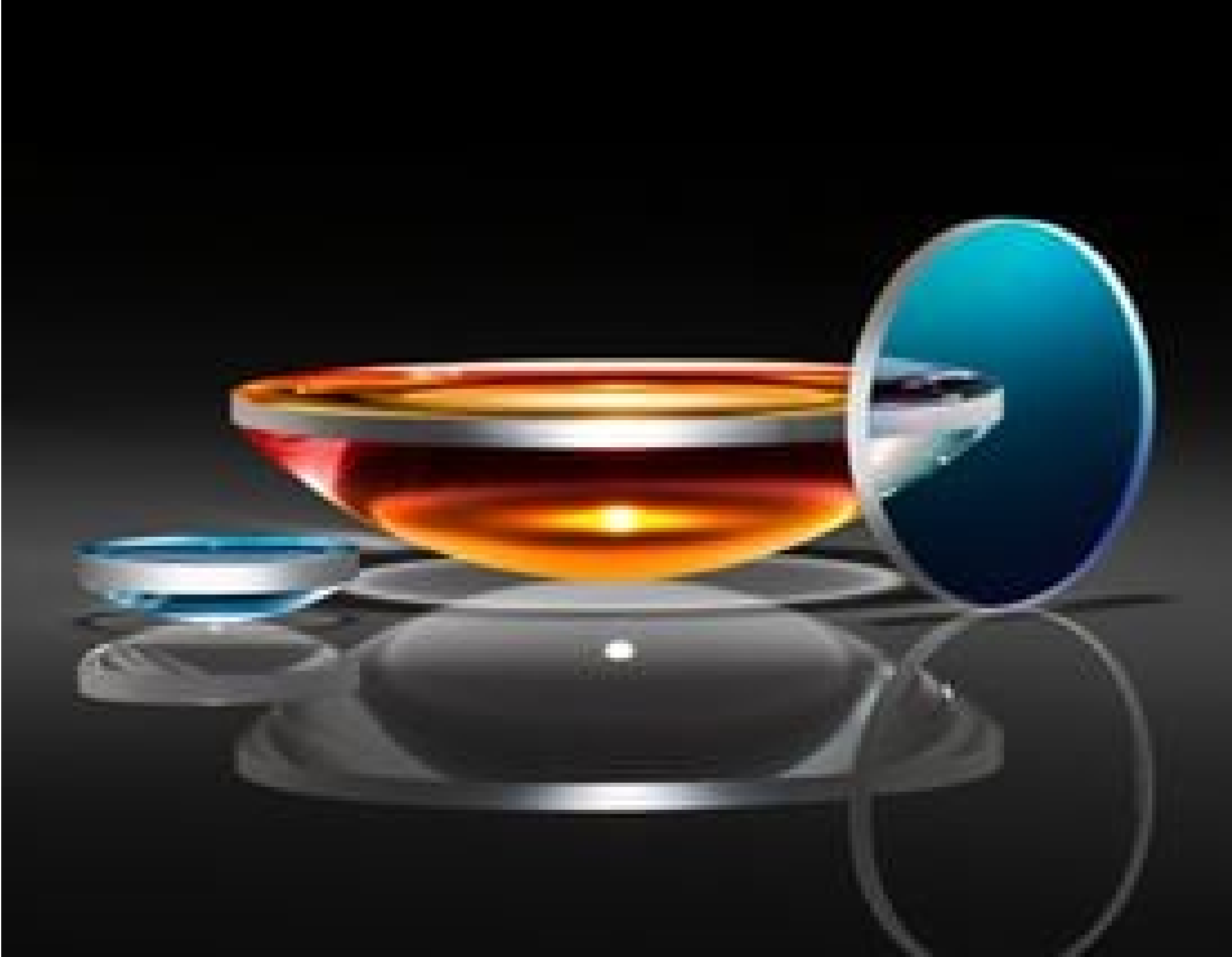

UV Fused Silica Plano-Convex (PCX) Lenses



Stock **#45-693** 3-4 DAYS

[Other Coating Options](#)



1



€120,00

ADD TO CART

Qty 1-5

€120,00

Qty 6+

€96,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
9.00 +0.0/-0.025

Effective Focal Length EFL (mm): 13.50 @ 587.6nm
Back Focal Length BFL (mm): 11.44
Coating: Uncoated
Substrate:  Fused Silica (Corning 7980)
Surface Quality: 40-20
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Focal Length Tolerance (%): ±1
Centering (arcmin): <1
Center Thickness CT (mm): 3.00 ±0.05
Edge Thickness ET (mm): 1.06
Radius R₁ (mm): 6.19
Clear Aperture CA (mm): 8.1
f/#: 1.5
Numerical Aperture NA: 0.33
Type: Plano-Convex Lens
Bevel: Protective bevel as needed
Wavelength Range (nm): 200 - 2200

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View