


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

Pixellink PL-D755MU-T-POL, 2/3" 5.0MP, C-Mount USB 3.0 Polarized Monochrome Camera

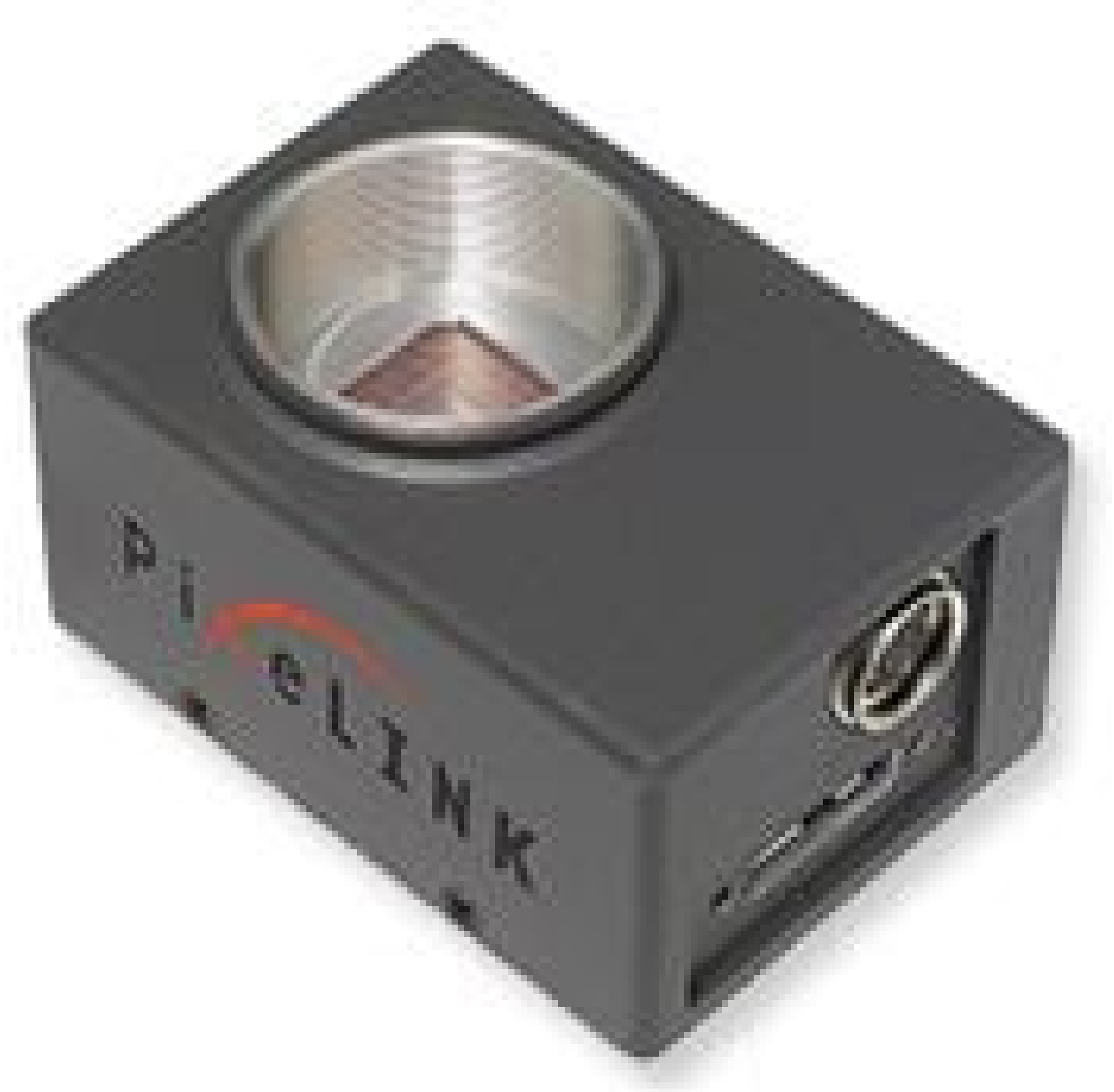

Pixellink® USB 3.0 Cameras (Full Housing)



Stock #14-157 [CONTACT US](#)

[Similar Cameras](#)



1



€4.095,00

ADD TO CART

Qty 1+

€4.095,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Video Output:
USB 3.0

Type:
Polarized Monochrome Camera

Manufacturer:
Pixellink

Mounting Threads: 1/4-20 with Tripod Mount Adapter #89-408
Image Buffer: Not Specified
Camera Family: PL-D
Model Number: PL-D755MJ-T-POL
Imaging Sensor: Sony IMX250MZR
Type of Sensor: Progressive Scan CMOS
Type of Shutter: Global
Camera Sensor Format: 2/3"
Resolution (MegaPixels): 5.01
Pixels (H x V): 2,448 x 2,048
Pixel Size, H x V (µm): 3.45 x 3.45
Sensing Area, H x V (mm): 8.45 x 7.07
Frame Rate (fps): 36.00
Pixel Depth: 8/12 bit
Exposure Time: 20µs - 120s
Connector: USB 3.0, Micro-B
Power Supply: Power over USB
Power Consumption (W): Not Specified
GPIOs: 1 opto-isolated trigger input, 1 opto-isolated output, 2 non-isolated outputs, 1 non-isolated input
Synchronization: Hardware Trigger (GPIO) or Software Trigger
Dimensions (mm): 55 x 38.5 x 27 (excludes connectors and lens mount)
Weight (g): 89
Mount: C-Mount
Housing: Full
Interface Port Orientation: Side Panel
Dynamic Range (dB): 70
Operating Temperature (°C): 0 to +50
Storage Temperature (°C): -45 to +85
GPIO Connector Type: 8-pin Hirose (HR25)
Machine Vision Standard: USB3 Vision v1.0
Operating System: Software Driver: Windows 32 and 64 bit

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View