


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

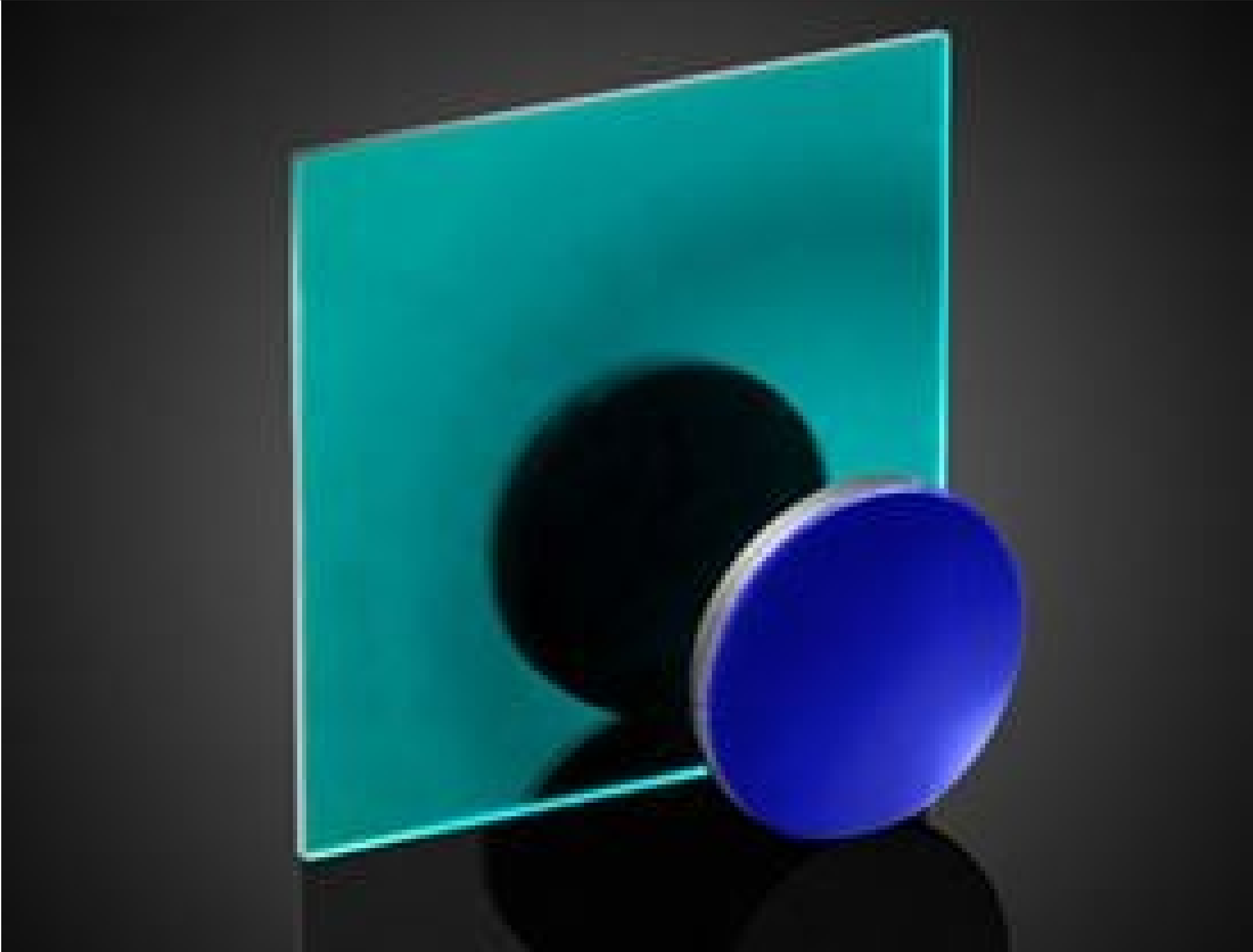

Stock **#16-370** [CONTACT US](#)



1



€72,00

ADD TO CART

Qty 1-10

€72,00

Qty 11+

€63,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50

Density (g/cm³):
3.59

Glass/Filter Number: SCHOTT BG36
Coating: Uncoated
Color: Clear
Index of Refraction n_d: 1.69
Surface Quality: 60-40
Transformation Temperature (°C): 657
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: UV-IR
Bevel: Protective as needed

Regulatory Compliance

Certificate of Conformance: View
--