 



SCHOTT BG42, 50mm Sq., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

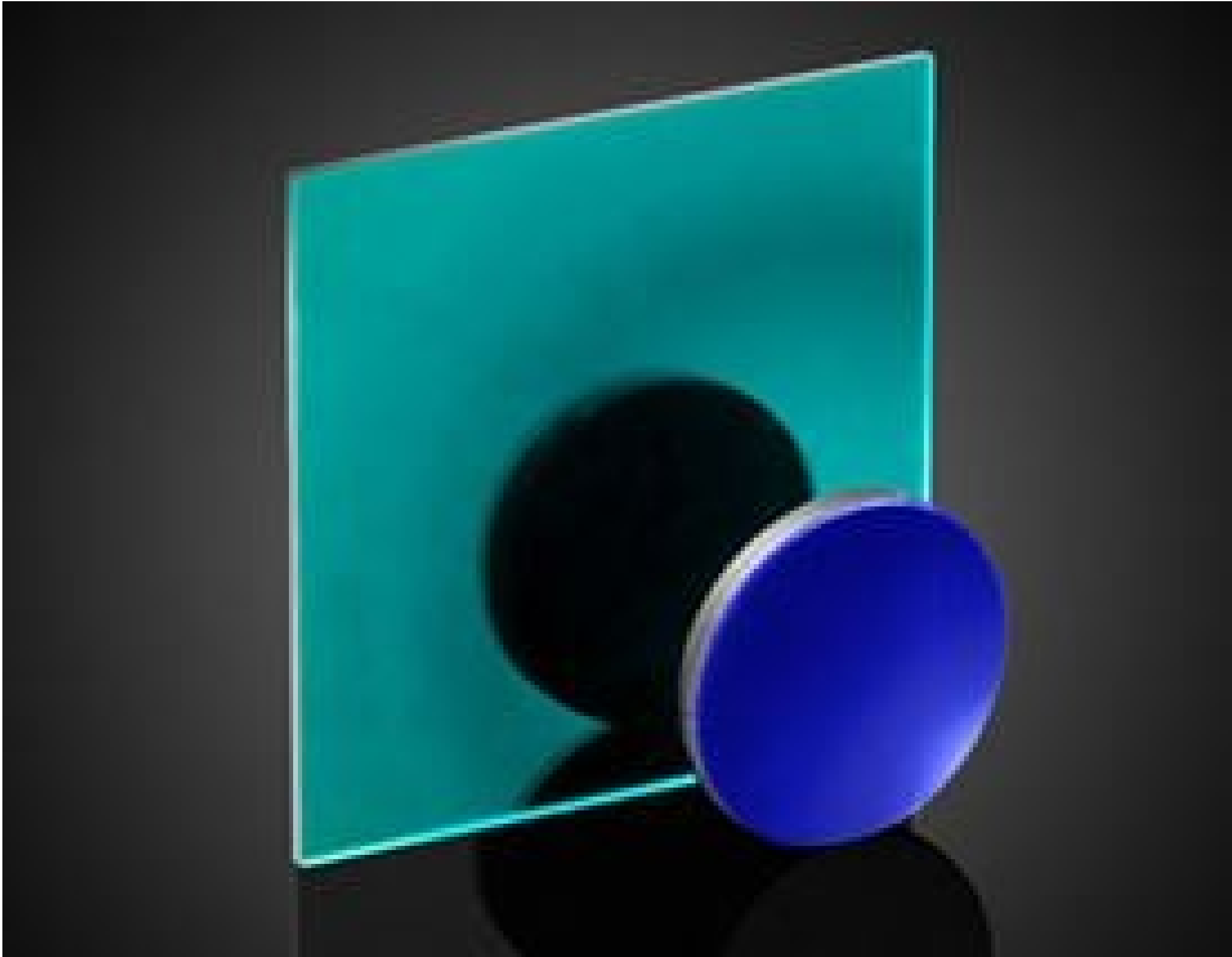

Stock **#14-424** ☐ In Stock

- 1 +

€88,00

ADD TO CART

Qty 1-10
€88,00
Qty 11+
€78,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Center Wavelength CWL (nm):
480.00

Density (g/cm³): 2.69
Glass/Filter Number: SCHOTT BG42
Length (mm): 50.00
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.54
Surface Quality: 60-40
Transformation Temperature (°C): 475
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View