

In order to provide more accurate inventory information, please select your shipping country.


Select Your Country/Region: European Union




SUBMIT

## SCHOTT NG1, 25mm Dia., 1mm Thick, Absorptive ND Filter

See More by [SCHOTT Optical Components](#)

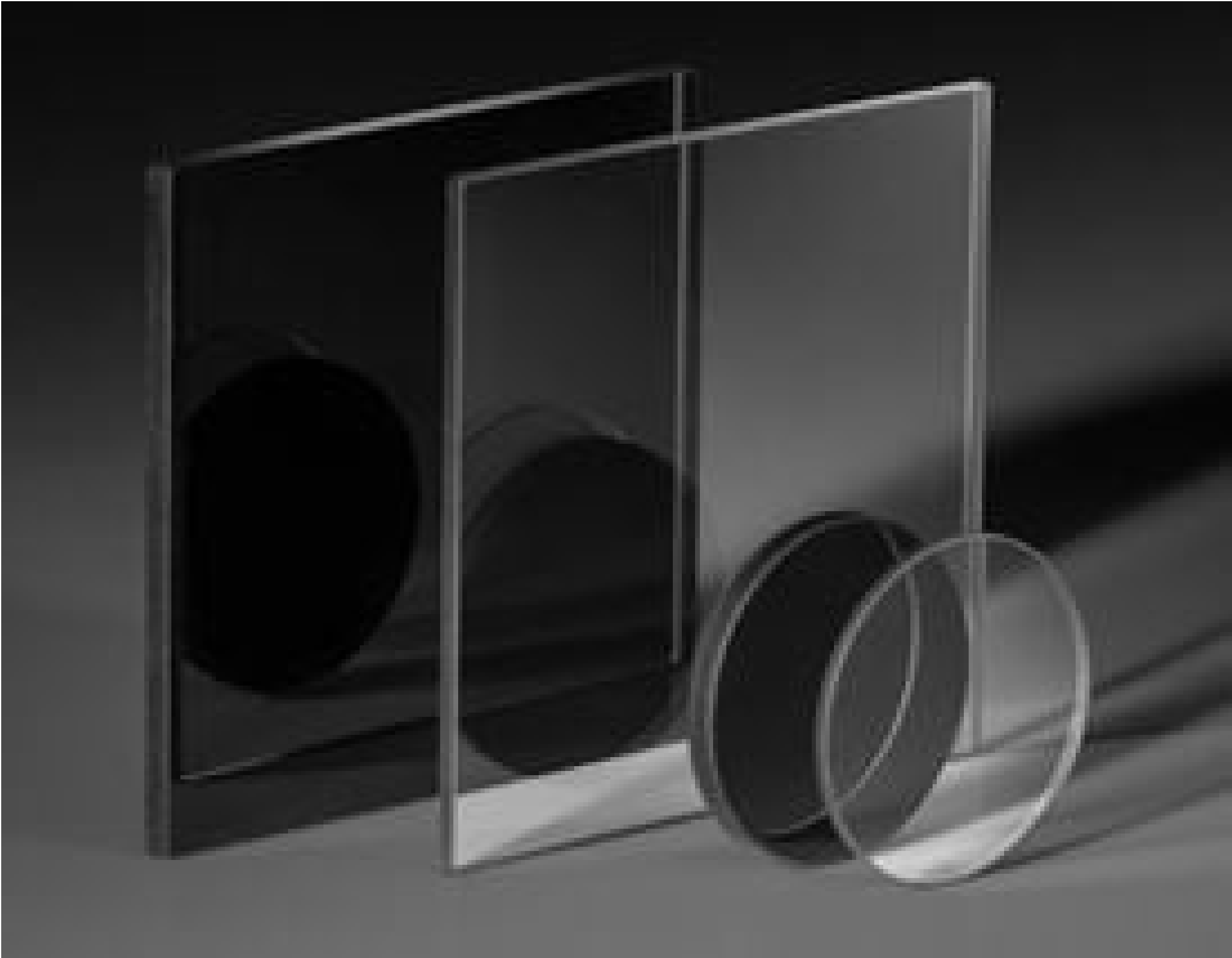

 SCHOTT NG Gray Glass Neutral Density (ND) Filters



Stock **#14-075** □ In Stock



1



€42,00

ADD TO CART

Qty 1-10

€42,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):  
25.00

Optical Density OD (Average):  
4.84

|                                                           |
|-----------------------------------------------------------|
| <b>Glass/Filter Number:</b><br><a href="#">SCHOTT NG1</a> |
| <b>Coating:</b><br>Uncoated                               |
| <b>Index of Refraction <math>n_d</math>:</b><br>1.52      |
| <b>Surface Quality:</b><br>60-40                          |
| <b>Transformation Temperature (°C):</b><br>471            |
| <b>Thickness (mm):</b><br>1.00 ±0.1                       |
| <b>Transmission (%):</b><br>0.001                         |
| <b>Transmission Tolerance (%):</b><br>(nominal)           |
| <b>Type:</b><br>Neutral Density Filter                    |
| <b>Parallelism (arcmin):</b><br>≤3                        |
| <b>Dimensional Tolerance (mm):</b><br>±0.2                |
| <b>Optical Density Tolerance (%):</b><br>(nominal)        |

## Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS:</b><br><a href="#">Compliant</a>                  |
| <b>Reach 223:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |