


# SCHOTT NG9, 3.6 OD, 50mm Sq., Absorptive ND Filter

See More by [SCHOTT Optical Components](#)

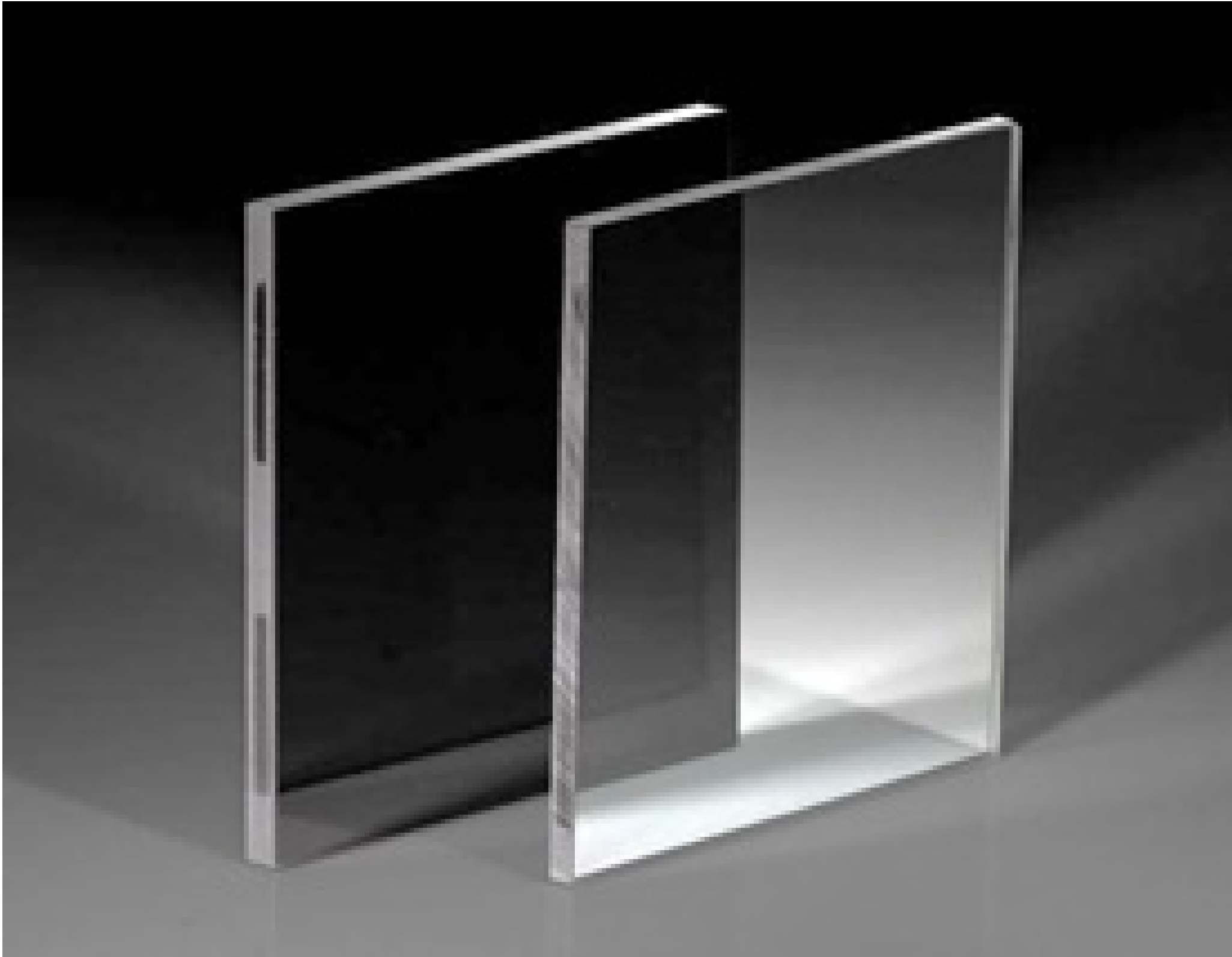

Stock **#14-064** ☐ In Stock

⊖

1

⊕

**€93,00**

ADD TO CART

Qty 1-10

€93,00

Qty 11+

€82,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads

**Dimensions (mm):**  
50.0 x 50.0

**Optical Density OD (Average):**  
3.6 ±0.07 @ 546nm

**Glass/Filter Number:**  
[SCHOTT NG9](#)

|                                                      |
|------------------------------------------------------|
| <b>Length (mm):</b><br>50.00                         |
| <b>Coating:</b><br>Uncoated                          |
| <b>Index of Refraction <math>n_d</math>:</b><br>1.51 |
| <b>Surface Quality:</b><br>60-40                     |
| <b>Transformation Temperature (°C):</b><br>470       |
| <b>Thickness (mm):</b><br>2.60                       |
| <b>Thickness Tolerance (mm):</b><br>(nominal)        |
| <b>Transmission (%):</b><br>0.025 ±0.00425% @ 546nm  |
| <b>Type:</b><br>Neutral Density Filter               |
| <b>Width (mm):</b><br>50.00                          |
| <b>Parallelism (arcmin):</b><br>≤3                   |
| <b>Dimensional Tolerance (mm):</b><br>±0.2           |
| <b>Wavelength Range (nm):</b><br>400 - 700           |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS:</b><br><a href="#">Compliant</a>                  |
| <b>Reach 223:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |