


Green Fluorescent Filter (G9), 50mm Square

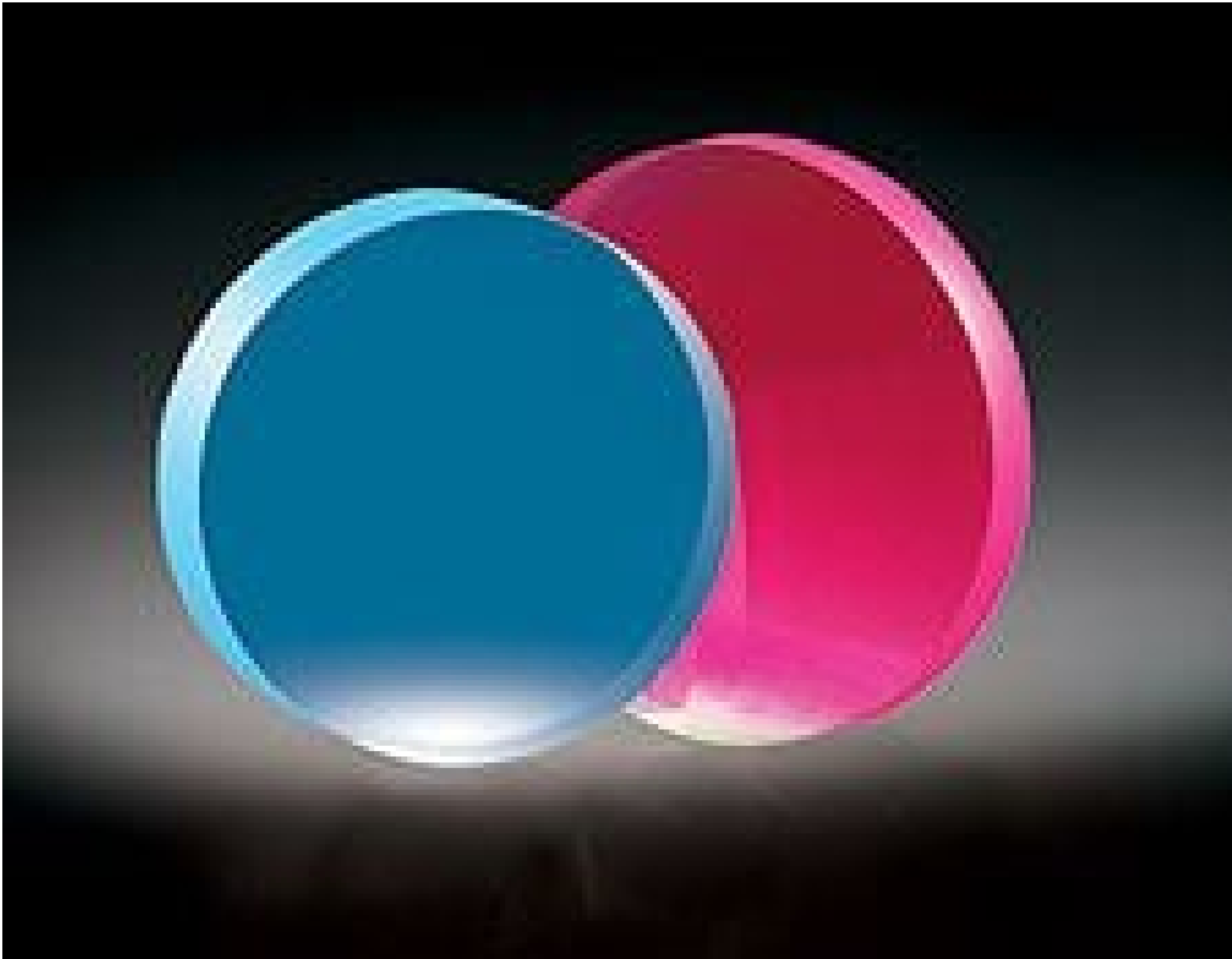

Stock **#84-887** 3-4 DAYS

⊖ 1 ⊕ **€690,00**

ADD TO CART

Qty 1-9
€690,00
Qty 10+
€607,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
50.0 x 50.0 ±0.10

Glass/Filter Number:
G9

Substrate: ☐

Lumilass
Length (mm): 50.00
Coating: Uncoated
Color: Green
Index of Refraction n_d: 1.694
Transformation Temperature (°C): 660.00
Thickness (mm): 3.00 ±0.10
Type: Color Filter
Width (mm): 50.00
Peak Emission Wavelength (nm): 540.00
Excitation Wavelength (nm): 200 - 390
Peak Excitation Wavelength (nm): 365.00
Minimum Sensitivity: ~1μW/cm ²

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant