


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

Pixellink PL-D722MU-1, 2/3" 2.3MP, C-Mount USB 3.0 Monochrome Camera

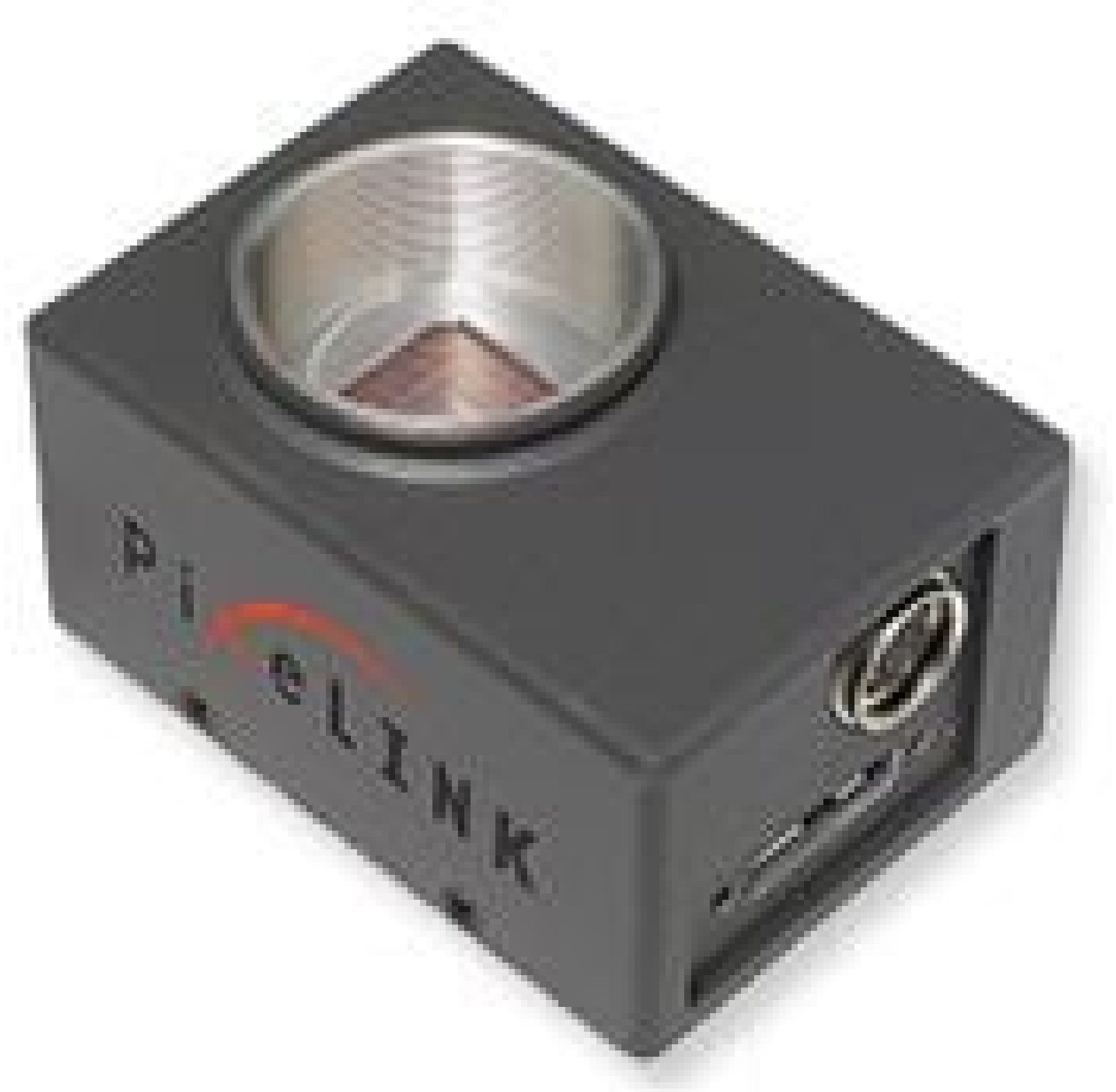

Pixellink® USB 3.0 Cameras (Full Housing)



Stock #89-382 3-4 DAYS

[Similar Cameras](#)



1



€1.595,00

ADD TO CART

Qty 1+

€1.595,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Video Output:  
USB 3.0

Type:  
Monochrome Camera

|                                                                                                                      |
|----------------------------------------------------------------------------------------------------------------------|
| <b>Manufacturer:</b><br>Pixelink                                                                                     |
| <b>Mounting Threads:</b><br>¼-20 with Tripod Mount Adapter <a href="#">#89-408</a>                                   |
| <b>Image Buffer:</b><br>Not Specified                                                                                |
| <b>Camera Family:</b><br>PL-D                                                                                        |
| <b>Model Number:</b><br>PL-D722MJ-T                                                                                  |
| <b>Imaging Sensor:</b><br>ON Semi VITA2000                                                                           |
| <b>Type of Sensor:</b><br>Progressive Scan CMOS                                                                      |
| <b>Type of Shutter:</b><br>Global                                                                                    |
| <b>Camera Sensor Format:</b><br>2/3"                                                                                 |
| <b>Resolution (MegaPixels):</b><br>2.30                                                                              |
| <b>Pixels (H x V):</b><br>1,920 x 1,200                                                                              |
| <b>Pixel Size, H x V (µm):</b><br>4.8 x 4.8                                                                          |
| <b>Sensing Area, H x V (mm):</b><br>9.22 x 5.76                                                                      |
| <b>Frame Rate (fps):</b><br>87.00                                                                                    |
| <b>Pixel Depth:</b><br>8/10 bit                                                                                      |
| <b>Exposure Time:</b><br>1µs - 4.33s                                                                                 |
| <b>Connector:</b><br>USB 3.0, Micro-B                                                                                |
| <b>Power Supply:</b><br>Power over USB                                                                               |
| <b>Power Consumption (W):</b><br>Not Specified                                                                       |
| <b>GPIOs:</b><br>1 opto-isolated trigger input, 1 opto-isolated output, 2 non-isolated outputs, 1 non-isolated input |
| <b>Synchronization:</b><br>Hardware Trigger (GPIO) or Software Trigger                                               |
| <b>Dimensions (mm):</b><br>55 x 38.5 x 27 (excludes connectors and lens mount)                                       |
| <b>Weight (g):</b><br>89                                                                                             |
| <b>Mount:</b><br>C-Mount                                                                                             |
| <b>Housing:</b><br>Full                                                                                              |
| <b>Interface Port Orientation:</b><br>Side Panel                                                                     |
| <b>Dynamic Range (dB):</b><br>53                                                                                     |
| <b>Operating Temperature (°C):</b><br>0 to +50                                                                       |
| <b>Storage Temperature (°C):</b><br>-45 to +85                                                                       |
| <b>GPIO Connector Type:</b><br>8-pin Hirose (HR25)                                                                   |
| <b>Machine Vision Standard:</b><br>USB3 Vision v1.0                                                                  |
| <b>Operating System:</b><br>Software Driver: Windows 32 and 64 bit                                                   |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 224:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |

