


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

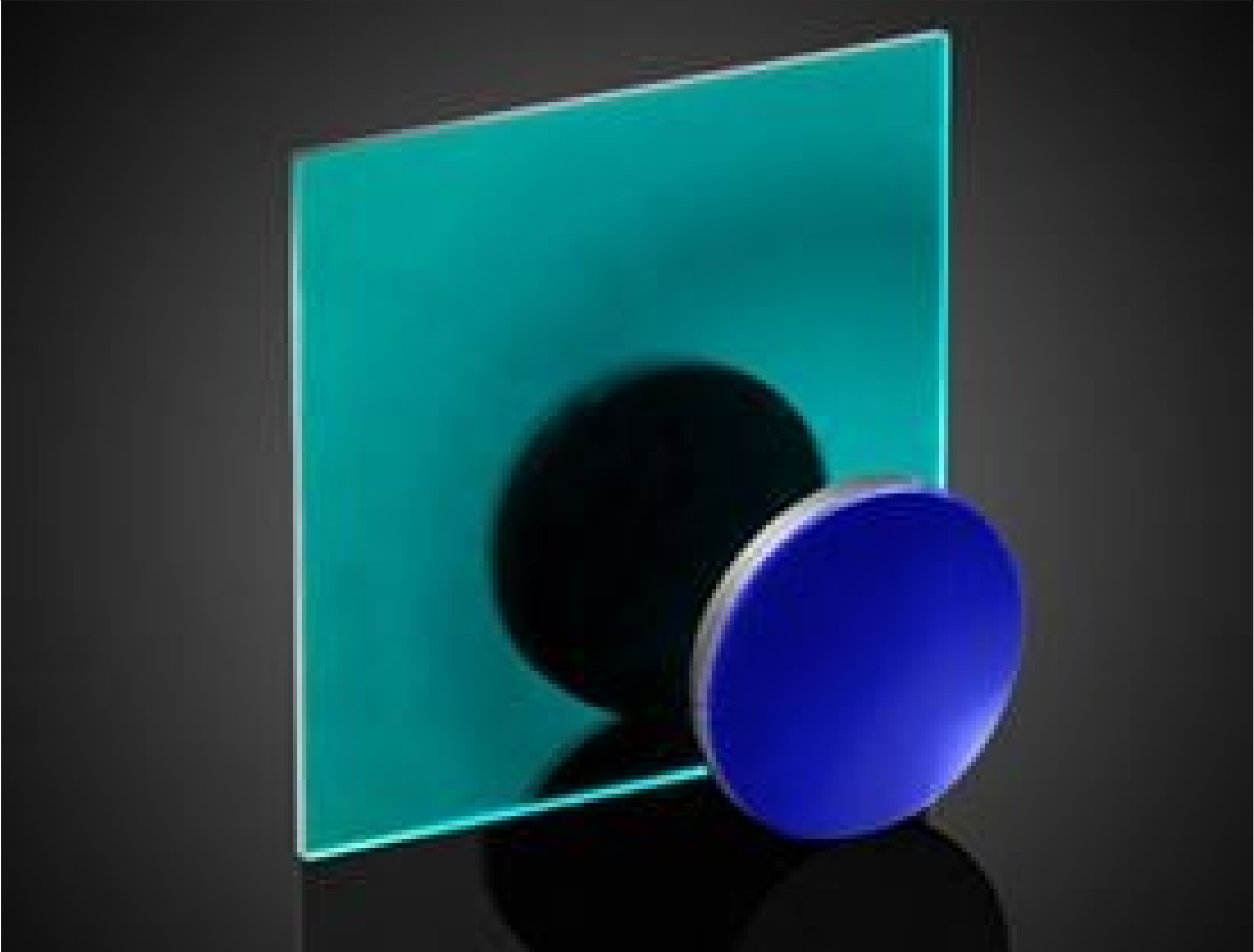

Stock **#14-419** ☐ In Stock



1



€88,00

ADD TO CART

Qty 1-10

€88,00

Qty 11+

€78,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):

50.0 x 50.0

Center Wavelength CWL (nm):

507.00

|                                                                 |
|-----------------------------------------------------------------|
| <div>Density (g/cm³):<br/>2.74</div>                            |
| <div>Glass/Filter Number:<br/><a href="#">SCHOTT BG39</a></div> |
| <div>Length (mm):<br/>50.00</div>                               |
| <div>Coating:<br/>Uncoated</div>                                |
| <div>Color:<br/>Blue-Green</div>                                |
| <div>Index of Refraction n<sub>d</sub>:<br/>1.54</div>          |
| <div>Surface Quality:<br/>60-40</div>                           |
| <div>Transformation Temperature (°C):<br/>322</div>             |
| <div>Thickness (mm):<br/>2.00 ±0.2</div>                        |
| <div>Type:<br/>Bandpass Filter</div>                            |
| <div>Wavelength:<br/>VIS</div>                                  |
| <div>Width (mm):<br/>50.00</div>                                |
| <div>Bevel:<br/>Protective as needed</div>                      |

## Regulatory Compliance

|                                                                 |
|-----------------------------------------------------------------|
| <div>RoHS:<br/><a href="#">Compliant</a></div>                  |
| <div>Certificate of Conformance:<br/><a href="#">View</a></div> |