



In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

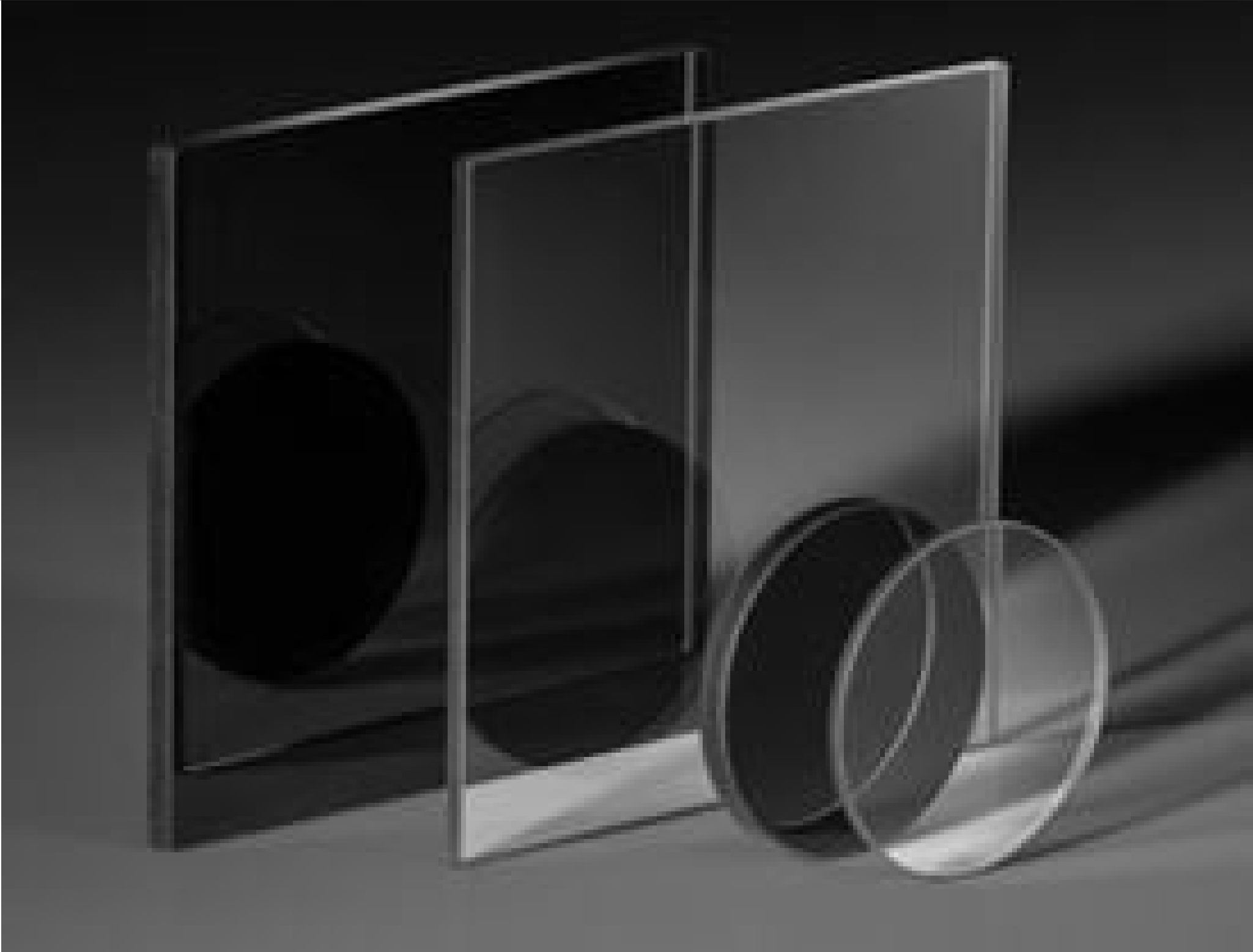

 SCHOTT NG Gray Glass Neutral Density (ND) Filters



Stock #14-077 In Stock



1



€42,00

ADD TO CART

Qty 1-10

€42,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):  
25.00

Optical Density OD (Average):  
>5

|                                                                |
|----------------------------------------------------------------|
| <div>Glass/Filter Number:<br/><a href="#">SCHOTT NG1</a></div> |
| <div>Coating:<br/>Uncoated</div>                               |
| <div>Index of Refraction <math>n_d</math>:<br/>1.52</div>      |
| <div>Surface Quality:<br/>60-40</div>                          |
| <div>Transformation Temperature (°C):<br/>471</div>            |
| <div>Thickness (mm):<br/>2.00 ±0.2</div>                       |
| <div>Transmission (%):<br/>&lt;0.001</div>                     |
| <div>Transmission Tolerance (%):<br/>(nominal)</div>           |
| <div>Type:<br/>Neutral Density Filter</div>                    |
| <div>Parallelism (arcmin):<br/>≤3</div>                        |
| <div>Dimensional Tolerance (mm):<br/>±0.2</div>                |
| <div>Optical Density Tolerance (%):<br/>(nominal)</div>        |

## Regulatory Compliance

|                                                                 |
|-----------------------------------------------------------------|
| <div>RoHS:<br/><a href="#">Compliant</a></div>                  |
| <div>Reach 223:<br/><a href="#">Compliant</a></div>             |
| <div>Certificate of Conformance:<br/><a href="#">View</a></div> |