

In order to provide more accurate inventory information, please select your shipping country:

 

Select Your Country/Region: European Union



SUBMIT

Hoya U330 (UV) 12mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

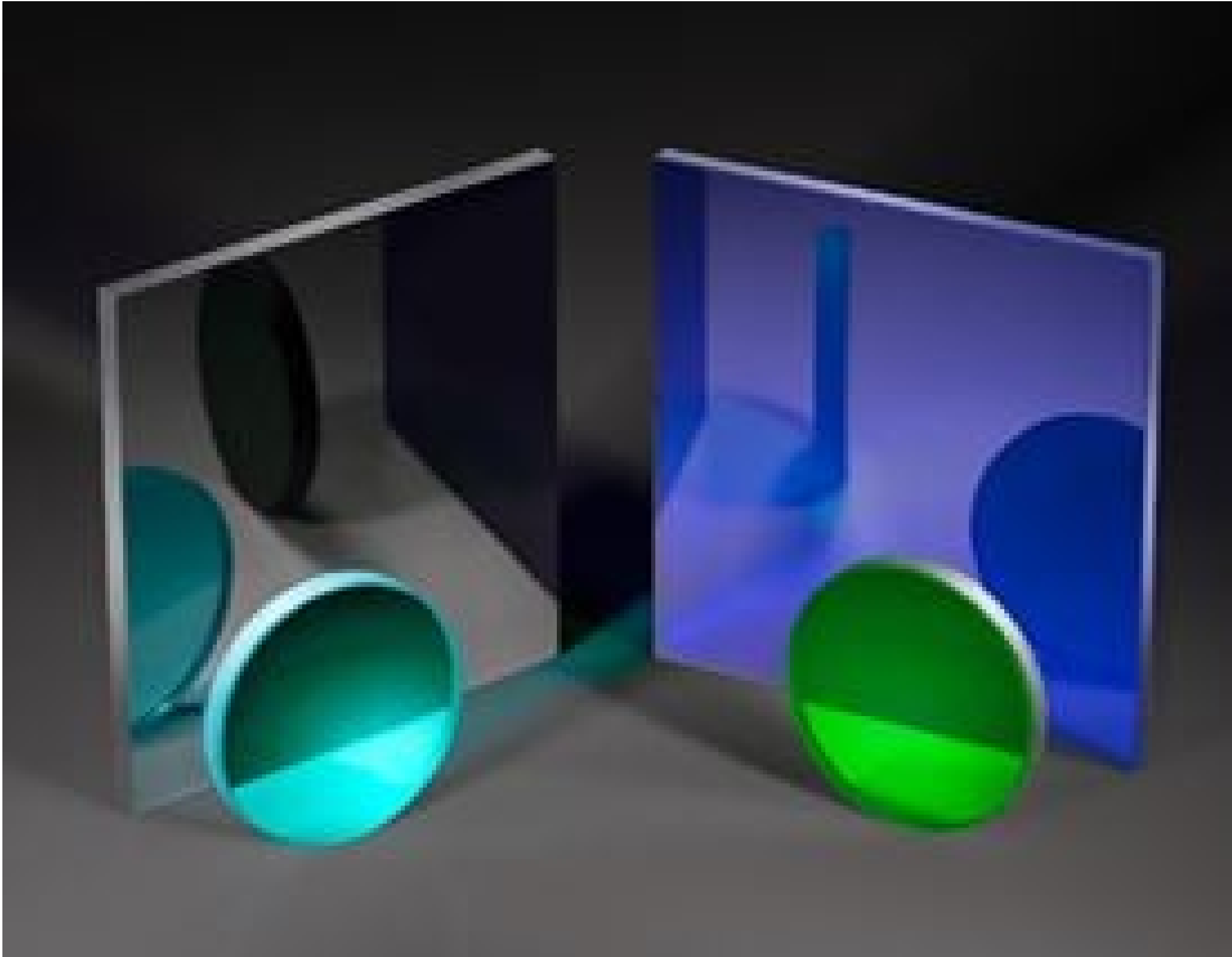

Stock #46-095 3-4 DAYS

☐ [Additional Bandwidths](#)



1



€41,00

ADD TO CART

Qty 1-10

€41,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):  
12.00

|                                                             |
|-------------------------------------------------------------|
| <b>Center Wavelength CWL (nm):</b><br>330.00                |
| <b>Density (g/cm³):</b><br>2.78                             |
| <b>Full Width-Half Max FWHM (nm):</b><br>140.00             |
| <b>Glass/Filter Number:</b><br><a href="#">Hoya U330</a>    |
| <b>Substrate:</b> <input type="checkbox"/><br>Colored Glass |
| <b>Coating:</b><br>Uncoated                                 |
| <b>Color:</b><br>Black                                      |
| <b>Surface Quality:</b><br>60-40                            |
| <b>Thickness (mm):</b><br>2.50                              |
| <b>Thickness Tolerance (mm):</b><br>±0.2                    |
| <b>Type:</b><br>Bandpass Filter                             |
| <b>Wavelength:</b><br>UV                                    |
| <b>Parallelism (arcmin):</b><br>≤1                          |
| <b>Dimensional Tolerance (mm):</b><br>+0/-0.25              |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Exempt</a>                |
| <b>Reach 224:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |