


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

variable Frequency Targets 5-200 lp/mm

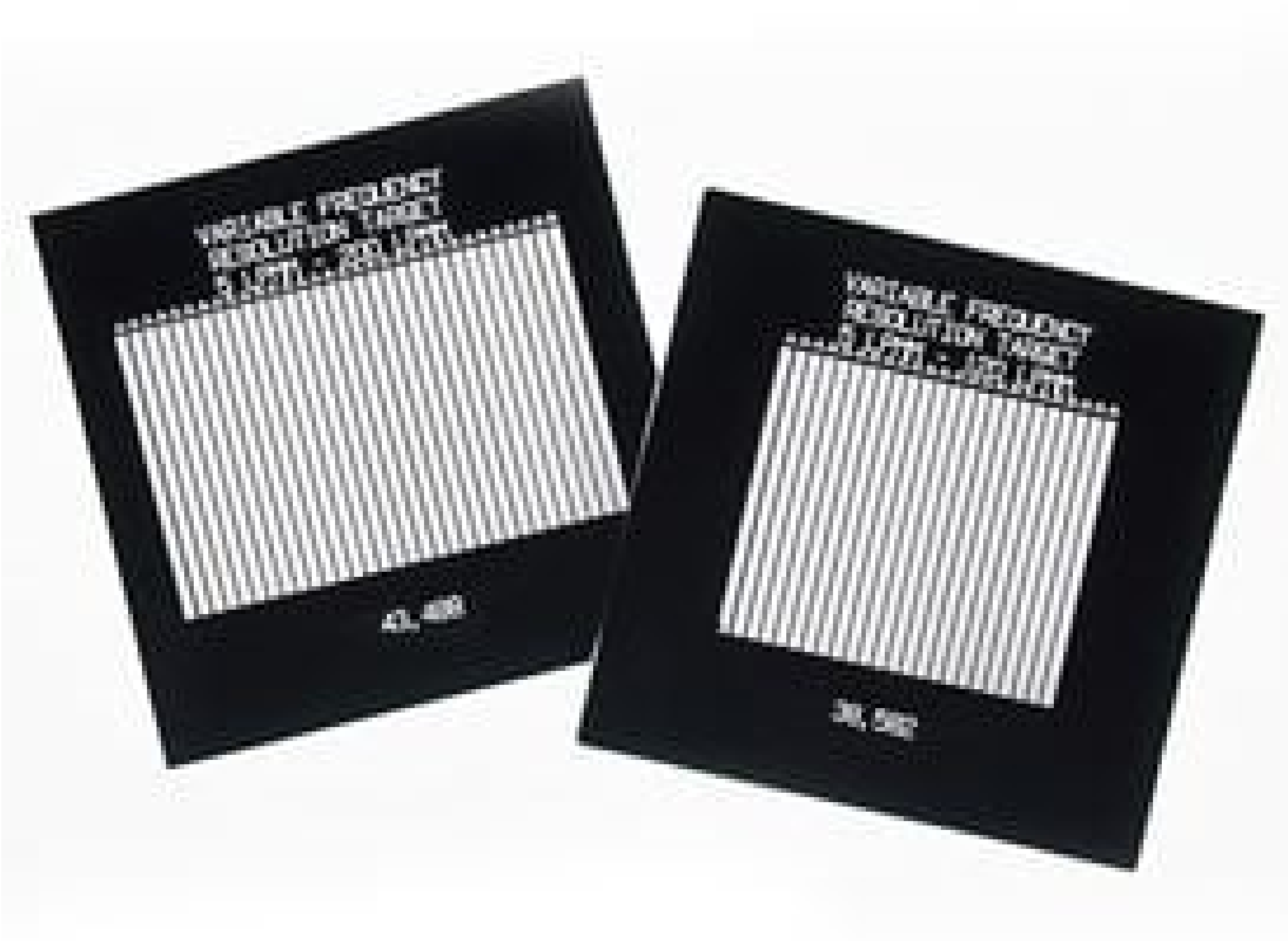

Stock #43-488 3-4 DAYS



1



€781,00

ADD TO CART

Qty 1-4

€781,00

Qty 5+

€742,30

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
Vacuum deposited durable chromium

Substrate:
Float Glass

Optical Density OD (Average):
≥3.0

Pattern Size (mm):

25.4 x 39.37
Dimensions (inches): 2 x 2
Surface Quality: 40-10
Thickness (mm): 1.50
Edges: Beveled
Flatness (mm): 0.00254

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View