
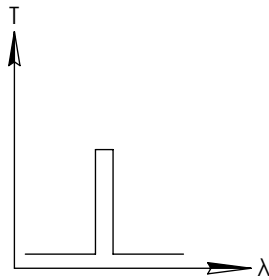
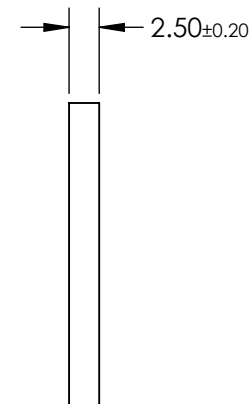
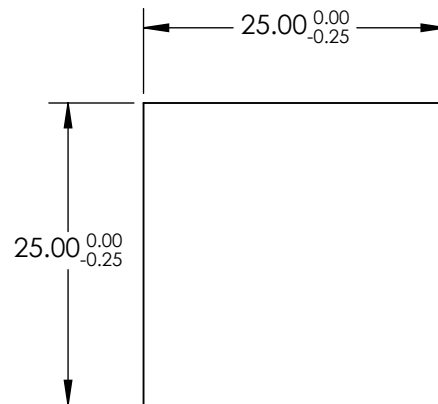


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

 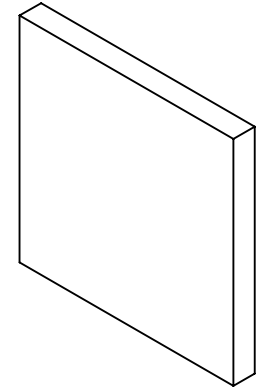


BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	360
FULL WIDTH HALF MAX (FWHM) (nm)	45
SURFACE QUALITY	80-50
CAOTING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED



THIRD ANGLE PROJECTION 

ALL DIMS IN mm

TITLE	HOYA U-360 (UV) 25mm Square, Colored Glass Bandpass Filter
DWG NO	46085
SHEET 1 OF 1	