
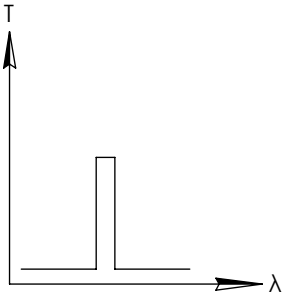
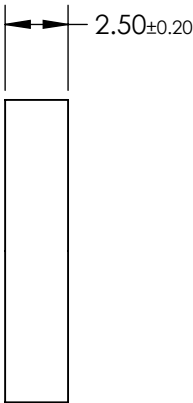
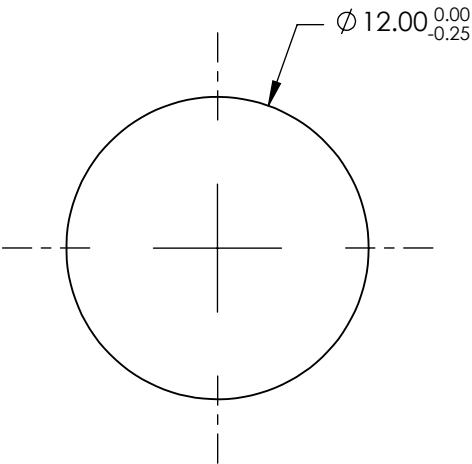


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

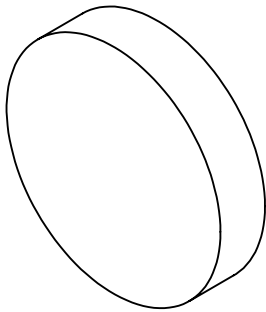

BANDPASS FILTER


SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	410
FULL WIDTH HALF MAX (FWHM) (nm)	232
SURFACE QUALITY	80-50
COATING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED

THIRD ANGLE
PROJECTION

ALL DIMS IN

mm

<div> Edmund Optics®</div>			
TITLE		HOYA B-410 (UV-VIS) 12mm Dia., Colored Glass Bandpass Filter	
DWG NO		34431	SHEET 1 OF 1